

GP3300i

GP Series Inverter Generator

FEATURES

- **COsense® Technology** STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **Quiet Inverter Power** reduces sound emissions and provides optimal performance.
- **True Power™ Technology** provides clean, stable power ideal for sensitive electronics, tools and appliances.
- **Easy to Carry** - compact & lightweight design with built-in handle makes transportation easy.
- **PowerDial™** - Off, Run, Choke: three operation settings integrated into one simple-to-use dial.
- **Economy Mode** automatically adjusts engine speed to save fuel and reduce sound emissions.
- **USB Ports** to charge mobile devices including smart phones and tablets.
- **Parallel Ready** to connect two GP3300i inverter generators for twice the power. (Parallel kit sold separately.)
- **Generator Status Lights** - visual alerts when unit is low on oil, overloaded or ready to use.

*Increases electrical current upon demand; above rated output when starting electric motors.

Model 7153-2 UPC: 696471104011 (49ST)

Model 7153-3 UPC: 696471104011 (49ST/CSA)

Photograph may not represent actual content.




AC Rated Output Running Watts 2500

AC Maximum Output Starting Watts 3300



Model 7668-0 UPC: 696471073102

CONTROL PANEL

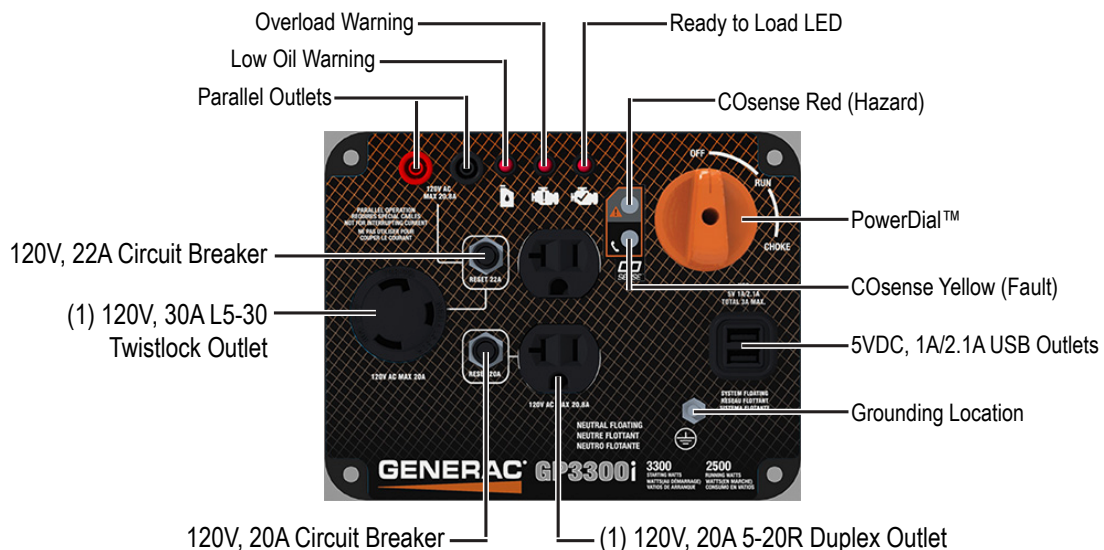

SPECIFICATIONS

Product Series	GP3300i
Model (Configuration)	7153-2 (49ST) / 7153-3 (49ST/CSA)
AC Rated Output Running Watts	2500
AC Maximum Output Starting Watts	3300
Rated AC Voltage	120 VAC
Rated AC Frequency	60 Hz
Rated 120 VAC Amperage	20.83
Total Harmonic Distortion	<3%
Engine Displacement	149cc
Engine Type	OHV
Engine RPM	Variable
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	0.6 (0.6)
Lubrication Method	Splash
Choke Location	Integrated into PowerDial™
Fuel Shut Off	Integrated into PowerDial™
Starting Method	Recoil Pull Start
Low Oil Shutdown	Yes

Floating Neutral	Yes
Start Switch Type	PowerDial™
Start Switch Location	On Control Panel
Fuel Tank Capacity Gal (L)	106 (4.0)
Run Time at 50% (Hours)	4.5
Run Time at 25% (Hours)	7
Warranty - Commercial	2 Year Limited
Warranty - Residential	3 Year Limited
Included	Engine oil, oil funnel, tool kit and Owner's Manual
Product Series	Inverter Parallel Kit (sold separately) (Not for sale in Canada)
Model	7668-0
Receptacle Type	(1) 120V 50A 14-50R / (1) 120V 30A TT-30R (RV)
Rated 120 VAC Amperage	50 Amp
AC Rated Voltage	120 V
Warranty - Parallel Kit	90 Day Limited

DIMENSIONS AND WEIGHTS

Length in (mm)	22.2 (565)
Width in (mm)	13.3 (339)
Height in (mm)	18.4 (467)
Carton Length in (mm)	23.6 (600)
Carton Width in (mm)	13.4 (340)
Carton Height in (mm)	20.7 (525)
Unit Weight lbs (kg)	61 (27.7)
Shipping Weight lbs (kg)	68 (31)

Inverter Parallel Kit (sold separately)	
Length in (mm)	9.84 (250)
Width in (mm)	4.33 (110)
Height in (mm)	8.27 (210)
Carton Length in (mm)	11.02 (280)
Carton Width in (mm)	9.37 (238)
Carton Height in (mm)	6.10 (155)
Unit Weight lbs (kg)	3.53 (1.6)
Shipping Weight lbs (kg)	3.8 (1.75)

