


3 AA (not included)

INTRINSICALLY SAFE FLASHLIGHT WITH LASER

XPP-5422GXL

NIGHTSTICK®

Life Depends on Light™

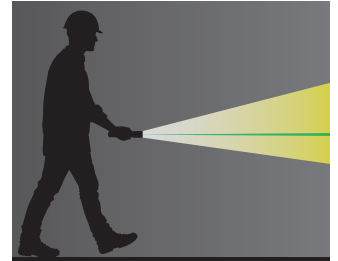

Simultaneous **flashlight and laser** operation



Durable polymer body is **impact & chemical resistant**



Sharp focused flashlight beam for **illumination up to 187 m**

**CLASS I
DIV 1**

CLASS 3R
LASER
GREEN

IP-67
DUST/WATER
PROOF

CERTIFIED
CE  UK
CA

210 LUMENS

1-800-233-2155 · 1-469-326-9400 · nightstick.com

FLASHLIGHT - GREEN LASER

3 AA (not included)

ITEM NUMBER/UPC

- XPP-5422GXL, UPC 0 17398 80802 6

MARKET APPLICATIONS

- Hazardous work environments, industrial, automotive

CERTIFICATIONS

- cETLus, CE
- Laser Cert : UL
US: CFR Title21
IEC: IEC60825-1

CASE MATERIAL

- Engineered polymer

**LUMENS/RUNTIME
FLASHLIGHT**

-210L, 16 hrs. runtime

CANDELA

- 7,970

BEAM DISTANCE

- 187 m

WATER RATING

- ANSI IP-67 dustproof / waterproof

DROP RATING

- 2 meters

DIMENSIONS

- LENGTH: 7.0 in (178 mm)
- HANDLE DIAMETER: 1.1 in x 1.5 in (28 mm x 38 mm)
- HEAD DIAMETER: 1.8 in (46 mm)
- WEIGHT: 7.6 oz (215 g)

POWER SOURCE


- 3 AA batteries (not included)

WARRANTY

- Limited lifetime

WHAT'S INCLUDED

- Flashlight
- Removable lanyard
- Instruction Manual

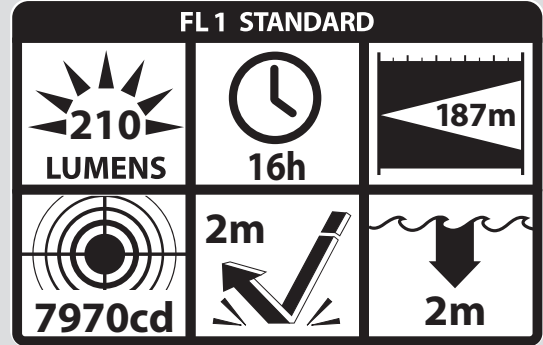

Bayco Products, Inc. XPP-5422GXL
640 S. Sanden Blvd.
Wylie, TX 75098



ID 4003544
INTRINSICALLY SAFE
SECURITE INTRINSEQUE



CLASS I DIV 1 GRPS A-D T3
CLASS II & III DIV 1 GRPS E-G T135°C
CLASS I ZONE 0 IIC T3
CLASS II ZONE 20 IIIC T135°C
-20°C ≤ Tamb ≤ +40°C
1.5V/Cell AA Alkaline

SEE INSTRUCTION MANUAL
VOIR MANUEL

MFG MM-YY

CERTIFIED



© 2023 Bayco Products Inc. Items shown are intended as a visual representation for informational purposes only and are subject to change without notice. Visit: nightstick.com for product updates. XPP-5422GXL-23

