

# Purdy®

PROFESSIONAL PAINTING TOOLS

## Paint Any Surface With Ease.

PRODUCT CATALOG



# Quality. Integrity. Value.

Purdy® began in 1925 when S. Desmond Purdy began building paintbrushes in his garage in Portland, OR. Mr. Purdy built his brushes on three foundational principles—quality, integrity and value. Although handcrafting the finest painting tools may take longer, it is the only way to "build in" the qualities that create a brush of superior coverage and unsurpassed performance.

*Over 95 years later, Purdy is still dedicated to crafting the finest applicators in the industry.*



# CONTENTS

## BRUSHES

<b>How to Choose a Brush</b> .....	<b>6</b>	<b>BRISTLES</b>
Clearcut® Elite™ Series .....	7	<b>Ultra Stiff</b>
DuPont® Chinex® Elite™ Series .....	10	<b>Extra Stiff</b>
XL® Elite™ Series .....	12	<b>Stiff</b>
Pro-Extra® Series.....	14	<b>Stiff</b>
Clearcut® Series.....	17	<b>Stiff</b>
XL® Series .....	19	<b>Medium Stiff</b>
◆ Black Bristle Series.....	24	<b>Medium Stiff</b>
◆ White Bristle Series.....	26	<b>Soft</b>
Nylox™ Black Series.....	28	<b>Soft</b>
Nylox Series .....	29	<b>Soft</b>
Syntox™ Series.....	32	<b>Extra Soft</b>
◆ Ox Hair Series .....	34	<b>Extra Soft</b>



## ROLLER COVERS

<b>How to Choose a Roller Cover</b> .....	<b>36</b>	<b>MATERIALS</b>
Ultra Finish® Series .....	37	<b>Woven</b>
WhiteDove™ Series.....	38	<b>Woven</b>
Contractor 1st™ Series.....	40	<b>Knit</b>
GoldenEagle™ Series.....	41	<b>Knit</b>
Marathon® Series.....	42	<b>Knit</b>
Colossus™ Series .....	43	<b>Woven</b>
Parrot™ Series.....	44	<b>Woven</b>
Non-Bevel™ .....	45	<b>Knit</b>
Roadrunner™ .....	45	<b>Knit</b>
Lambskin .....	45	<b>Knit</b>
Kits.....	46	



## TRAYS, STORAGE, FRAMES & POLES

Buckets & Trays .....	48
Liners .....	49
Pail & Pail Liners .....	50
Painter's Backpack .....	51
Frames & Power Lock® Pole .....	52
Miscellaneous Products .....	54

## SURFACE PREP TOOLS

Premium Series.....	56
Contractor Series.....	58

## FAUX FINISHING TOOLS

Brushes, Rollers & Sponges .....	60
----------------------------------	----

◆ for oil-based coatings only





# BRUSHES


*Expertly crafted for*  
**LASTING QUALITY**

Purdy® brushes are handcrafted in the U.S.A. by expert brushmakers, many with decades of experience. Each brushmaker learns from their peers for two years to gain all the knowledge it takes to be an expert. This dedication to crafting the highest quality brushes is reflected with a personal sticker on each brush, featuring the signature of the brushmaker who crafted it.

# How to CHOOSE A BRUSH

**Not All Brushes Are Created Equal.** All Purdy® brushes feature alderwood handles, resulting in a light, durable and maneuverable handle that absorbs sweat to keep hands dry.

With synthetic filaments and natural bristles sourced from the finest natural resources, Purdy is dedicated to the highest standard of quality.

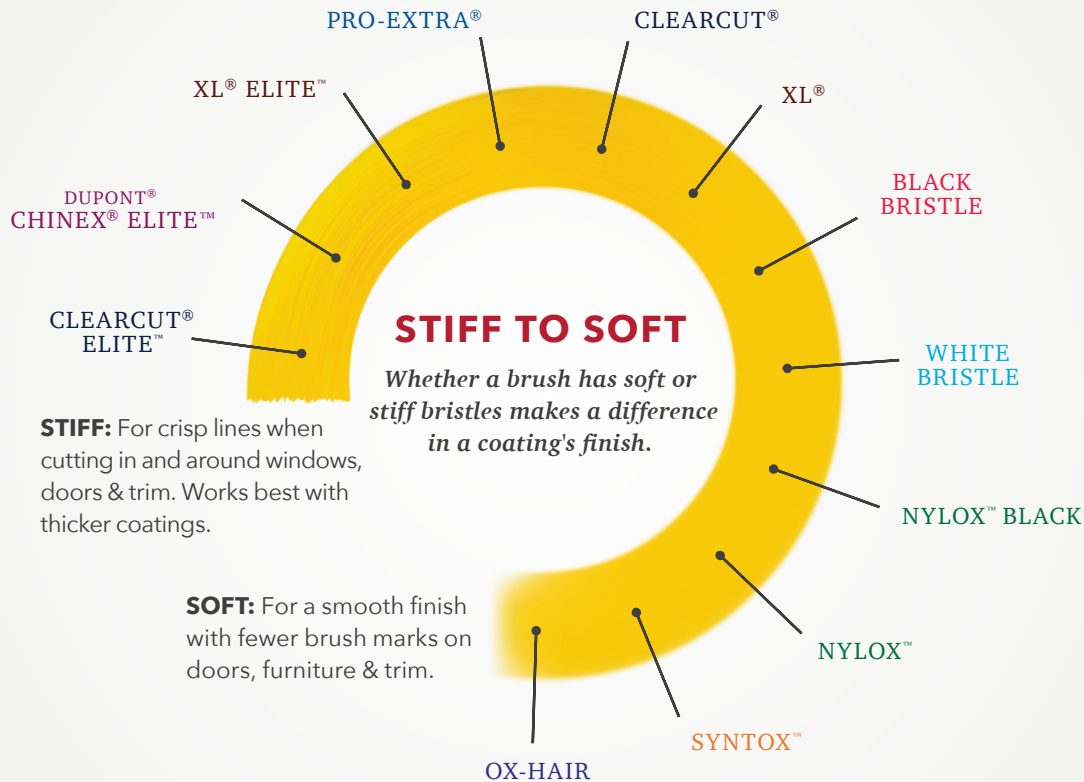

## WALL OR TRIM

Within each brush series, brushes are classified as either a wall or trim brush.

**Trim** brushes are for short strokes when you need more control, so they hold less paint.

**Wall** brushes are for longer strokes when you need to cover more surface area, so they have thicker bristles, or filaments, to hold more paint.

## SIZE & STYLE

**Small** size brushes or widths are good for detailed work on small spaces, like furniture spindles or mutton bars on windows.

**Angular** style brushes are also excellent for getting into tight corners.

**Large** size brushes are good for big surface areas, where a roller isn't ideal, such as fences or curved surfaces, like a boat hull.

**Flat** style brushes are great for laying off paint and coatings on continuous surfaces, as opposed to corners, like angular. However, both can be used for everything depending on your painting style.

## THE PERFECT HANDLE


The ideal brush handle varies based on how the painter prefers to hold a brush.

**Rattail:** Long and skinny to hold like a pencil.

**Fluted:** Square with cut-off corners to rest easier in a hand.

**Beavertail:** Thick and round for fitting nicely in the palm of a hand.

**Short:** Short in length for painting tight spots, where a longer handle would get in the way.

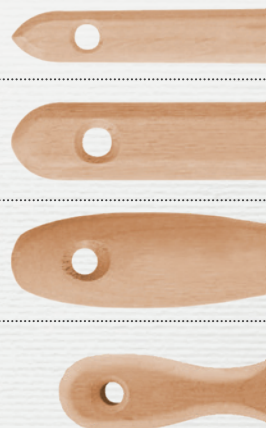

# CLEARCUT® ELITE™ Series

## AN EVOLUTION OF CLEARCUT WITH A STIFFER FORMULATION FOR LOW-VOC COATINGS.

**Coating Types:** Low-VOC and Latex Paints and Primers

**Project Types:** Precision Work Around Molding, Trim, Corners and Ceilings

**Filament Materials:** Tynex® Nylon / Orel® Polyester Blend



CLEARCUT  
ELITE  
ANGULAR  
PIP™

Wall Brush

Style  
**Angular**

Ferrule  
**Semi-oval Angle**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144424825	2 1/2"	1"	3 3/16"	2	716341406837
144424830	3"	1 1/8"	3 7/16"	2	716341406844

CLEARCUT  
ELITE  
BOW™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**




Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144064820	2"	9/16"	2 11/16"	6	716341406288



Style **Angular** | Ferrule **Round Edge** | Handle Style **Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152820	2"	9/16"	2 11/16"	6	716341406295
144152825	2 1/2"	5/8"	2 15/16"	6	716341406202
144152830	3"	5/8"	3 3/16"	6	716341406318

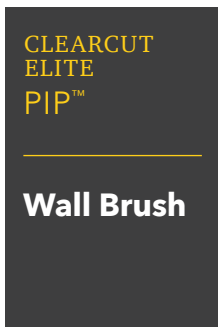

Style **Flat** | Ferrule **Semi-oval** | Handle Style **Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144324830	3"	1 1/8"	3 11/16"	6	716341406325



CLEARCUT®  
ELITE™  
SPRIG™

---

**Trim Brush**

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380830	3"	5/8"	3 3/16"	6	716341406899

CLEARCUT  
ELITE  
SWAN™

---

**Wall Brush**

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400830	3"	7/8"	3 7/16"	6	716341406332

# DUPONT® CHINEX® ELITE™ Series

## EXTREMELY DURABLE & CLEANABLE

**Coating Types:** Heavy Bodied and Low VOC Paints

**Project Types:** Textured Surfaces like Stucco, Rough Sawn Lumber and Brick Work

**Filament Materials:** 100% DuPont Chinex Nylon



DUPONT  
CHINEX ELITE  
BOW™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144553025	2 1/2"	5/8"	2-15/16"	6	716341010027

DUPONT  
CHINEX ELITE  
DALE™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144580920	2"	7/16"	2 7/16"	6	716341010645
144580925	2 1/2"	1/2"	2 11/16"	6	716341010614

DUPONT  
CHINEX ELITE  
GLIDE™

**Trim Brush**

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144552920	2"	9/16"	2 11/16"	6	716341010638
144552925	2 1/2"	5/8"	2 15/16"	6	716341010591
144552930	3"	5/8"	3 3/16"	6	716341009960

DUPONT  
CHINEX® ELITE™  
SPRIG™

**Trim Brush**

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144581925	2 1/2"	5/8"	2 15/16"	6	716341010652
144580930	3"	5/8"	3 3/16"	6	716341009991

DUPONT  
CHINEX ELITE  
SWAN™

**Wall Brush**

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144500930	3"	7/8"	3 7/16"	6	716341009984

# XL<sup>®</sup> ELITE<sup>™</sup> Series

## VERSATILITY OF XL WITH IMPROVED PERFORMANCE IN HEAVIER COATINGS & INCREASED CLEANABILITY.

**Coating Types:** Low-VOC, Latex and Oil-Based Paints, Primers and Stains

**Project Types:** Walls, Ceilings and Trim

**Filament Materials:** DuPont<sup>®</sup> Chinex<sup>®</sup> Nylon/Orel<sup>®</sup> Polyester Blend



XL ELITE  
DALE<sup>™</sup>

---

Trim Brush



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144080510	1"	5/16"	1 15/16"	6	716341403294
144080515	1 1/2"	3/8"	2 3/16"	6	716341403300
144080520	2"	7/16"	2 7/16"	6	716341403317
144080525	2 1/2"	1/2"	2 11/16"	6	716341403324


XL ELITE  
GLIDE<sup>™</sup>

---

Trim Brush



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152520	2"	9/16"	2 11/16"	6	716341403270
144152525	2 1/2"	5/8"	2 15/16"	6	716341403287
144152530	3"	5/8"	3 3/16"	6	716341403348

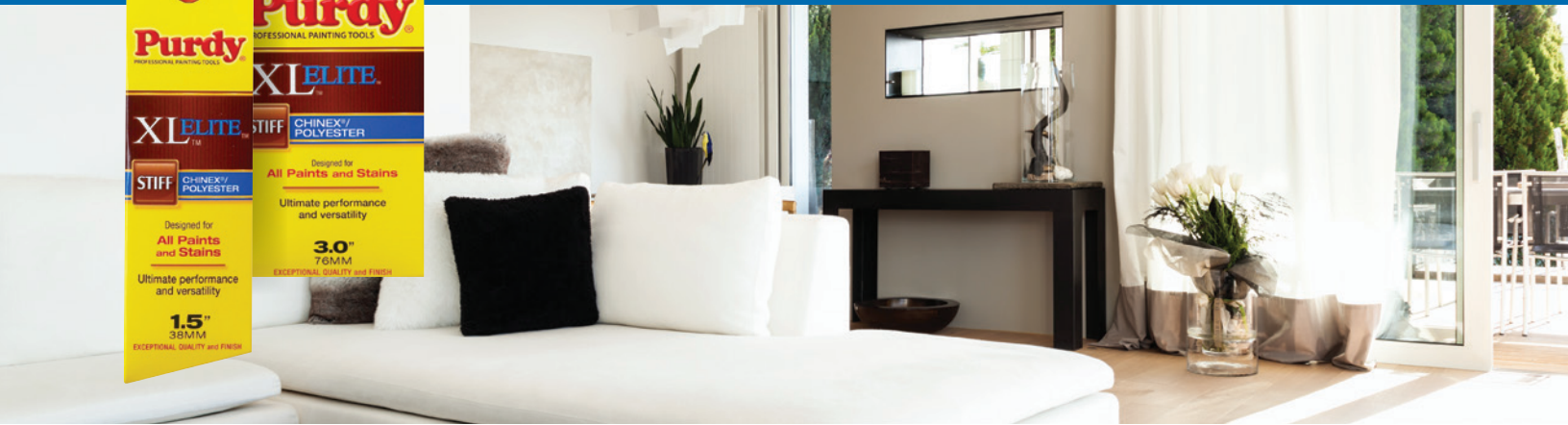

XL ELITE™  
SPRIG™  
  
**Trim Brush**

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380510	1"	7/16"	2 3/16"	6	716341095901
144380515	1 1/2"	1/2"	2 7/16"	6	716341404246
144380520	2"	9/16"	2 11/16"	6	716341404253
144380525	2 1/2"	5/8"	2 15/16"	6	716341403966
144380530	3"	5/8"	3 13/16"	6	716341403331

# PRO-EXTRA® Series

## HOLDS MORE PAINT TO GET THE JOB DONE FASTER.

**Coating Types:** Latex Paints and Primers

**Project Types:** Drywall, Siding Board, Brick and Concrete Block

**Filament Materials:** DuPont® Chinex® Nylon / Tynex® Nylon / Orel® Polyester Blend



PRO-EXTRA  
DALE™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144080720	2"	7/16"	2 11/16"	6	716341045135
144080725	2 1/2"	1/2"	2 15/16"	6	716341016043
144080730	3"	1/2"	3 3/16"	6	716341045128

PRO-EXTRA  
ELASCO™

Trim Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144100725	2 1/2"	3/4"	3 7/16"	6	716341010553
144100730	3"	3/4"	3 11/16"	6	716341045111

PRO-EXTRA®  
GLIDE™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152720	2"	9/16"	2 15/16"	6	716341015930
144152725	2 1/2"	5/8"	3 3/16"	6	716341015947
144152730	3"	5/8"	3 7/16"	6	716341015954
144152735	3 1/2"	11/16"	3 5/16"	6	716341350505

PRO-EXTRA  
MONARCH™

Wall Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144234710	1"	5/8"	2 15/16"	6	716341000523
144234715	1 1/2"	5/8"	3 3/16"	6	716341000530
144234720	2"	3/4"	3 7/16"	6	716341000547
144234730	3"	7/8"	3 7/16"	6	716341000554

PRO-EXTRA  
MOOSE™

Wall Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Shasta**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144232730	3"	13/16"	3 11/16"	6	716341350956

# PRO-EXTRA® Series


PRO-EXTRA  
PIP™

Wall Brush

Style  
**Flat**

Ferrule  
**Semi-oval**

Handle Style  
**Beavertail**

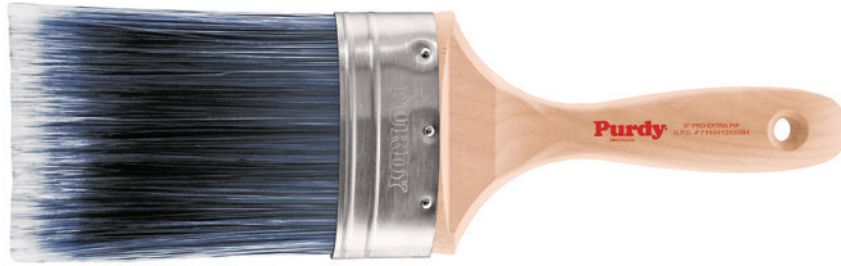

Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144324730	3"	1 1/8"	3 15/16"	6	716341353094

PRO-EXTRA  
SPRIG™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380730	3"	5/8"	3 7/16"	6	716341045098

PRO-EXTRA  
SWAN™

Wall Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400730	3"	7/8"	3 11/16"	6	716341044954
144400740	4"	7/8"	4 3/16"	6	716341044978

# CLEARCUT® Series

## DESIGNED TO CREATE PRECISE LINES FOR CUTTING IN.

**Coating Types:** Latex Paints and Primers

**Surface Types:** Precision Work Around Molding, Trim, Corners and Ceilings

**Filament Materials:** Tynex® Nylon / Orel® Polyester Blend



CLEARCUT  
DALE™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144080115	1 1/2"	3/8"	2 3/16"	6	716341401078

CLEARCUT  
GLIDE™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152120	2"	9/16"	2 11/16"	6	716341401085
144152125	2 1/2"	5/8"	2 15/16"	6	716341401092
144152130	3"	5/8"	3 3/16"	6	716341401108



Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380130	3"	5/8"	3 3/16"	6	716341401115



Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400130	3"	7/8"	3 7/16"	6	716341401122

# XL® Series

## OUR MOST VERSATILE BRUSH FOR ALL TYPES OF ENVIRONMENTS.

**Coating Types:** Latex and Oil-Based Paints, Primers and Stains

**Surface Types:** Walls, Ceilings and Trim

**Filament Materials:** Tynex® Nylon/Orel® Polyester Blend



XL  
BLUE  
HERON™ B.T.™


---

**Trim Brush**

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**

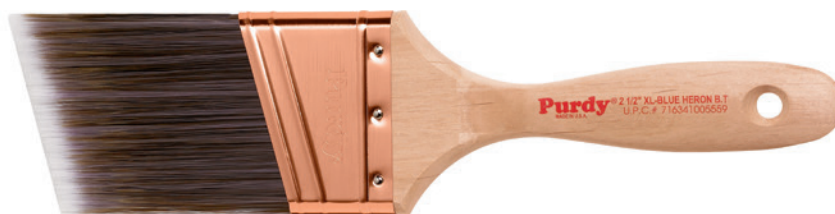

Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144060925	2 1/2"	5/8"	2 15/16"	6	716341005559

XL  
BOW™

---

**Trim Brush**

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144064320	2"	9/16"	2 11/16"	6	716341006105
144064325	2 1/2"	5/8"	2 15/16"	6	716341006204
144064330	3"	5/8"	3 3/16"	6	716341006303

# XL® Series

XL  
CUB™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Short**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144153320	2"	9/16"	2 11/16"	6	716341352073
144153325	2 1/2"	5/8"	2 15/16"	6	716341352066

XL  
DALE™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144080310	1"	5/16"	1 15/16"	6	716341008406
144080315	1 1/2"	3/8"	2 3/16"	6	716341008505
144080320	2"	7/16"	2 7/16"	6	716341008604
144080325	2 1/2"	1/2"	2 11/16"	6	716341008703
144080330	3"	1/2"	2 15/16"	6	716341008802

XL  
ELASCO™

Trim Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144100320	2"	11/16"	2 15/16"	6	716341010300
144100325	2 1/2"	3/4"	3 3/16"	6	716341010409
144100330	3"	3/4"	3 7/16"	6	716341010508

XL®  
GLIDE™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152315	1 1/2"	1/2"	2 7/16"	6	716341015503
144152320	2"	9/16"	2 11/16"	6	716341015602
144152325	2 1/2"	5/8"	2 15/16"	6	716341015701
144152330	3"	5/8"	3 3/16"	6	716341015800
144152335	3 1/2"	11/16"	3 3/8"	6	716341015909

XL  
MOOSE™

Wall Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Shasta**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144232330	3"	13/16"	3 7/16"	6	716341023102

XL  
NYLONIA™

Wall Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144264330	3"	1"	3 15/16"	6	716341025601

# XL® Series

XL  
PIP™

Wall Brush

Style  
**Flat**

Ferrule  
**Semi-oval**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144324325	2 1/2"	1"	3 7/16"	6	716341032104
144324330	3"	1 1/8"	3 11/16"	6	716341032203
144324335	3 1/2"	1 1/4"	3 15/16"	6	716341032302

XL  
SPRIG™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380320	2"	9/16"	2 11/16"	6	716341040505
144380325	2 1/2"	5/8"	2 15/16"	6	716341040604
144380330	3"	5/8"	3 3/16"	6	716341040703
144380335	3 1/2"	11/16"	3 7/16"	6	716341040802
144380340	4"	11/16"	3 11/16"	6	716341040901

XL  
SWAN™

Wall Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400325	2 1/2"	3/4"	3 3/16"	6	716341095758
144400330	3"	7/8"	3 7/16"	6	716341044404
144400335	3 1/2"	7/8"	3 11/16"	6	716341044503
144400340	4"	7/8"	3 15/16"	6	716341044602

XL®  
HIGH  
CAPACITY

Wall Brush

Style  
**Angled**

Ferrule  
**Stadium**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144424420	2"	3/4"	2 15/16"	3	716341009021
144424425	2.5"	7/8"	3 3/16"	3	716341009038
144424430	3"	7/8"	3 7/16"	3	716341009045

XL  
MULTI-  
PACKS

Description	Item No.	Pkg. Qty.	UPC
3 Pack: 1" XL Dale™, 1 1/2" XL Glide™, 2" XL Sprig™	140853100	8	716341400231
3 Pack: 1" XL Dale, 1 1/2" XL Glide, 2" XL Sprig, Brush Comb	140853210	16	716341404307



# BLACK BRISTLE Series

**HOLDS MORE COATING THAN ANY OTHER NATURAL MATERIAL, WITH STIFFER BRISTLES FOR THICKER COATINGS.**

**Coating Types:** Oil-Based Paints, Stains, Epoxy and Spar Urethanes

**Project Types:** Bare Wood Floors, Furniture, Doors, Cabinets and Concrete

**Filament Materials:** 100% Natural Black Bristle



BLACK BRISTLE  
ADJUTANT™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144024010	1"	5/16"	2 1/8"	6	716341000202
144024015	1 1/2"	3/8"	2 3/8"	6	716341000301
144024020	2"	7/16"	2 5/8"	6	716341000400
144024025	2 1/2"	1/2"	2 7/8"	6	716341000509
144024030	3"	1/2"	3 1/8"	6	716341000608

BLACK BRISTLE  
EXTRA  
OREGON™

Trim Brush

Style  
**Angular**


Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144116015	1 1/2"	1/2"	2 3/8"	6	716341011604
144116020	2"	9/16"	2 5/8"	6	716341011703
144116025	2 1/2"	5/8"	2 7/8"	6	716341011802
144116030	3"	5/8"	3 1/8"	6	716341011901

PICKS UP AND RELEASES  
MORE STAIN

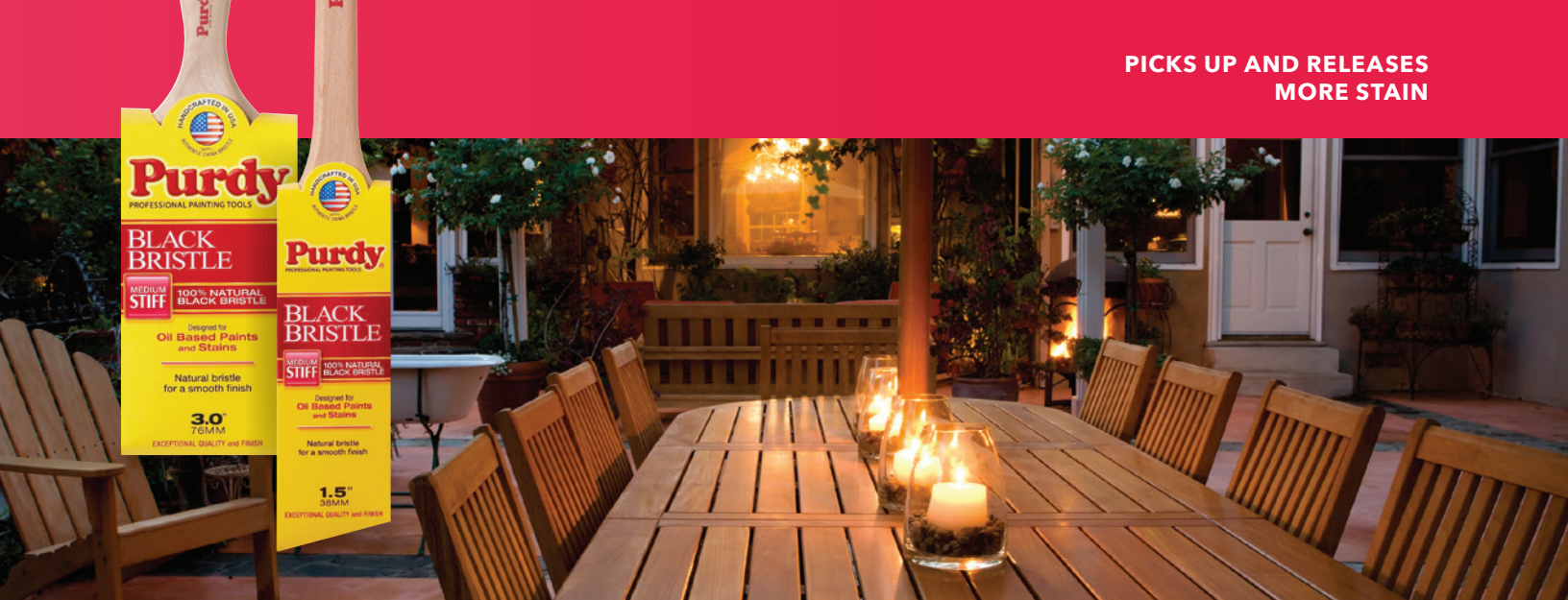

BLACK BRISTLE  
SPRIG™

---

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380030	3"	5/8"	3 1/8"	6	716341039608

BLACK BRISTLE  
SWAN™

---

Wall Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400030	3"	7/8"	3 3/8"	6	716341043803
144400040	4"	7/8"	3 7/8"	6	716341044008

# WHITE BRISTLE Series

## THE MOST VERSATILE, NATURAL BRISTLE BRUSH FOR OIL-BASED COATINGS & PROJECTS.

**Coating Types:** Oil-Based Stains, Polyurethanes, Wood Conditioners, Lacquer Thinners and Clears

**Project Types:** Decks, Siding, Floors, Furniture and Antiques

**Filament Materials:** 100% Natural White Bristle



WHITE BRISTLE  
ADJUTANT™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144024415	1 1/2"	3/8"	2 3/8"	6	716341000905
144024420	2"	7/16"	2 5/8"	6	716341001001
144024425	2 1/2"	1/2"	2 7/8"	6	716341001100
144024430	3"	1/2"	3 1/8"	6	716341001209

WHITE BRISTLE  
EXTRA  
OREGON™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144116415	1 1/2"	1/2"	2 3/8"	6	716341012106
144116420	2"	9/16"	2 5/8"	6	716341012205
144116425	2 1/2"	5/8"	2 7/8"	6	716341012304



WHITE BRISTLE  
PLATO™


---

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Dowel**

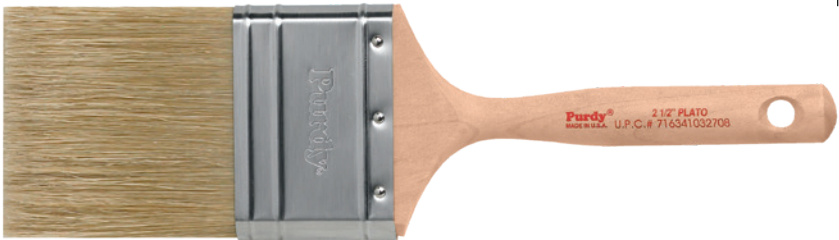

Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144332030	3"	5/8"	2 7/8"	6	716341032807

WHITE BRISTLE  
SPRIG™

---

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380420	2"	9/16"	2 7/8"	6	716341041007
144380425	2 1/2"	5/8"	2 7/8"	6	716341041106
144380430	3"	5/8"	3 1/8"	6	716341041205

# NYLOX™ BLACK Series

## EXTRA DURABLE BRUSH THAT LEAVES A VERY SMOOTH FINISH.

**Coating Types:** Latex Paints and Primers

**Project Types:** Interior Windows, Doors and Trim

**Filament Materials:** 100% Black Nylon



NYLO-PEACOCK™

Trim Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144316125	2 1/2"	3/4"	3 7/16"	6	716341031008
144316130	3"	3/4"	3 11/16"	6	716341031107

NYLO-SCOTER™

Wall Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144360130	3"	7/8"	3 7/16"	6	716341036904

# NYLOX™ Series

## FOR AN ULTRA-SMOOTH FINISH ON DOORS & TRIM.

**Coating Types:** Semi-Gloss to High Gloss Latex Paints

**Project Types:** Interior Windows, Cabinets, Doors and Trim

**Filament Materials:** 100% Dyed Nylon



NYLOX  
DALE™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144080210	1"	5/16"	1 15/16"	6	716341007805
144080215	1 1/2"	3/8"	2 3/16"	6	716341007904
144080220	2"	7/16"	2 7/16"	6	716341008000
144080225	2 1/2"	1/2"	2 11/16"	6	716341008109
144080230	3"	1/2"	2 15/16"	6	716341008208

NYLOX  
ELASCO™

Trim Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144100220	2"	11/16"	2 15/16"	6	716341010003
144100225	2 1/2"	3/4"	3 3/16"	6	716341010102
144100230	3"	3/4"	3 7/16"	6	716341010201

# NYLOX™ Series


NYLOX  
GLIDE™

Trim Brush

Style  
**Angular**

Ferrule  
**Round Edge**

Handle Style  
**Fluted**

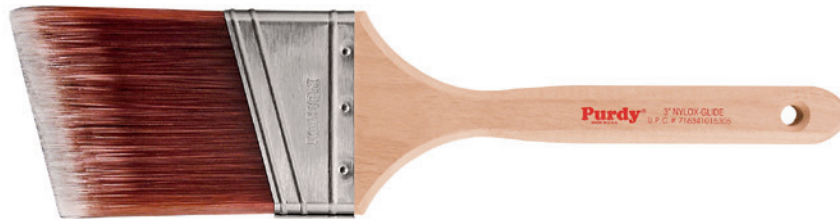

Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144152215	1 1/2"	1/2"	2 7/16"	6	716341015008
144152220	2"	9/16"	2 11/16"	6	716341015107
144152225	2 1/2"	5/8"	2 15/16"	6	716341015206
144152230	3"	5/8"	3 3/16"	6	716341015305
144152235	3 1/2"	11/16"	3 3/8"	6	716341015404

NYLOX  
MODE™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Dowel**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144228230	3"	5/8"	2 15/16"	6	716341021702
144228235	3 1/2"	11/16"	3 3/16"	6	716341021801

NYLOX  
MOOSE™

Wall Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Shasta**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144232225	2 1/2"	13/16"	3 3/16"	6	716341022709
144232230	3"	13/16"	3 7/16"	6	716341022808

NYLOX™  
PIP™

Wall Brush

Style  
**Flat**

Ferrule  
**Semi-Oval**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144324225	2 1/2"	1"	3 7/16"	6	716341031800

NYLOX™  
SPRIG™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144380220	2"	9/16"	2 11/16"	6	716341040000
144380225	2 1/2"	5/8"	2 15/16"	6	716341040109
144380230	3"	5/8"	3 3/16"	6	716341040208

NYLOX™  
SWAN™

Wall Brush

Style  
**Flat**

Ferrule  
**Square Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144400230	3"	7/8"	3 7/16"	6	716341044107
144400240	4"	7/8"	3 15/16"	6	716341044305

# SYNTOX™ Series

## A MORE DURABLE ALTERNATIVE TO NATURAL OX HAIR.

**Coating Types:** Latex and Oil-Based Paints, Stains, Clears, Polyurethanes and Varnishes

**Project Types:** Interior Surfaces – Wood Floors, Furniture, Cabinets, Doors and Trim

**Filament Materials:** Tynex® Nylon / DuPont® Chinex® Nylon Blend



SYNTOX  
ANGULAR™

---

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144403620	2"	7/16"	2 7/16"	6	716341000226
144403625	2 1/2"	1/2"	2 11/16"	6	716341000233
144403630	3"	1/2"	2 15/16"	6	716341000240

SYNTOX  
FLAT™

---

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Thin Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144402620	2"	7/16"	2 11/16"	6	716341000257
144402625	2 1/2"	1/2"	2 11/16"	6	716341000264

EVOLUTION OF NATURAL BRISTLE FOR VERSATILITY  
WITH WATER- & OIL-BASED COATINGS



SYNTOX™  
SPRIG™

---

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Beavertail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144404630	3"	5/8"	3 3/16"	6	716341350581

# OX HAIR Series

## THE SOFTEST, NATURAL BRISTLE FOR A GLASS-LIKE FINISH.

**Coating Types:** Oil-Based Paints, Stains, Clears, Polyurethanes and Varnishes

**Project Types:** Marine Woodwork, Furniture and Fine Artistry

**Filament Materials:** Ox Hair/White Bristle Blend



OX-O-  
ANGULAR™

Trim Brush

Style  
**Angular**

Ferrule  
**Square Edge**

Handle Style  
**Rattail**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144296015	1 1/2"	3/8"	2 1/8"	6	716341028305
144296020	2"	7/16"	2 1/8"	6	716341028404
144296025	2 1/2"	1/2"	2 3/8"	6	716341028503
144296030	3"	1/2"	2 5/8"	6	716341028602

OX-O-  
THIN™

Trim Brush

Style  
**Flat**

Ferrule  
**Round Edge**

Handle Style  
**Thin Fluted**



Item No.	Size	Thickness	Length	Pkg. Qty.	UPC
144300020	2"	7/16"	2 3/8"	6	716341029302
144300025	2 1/2"	1/2"	2 5/8"	6	716341029401
144300030	3"	1/2"	2 5/8"	6	716341029500



# ROLLER COVERS


*A full line to cover*  
**EVERY JOB**

Producing roller covers that result in less spatter, even release or a lint-free finish has been part of Purdy's dedication to innovation. Purdy® has developed exclusive, proprietary manufacturing processes to produce high-quality products for professionals who use them to earn their livelihood. After each roller cover is wound, they are double vacuumed to reduce potential fiber shedding and then hand inspected to ensure they meet Purdy's high-quality standards.

# How to CHOOSE A ROLLER COVER

**Keep on rolling.** Purdy® roller covers feature durable polypropylene cores that are resistant to all paints, stains and solvents, extending their life. For increased durability, thermal bond technology winds roller cover fabric to the

core with a perfect spiral seam for smooth rolling. Ultra-durable roller cover cores eliminate bending, allowing even contact with the wall. No matter the project, there is a Purdy roller cover for exceptional results.

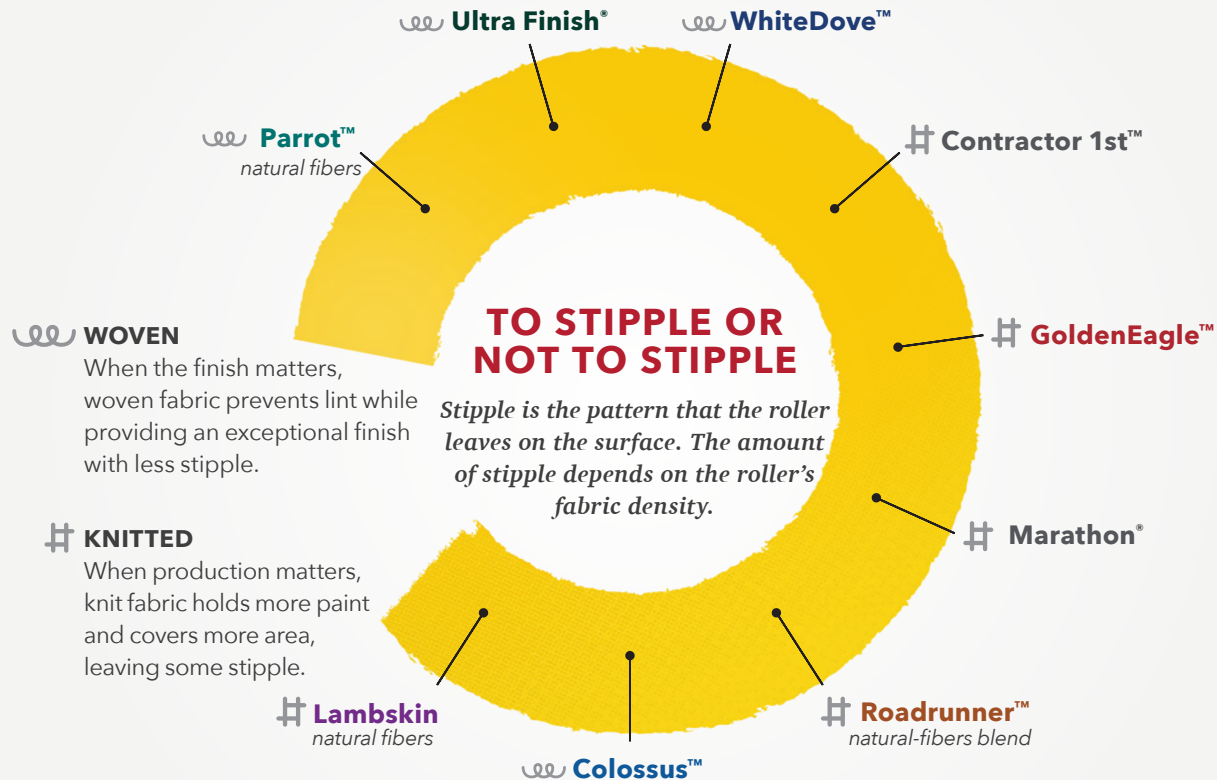


## NAP SELECTOR

The nap size is determined by the surface you are painting.


**1/4" nap**  
metal doors, cabinets & trim



**3/8" nap**  
walls and ceilings

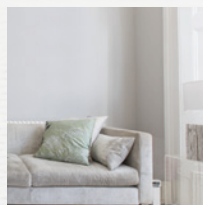

**1/2" nap**  
textured walls, decks and concrete

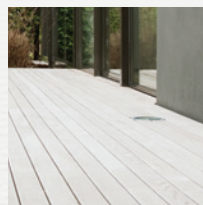

**3/4" nap**  
textured ceilings, stucco & masonry



**1"- 1 1/4" nap**  
brick and masonry block



## WE'VE GOT YOU COVERED

The size of a paint project is important, and so is the roller cover.

Using the same roller cover fabric and nap size is important to ensure a **matching stipple** on the final finish. Whether using a mini roller cover to paint behind an appliance or an 18" roller cover for today's large open floor plans, you are sure to get a beautiful, consistent finish with Purdy.

Purdy also offers two different mini roller cover styles that are made from the same materials as the standard roller covers: **wire mini**, which have a smaller wire shaped core, and **jumbo mini**, featuring a slightly larger, more traditional roller core.

# Ultra Finish® Series

## PREMIUM MICROFIBER FOR AN ULTRA-SMOOTH FINISH.

**Coating Type:** Latex and Oil-Based Paints

**Sheen Type:** Semi-Gloss, Gloss and High Gloss

**Project Type:** Drywall, Doors and Floors

**Material:** Woven Premium Microfiber



### Ultra Finish SINGLE ROLLER COVERS

Item No.	Size	Nap	Core	Case	UPC
140678092	9"	3/8"	1 1/2"	15	716341403096
140678093	9"	1/2"	1 1/2"	15	716341403102
140678142	14"	3/8"	1 1/2"	6	716341406226
140678143	14"	1/2"	1 1/2"	6	716341406134
140678182	18"	3/8"	1 1/2"	6	716341008833
140678183	18"	1/2"	1 1/2"	6	716341008840



### Ultra Finish MULTI-PACKS

Description	Item No.	Size	Nap	Core	Case	UPC
3 Pack	14B878000	9"	3/8"	1 1/2"	64	716341403225
3 Pack	14F878000	9"	3/8"	1 1/2"	9	716341403225
2 Pack	140878200	9"	1/2"	1 1/2"	12	716341404277



### Ultra Finish JUMBO MINI ROLLER COVERS

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack	140624052	4 1/2"	3/8"	3/4"	6	716341403942
2 Pack	140624053	4 1/2"	1/2"	3/4"	6	716341404130
2 Pack	14G626052	6 1/2"	3/8"	3/4"	3	716341403959
2 Pack	140626053	6 1/2"	1/2"	3/4"	6	716341404123



# WhiteDove™ Series

## A VERSATILE COVER FOR A SMOOTH, LINT-FREE FINISH.

**Coating Type:** Latex and Oil-Based Paints, Primers Stains and Clears

**Sheen Type:** All

**Project Type:** Drywall, Ceilings and Floors

**Materials:** Woven Dralon®



**WhiteDove  
SINGLE  
ROLLER  
COVERS**




Item No.	Size	Nap	Core	Case	UPC
140786104	4"	3/8"	1 1/2"	24	716341088408
140662071	7"	1/4"	1 1/2"	24	716341075507
140670072	7"	3/8"	1 1/2"	24	716341078508
140670073	7"	1/2"	1 1/2"	24	716341078607
140672074	7"	3/4"	1 1/2"	24	716341079505
144662091	9"	1/4"	1 1/2"	15	716341075606
144670092	9"	3/8"	1 1/2"	15	716341078706
14B670092	9"	3/8"	1 1/2"	191	716341078706
144670093	9"	1/2"	1 1/2"	15	716341078805
14B670093	9"	1/2"	1 1/2"	167	716341078805
14G672094	9"	3/4"	1 1/2"	10	716341079604
140670122	12"	3/8"	1 1/2"	10	716341401566
14A670142	14"	3/8"	1 1/2"	6	716341078904
14A670143	14"	1/2"	1 1/2"	6	716341406578
144662181	18"	1/4"	1 1/2"	6	716341075804
144670182	18"	3/8"	1 1/2"	6	716341079109
144670183	18"	1/2"	1 1/2"	6	716341079208
144670184	18"	3/4"	1 1/2"	6	716341353155

**WhiteDove  
MULTI-  
PACKS**



Description	Item No.	Size	Nap	Core	Case	UPC
3 Pack	14B863000	9"	3/8"	1 1/2"	63	716341100025
3 Pack	140864000	9"	1/2"	1 1/2"	44	716341000288
3 Pack	14E863000	9"	3/8"	1 1/2"	9	716341100025
3 Pack	14E864000	9"	1/2"	1 1/2"	8	716341000288
6 Pack	14D866000	9"	3/8"	1 1/2"	8	716341009922

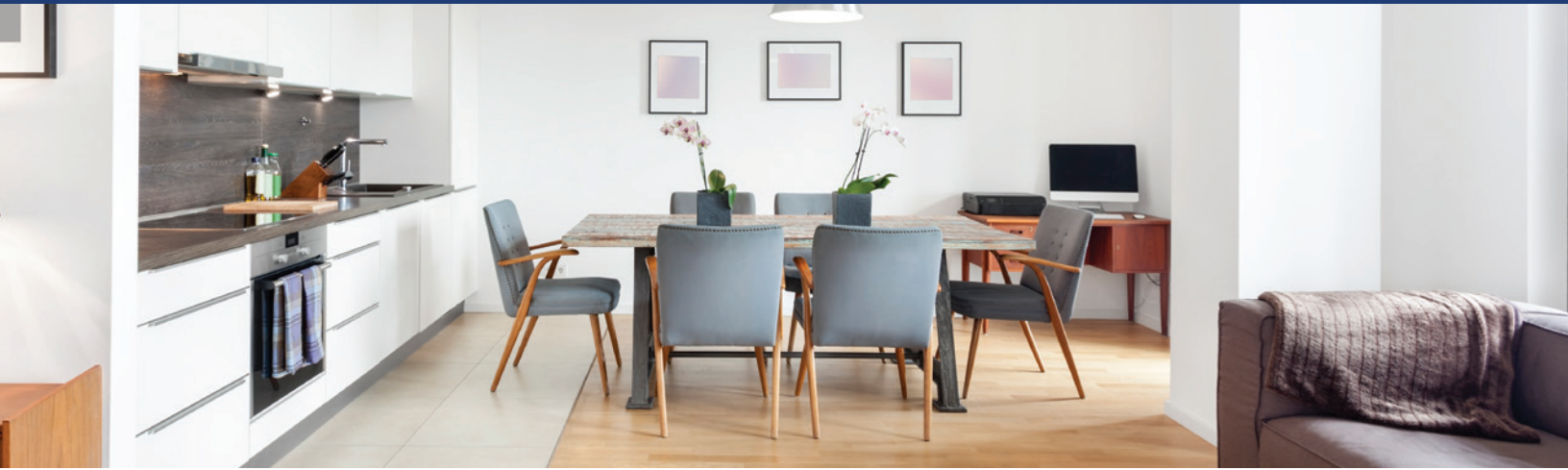

**WhiteDove™**  
**Pro-Extra\*\***  
**SINGLE**  
**ROLLER**  
**COVERS**

Item No.	Size	Nap	Core	Case	UPC
140671092	9"	3/8"	1 3/4"	15	716341351090
140671093	9"	1/2"	1 3/4"	15	716341351106

\*Pro-Extra covers require a 1 3/4" frame.



**WhiteDove**  
**MINI**  
**ROLLER**  
**COVERS**

**JUMBO**

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Jumbo	140624010	4 1/2"	1/4"	3/4"	6	716341402587
2 Pack Jumbo	14G624012	4 1/2"	3/8"	3/4"	3	716341402594
6 Pack Jumbo	140624612	4 1/2"	3/8"	3/4"	6	716341402969
2 Pack Jumbo	14G624013	4 1/2"	1/2"	3/4"	3	716341402600
2 Pack Jumbo	140626010	6 1/2"	1/4"	3/4"	6	716341402662
2 Pack Jumbo	14G626012	6 1/2"	3/8"	3/4"	3	716341402679
2 Pack Jumbo	14G626013	6 1/2"	1/2"	3/4"	3	716341402686



**WIRE**

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Wire	140606042	4"	3/8"	1/2"	6	716341401801
2 Pack Wire	140606044	4"	1/2"	1/2"	6	716341401818
2 Pack Wire	14G605060	6 1/2"	1/4"	1/2"	3	716341402891
2 Pack Wire	14G605062	6 1/2"	3/8"	1/2"	3	716341402907
2 Pack Wire	140605064	6 1/2"	1/2"	1/2"	6	716341402921

# Contractor 1<sup>st</sup>™ Series

## GOOD PAINT PICKUP & RELEASE AT A GREAT VALUE.

**Coating Type:** Latex and Oil-Based Paints and Primers

**Sheen Type:** Flat, Eggshell and Satin

**Project Type:** Drywall, Ceilings and Concrete

**Materials:** Knitted Medium Density Polyester



**Contractor 1<sup>st</sup>**  
SINGLE  
ROLLER  
COVERS

Item No.	Size	Nap	Core	Case	UPC
14B688092	9"	3/8"	1 1/2"	191	716341098834
144688092	9"	3/8"	1 1/2"	15	716341098834
144688093	9"	1/2"	1 1/2"	15	716341098841
14B688093	9"	1/2"	1 1/2"	167	716341098841
144688094	9"	3/4"	1 1/2"	15	716341098858
144688095	9"	1"	1 1/2"	12	716341098865
144688182	18"	3/8"	1 1/2"	6	716341400002
144688183	18"	1/2"	1 1/2"	6	716341400019
144688184	18"	3/4"	1 1/2"	6	716341400026

**Contractor 1<sup>st</sup>**  
MULTI-  
PACKS



Description	Item No.	Size	Nap	Core	Case	UPC
3 Pack	140867000	9"	3/8"	1 1/2"	64	716341351182
3 Pack	14C867000	9"	3/8"	1 1/2"	40	716341351182
3 Pack	14D876003	9"	3/8"	1 1/2"	32	716341010966
3 Pack	14E867000	9"	3/8"	1 1/2"	9	716341351182

# GoldenEagle™ Series

## DESIGNED TO HOLD & RELEASE MORE PAINT.

**Coating Type:** Latex and Oil-Based Paints and Primers

**Sheen Type:** Flat, Eggshell and Satin

**Project Type:** Drywall, Decks and Masonry

**Material:** Knitted High Density Polyester



### GoldenEagle SINGLE ROLLER COVERS



Item No.	Size	Nap	Core	Case	UPC
140786604	4"	1/2"	1 1/2"	24	716341088552
140608073	7"	1/2"	1 1/2"	24	716341065201
144608092	9"	3/8"	1 1/2"	15	716341351052
144608093	9"	1/2"	1 1/2"	15	716341065607
144608094	9"	3/4"	1 1/2"	15	716341065706
144608095	9"	1"	1 1/2"	12	716341065805
144608097	9"	1 1/4"	1 1/2"	12	716341065904
144608183	18"	1/2"	1 1/2"	6	716341066406
144608184	18"	3/4"	1 1/2"	6	716341066505

### GoldenEagle MULTI-PACKS



Description	Item No.	Size	Nap	Core	Case	UPC
3 Pack	14E868100	9"	3/8"	1 1/2"	8	716341010980
3 Pack	140868100	9"	3/8"	1 1/2"	64	716341403157
2 Pack	14C868000	9"	1/2"	1 1/2"	12	716341400200

### GoldenEagle MINI ROLLER COVERS



#### JUMBO

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Jumbo	140624022	4 1/2"	3/8"	3/4"	6	716341402617
2 Pack Jumbo	140624023	4 1/2"	1/2"	3/4"	6	716341402624
2 Pack Jumbo	140626022	6 1/2"	3/8"	3/4"	6	716341402693
2 Pack Jumbo	14G626023	6 1/2"	1/2"	3/4"	3	716341402709
2 Pack Jumbo	14G626024	6 1/2"	3/4"	3/4"	3	716341402716

#### WIRE

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Wire	140605063	6 1/2"	1/2"	1/2"	6	716341402914
2 Pack Wire	140605065	6 1/2"	3/4"	1/2"	6	716341402938

# Marathon® Series

## OUR MOST DURABLE ROLLER COVER THAT WON'T MAT DOWN ON LARGE PAINT JOBS.



**Coating Type:** Latex and Oil-Based Paints and Primers

**Sheen Type:** Flat, Eggshell, and Satin

**Project Type:** Drywall, Concrete, Masonry and Decks

**Materials:** Knitted High Density Nylon / Polyester

### Marathon SINGLE ROLLER COVERS



Item No.	Size	Nap	Core	Case	UPC
144786604	4"	1/2"	1 1/2"	24	716341404611
144602073	7"	1/2"	1 1/2"	24	716341404628
144602092	9"	3/8"	1 1/2"	15	716341404635
144602093	9"	1/2"	1 1/2"	15	716341404642
144602094	9"	3/4"	1 1/2"	15	716341404659
144602994	9" Non-Bevel	3/4"	1 1/2"	15	716341406103
14G602097	9"	1 1/4"	1 1/2"	10	716341404666
144602142	14"	3/8"	1 1/2"	6	716341008826
14A602143	14"	1/2"	1 1/2"	6	716341404727
14A602144	14"	3/4"	1 1/2"	6	716341406110
144602182	18"	3/8"	1 1/2"	6	716341406127
144602183	18"	1/2"	1 1/2"	6	716341404734
144602184	18"	3/4"	1 1/2"	6	716341404741
144602185	18"	1 1/4"	1 1/2"	4	716341008819

### Marathon MULTI-PACKS



Description	Item No.	Size	Nap	Core	Case	UPC
3 Pack	14F861000	9"	3/8"	1 1/2"	9	716341404673
3 Pack	14B861100	9"	1/2"	1 1/2"	25	716341404680
3 Pack	14F861100	9"	1/2"	1 1/2"	8	716341404680
6 Pack	14D861603	9"	1/2"	1 1/2"	8	716341009939
110 Pack	14X602092	9"	3/8"	1 1/2"	1	716341008949
100 Pack	14X602093	9"	1/2"	1 1/2"	1	716341406141
90 Pack	14X602094	9"	3/4"	1 1/2"	1	716341406271

### Marathon MINI ROLLER COVERS



#### JUMBO

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Jumbo	14G624062	4 1/2"	3/8"	3/4"	3	716341404550
2 Pack Jumbo	14G624063	4 1/2"	1/2"	3/4"	3	716341404567
2 Pack Jumbo	14G624064	4 1/2"	3/4"	3/4"	3	716341404574
2 Pack Jumbo	14G626063	6 1/2"	1/2"	3/4"	3	716341404598

#### WIRE

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack Wire	144605063	6 1/2"	1/2"	1/2"	6	716341404529
2 Pack Wire	144605064	6 1/2"	3/4"	1/2"	6	716341404536

## EXTREMELY DURABLE & DESIGNED FOR REPEATED USE.

**Coating Type:** Latex and Oil-Based Paints and Primers

**Sheen Type:** Flat, Eggshell and Satin

**Project Type:** Drywall, Masonry, Stucco and Rough Wood

**Materials:** Woven 100% Polyamide



### Colossus SINGLE ROLLER COVERS



Item No.	Size	Nap	Core	Case	UPC
144630093	9"	1/2"	1 1/2"	15	716341400101
144630094	9"	3/4"	1 1/2"	15	716341400118
144630095	9"	1"	1 1/2"	12	716341400125
140630125	12"	1"	1 1/2"	10	716341401573
14A630144	14"	3/4"	1 1/2"	6	716341404161
144630183	18"	1/2"	1 1/2"	6	716341401238
144630184	18"	3/4"	1 1/2"	6	716341401245
144630185	18"	1"	1 1/2"	6	716341404758

### Colossus Pro-Extra\*\* SINGLE ROLLER COVERS



Item No.	Size	Nap	Core	Case	UPC
140665093	9"	1/2"	1 3/4"	15	716341351441
140665094	9"	3/4"	1 3/4"	15	716341351151
140665095	9"	1"	1 3/4"	15	716341351168

\*Pro-Extra covers require a 1 3/4" frame.

### Colossus JUMBO MINI ROLLER COVERS



Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack	140624033	4 1/2"	1/2"	3/4"	6	716341402648
2 Pack	14G626033	6 1/2"	1/2"	3/4"	3	716341402723

## GLASS-LIKE FINISH ON VERY SMOOTH SURFACES TO RIVAL A PAINT SPRAYER LOOK.

**Coating Type:** Latex and Oil-Based Paints and Primers

**Sheen Type:** Semi-Gloss, High Gloss and Clear

**Project Type:** Metal, Wood, Cupboards and Doors

**Materials:** Woven Mohair



### Parrot SINGLE ROLLER COVERS

Item No.	Size	Nap	Core	Case	UPC
144644091	9"	1/4"	1 1/2"	15	716341072605



### Parrot JUMBO MINI ROLLER COVERS

Description	Item No.	Size	Nap	Core	Case	UPC
2 Pack	140624040	4 1/2"	1/4"	3/4"	6	716341402655
2 Pack	140626040	6 1/2"	1/4"	3/4"	6	716341402730



# Non-Bevel™, Roadrunner™ & Lambskin

## Non-Bevel SINGLE ROLLER COVERS



**NON-BEVELED EDGE REDUCES THE NEED TO CUT IN.**

**Coating Type:** Latex and Oil-Based Paints

**Sheen Type:** Flat, Eggshell and Satin

**Project Type:** Drywall, Stucco and Wood

**Materials:**  
Knitted High Density Polyester

Item No.	Size	Nap	Core	Case	UPC
144690094	9"	3/4"	1 1/2"	15	716341400095

## Roadrunner 50/50 SINGLE ROLLER COVERS



**THE BLEND OF NATURALLY ABSORBENT WOOL AND RESILIENT POLYESTER PREVENTS MATTING. A GREAT ALTERNATIVE TO LAMBSKIN.**

**Coating Type:** Latex and Oil-Based Paints

**Sheen Type:** Flat, Eggshell and Satin

**Project Type:** Wood Siding, Decks, Flooring and Fences

**Materials:**  
Knitted 50/50 Lambs Wool/ Polyester Blend

Item No.	Size	Nap	Core	Case	UPC
144654093	9"	1/2"	1 1/2"	15	716341074203
144654094	9"	3/4"	1 1/2"	15	716341074302
144654095	9"	1"	1 1/2"	12	716341074401
144654097	9"	1 1/4"	1 1/2"	12	716341074500

## Lambskin SINGLE ROLLER COVER



**NATURAL WOOL FIBERS ABSORB PAINT. PERFORMS BEST WITH OIL-BASED COATINGS.**

**Coating Type:** Latex and Oil-Based Paints

**Sheen Type:** All

**Project Type:** Decks, Wood Siding, Porches and Stucco

**Materials:**  
Knitted 100% Lambskin/Wool

Item No.	Size	Nap	Core	Case	UPC
14L636093	9"	1/2"	1 1/2"	12	716341071301

## EVERYTHING YOU NEED TO START PAINTING.

Tailored with products for each of your projects.



### PREMIUM PROFESSIONAL KITS

- 9" x 3/8" WhiteDove Roller Cover
- 9" Heavy-Duty, 5-Wire Frame
- Metal Paint Tray
- 2" XL® Dale™ Angular Trim Brush
- (2) 9" x 3/8" WhiteDove Roller Covers
- 9" Heavy-Duty, 5-Wire Frame
- Metal Paint Tray
- 2" XL Glide™ Angular Trim Brush
- Plastic liner

Item No.	Size	Nap	Case	UPC
14C810001	9"	3/8"	5	716341400385

Item No.	Size	Nap	Case	UPC
14C811000	9"	3/8"	5	716341400224



### JUMBO MINI KITS

- (2) 4 1/2" WhiteDove Roller Covers
- 12" Jumbo Mini Roller Frame
- Heavy-Duty Plastic 1 Quart Tray
- (2) 6 1/2" WhiteDove Roller Cover
- 12" Jumbo Mini Roller Frame
- Heavy-Duty Plastic 1 Quart Tray

Item No.	Size	Nap	Case	UPC
14C810600	4 1/2"	1/2"	6	716341405083

Item No.	Size	Nap	Case	UPC
14C810700	6 1/2"	1/2"	6	716341404901



- (2) 9" x 3/8" Contractor 1st Roller Covers
- 9" Heavy-Duty, 5-Wire Frame
- Metal Paint Tray

Item No.	Size	Nap	Case	UPC
140810200	9"	3/8"	6	716341402952



# TRAYS, STORAGE, FRAMES & POLES

*Meet the*  
**SUPPORTING CAST**

Purdy® trays, storage, frames & poles are lightweight and durable to withstand the most demanding jobs. Specially designed to work together and enhance other products, these create the perfect system to complete any job.

# Buckets & Trays



**A DURABLE SYSTEM FOR INCREASED PRODUCTIVITY.**



**NEST  
DUAL  
ROLL-OFF  
BUCKET**



Dual Roll-Off Bucket is the base of the NEST™ Tray System. All NEST trays and liners conveniently fit into this bucket to create a versatile, paint-holding storage system that is perfect for all jobs, big or small.

Item No.	Use with	Capacity	Case	UPC
140796018	Any Size Rollers	5 Gallons	1	716341403218

**NEST  
18" PAINT  
TRAY**



Item No.	Use with	Capacity	Case	UPC
14T903000	Rollers ≤ 18"	1 1/2 Gallons	6	716341008543

**NEST  
9" PAINT  
TRAY**



Item No.	Use with	Capacity	Case	UPC
15T901000	Rollers ≤ 9" or 240 mm	1 Gallon	6	716341008529

**NEST™  
BUCKET LID**



Item No.	Material	Case	UPC
14LID6018	Durable Plastic	3	716341009090

**NEST  
DUAL  
ROLL-OFF  
BUCKET  
LINER**



Description	Item No.	Use with	Capacity	Case	UPC
3 Pack	144700000	Any Size Rollers	5 Gallons	6	716341007188

**NEST  
18" PAINT  
TRAY LINER**



Description	Item No.	Use with	Capacity	Case	UPC
3 Pack	14T904000	Rollers ≤ 18"	1 1/2 Gallons	6	716341008550

**NEST  
9" PAINT  
TRAY LINER**



Description	Item No.	Use with	Capacity	Case	UPC
3 Pack	14T902000	Rollers ≤ 9" or 240 mm	1 Gallon	6	716341008536

# Pail & Pail Liners

## IT DOES MORE SO PROS CAN, TOO.

- Multi-grip options to help reduce hand fatigue.
- Hands-free ladder hook bail for added safety.
- Mini roller ramp and rest fits up to 4.5" mini roller.
- Powerful brush magnet keeps brush out of paint.



### PAIL



Description	Item No.	Capacity	Case	UPC
Pail	14T921000	1 qt.	3	716341011673

### PAIL LINERS



Description	Item No.	Capacity	Case	UPC
Pail Liners - 3 pack	14T931000	1 qt.	6	716341011666



# Painter's Backpack

## HARDWORKING FEATURES MAKE CARRYING IT ALL EASY.

- Multiple storage spaces for a variety of painting tools
- Even-weight distribution for easy carrying to job sites
- Durable, weather-resistant fabric exterior
- External USB connector



### PAINTER'S BACKPACK



Includes no-mess wet brush & roller pouch.

Description	Item No.	Case	UPC
Painter's Backpack	14S250000	2	716341011697



# Frames & **POWER LOCK**® Pole

## THE ULTIMATE CONNECTION.


- Lightweight and durable
- Reduces arm fatigue



**POWER LOCK**®



### REVOLUTION™ FRAMES

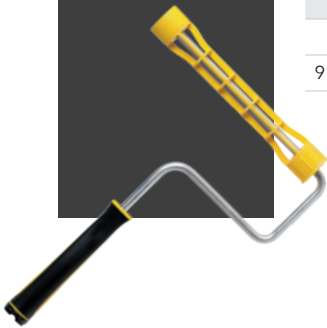

Lightweight frame design and comfort grip handle for reduced arm fatigue. Open cage design allows for quick and easy cleaning.

Description	Item No.	Use with	Frame Core	Case	UPC
9" Frame	14A751129	9" Rollers	1 1/2"	6	716341005665
9" Pro-Extra® Frame	14A751349	Pro-Extra Rollers	1 3/4"	6	716341005672
14" Frame	14A751130	14" Rollers	1 1/2"	4	716341010560

### REVOLUTION PREMIUM ADJUSTABLE FRAME



Unique angle design for greater coverage with less effort. Patent pending cam latch design for quick adjustment.

Item No.	Use with	Case	UPC
14A753018	12", 14", 18" Roller Covers	3	716341005689

### REPLACEMENT END CAPS



Description	Item No.	Use with	Case	UPC
2 Piece	140751218	12", 14", 18" Roller Covers	12	716341403980

**POWER LOCK®  
EXTENSION  
POLE**



Features a continuous-adjustment locking mechanism and a universal tip can be used with Purdy® Quick Connect system or any acme threaded frame.

Item No.	Handle Length	Case	UPC
140855612	1-2'	3	716341406042
140855624	2-4'	3	716341406059
140855648	4-8'	3	716341406066
140855661	6-12'	3	716341406073
140855681	8-16'	3	716341406080

**REVOLUTION™  
JUMBO MINI  
FRAME**



Item No.	Use with	Handle Length	Frame Core	Case	UPC
14A770014	4 1/2" & 6 1/2" Jumbo Mini Rollers	12"	3/4"	6	716341007959
14A770024	4 1/2" & 6 1/2" Jumbo Mini Rollers	22"	3/4"	6	716341008017

**REVOLUTION  
JUMBO MINI  
FRAME &  
COVER**



Item No.	Use with	Handle Length	Frame Core	Cover	Case	UPC
14A784014	4 1/2" & 6 1/2" Jumbo Mini Rollers	12"	3/4"	4 1/2" WhiteDove™	6	716341008314

**WIRE  
MINI ROLLER  
FRAME &  
COVER**



Description	Item No.	Handle Length	Use with	Cover	Nap	Case	UPC
4" Wire Mini Roller System	140743014	14"	4" Wire Mini Rollers	4" WhiteDove	3/8"	6	716341401795
6 1/2" Wire Mini Roller System	140765014	14"	6 1/2" Wire Mini Rollers	6 1/2" WhiteDove	3/8"	6	716341401856
6 1/2" Wire Mini Roller System	140765024	24"	6 1/2" Wire Mini Rollers	6 1/2" WhiteDove	3/8"	6	716341401863
6 1/2" Wire Mini Roller System	144765314	14"	6 1/2" Wire Mini Rollers	6 1/2" Marathon®	1/2"	6	716341404543

# Miscellaneous Products

## QUICK CONNECT ADAPTORS



Quickly convert any threaded tool to be compatible with the Purdy® Power Lock® Pole.

Item No.	Case	UPC
140900904	4	716341009137

## 5-WIRE RING KAGE™ FRAMES



Item No.	Description	Use with	Frame Core	Case	UPC
509304300	3"	1 1/2" Core Rollers	1 1/2"	12	079819930433
509304400	4"	1 1/2" Core Rollers	1 1/2"	12	079819930440
14B744009	Wood Pro 9™	For 9" Rollers	1 1/2"	6	716341406219


## METAL TRAYS & PLASTIC LINERS



Heavy-duty plated steel. Ribbed bottom. Ladder hook legs. Fits covers up to 9" wide. Optional, vacuum-formed plastic tray liner.

Item No.	Model	Description	Case	UPC
509363000	Pro1™	1 Gallon Metal Tray	12	079819936305
509360000	Pro1	1 Gallon Plastic Tray Liner	50	079819936008
509362000	551™	2 Quart Metal Tray	12	079819936206
509359000	551	2 Quart Plastic Tray Liner	50	079819935902
11764290	Std. Duty	1 1/2 Quart Metal Tray	10	078435820302

## PLATED METAL BUCKET GRIDS

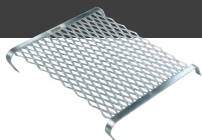

Description	Item No.	Case	UPC
5 Gallon Bucket Grid	509371000	12	079819937104
2 Gallon Bucket Grid	509372000	24	079819937203
1 Gallon Bucket Grid	509373000	24	079819937302



# Premium Series

## EXCEPTIONAL QUALITY FOR EXTREME DURABILITY.

- Rubberized ergonomic grip to prevent slipping and increase comfort\*
- Nail-set hammerhead end
- Full-length\*, rust-resistant, stainless steel blade

### Premium FOLDING TOOL



Folding tool, with a foldable blade and pocket clip, has the versatility of a regular multi-tool.

Description	Item No.	Blade Style	Case	UPC
Folding Tool	140900600	Folding Blade	5	716341008321

### Premium MULTI-TOOLS



Each multi-tool includes numerous features to set nails, scrape, open cans, spread compound, open/clean cracks and clean rollers. Features of 10-in-1 include nail puller and screwdriver key. 8-in-1 includes 11/16" and 3/4" hex wrenches.


Description	Item No.	Blade Style	Case	UPC
10-in-1	14A900800	Full-Length Blade	4	716341008512
8-in-1	14A900310	Full-Length Blade	5	716341008253
6 in-1	14A900210	Full-Length Blade	5	716341008246

### Premium JOINT KNIVES



Item No.	Blade Style	Size	Case	UPC
14A900030	Flexible Angled Blade	3"	5	716341008147
14A900040	Flexible Blade	4"	5	716341008154
14A900060	Flexible Blade	6"	5	716341008161

### Premium PUTTY KNIVES

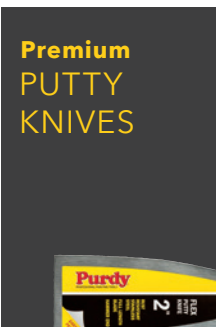

Item No.	Blade Style	Size	Case	UPC
14A900115	Stiff Blade	1 1/2"	5	716341008031
14A900015	Flexible Blade	1 1/2"	5	716341008024
14A900020	Flexible Blade	2"	5	716341008048
14A900025	Stiff Blade	2"	5	716341008086

\*Does not apply to Folding Tool and Bent Pole Scraper.

## Premium SCRAPERS



**BENT POLE SCRAPER** with stainless steel blade and Quick Connect feature with Power Lock® Poles.

Description	Item No.	Size	Case	UPC
Bent Pole Scraper, Stainless Steel	14A900540	3"	5	716341008772
Stiff Chisel Scraper	14A900130	3"	5	716341008123
Flexible Scraper	140900630	3"	10	716341400811
4-Edge Scraper	144900240	2 1/2"	5	716341402884
4-Edge Scraper Replacement Blades	144900535	2 1/2"	10	716341401467

## Premium CARBIDE SCRAPERS



For more aggressive scraping.

Description	Item No.	Size	Case	UPC
Carbide Scraper	144900220	2"	5	716341401412
Carbide Scraper	144900230	2 1/2"	5	716341401436
Carbide Scraper Replacement Blade	144900225	2"	10	716341401429
Carbide Scraper Replacement Blade	144900235	2 1/2"	10	716341401443


## Premium WIRE BRUSHES



Patented crisscross bristle design removes paint two times faster. Durable rust-resistant stainless steel bristles ensure many years of use.

Description	Item No.	Size	Case	UPC
Block Brush	140910300	8"	6	716341403195
Long Handle Wire Brush	140910200	14"	6	716341403188
Short Handle Wire Brush	140910100	11"	6	716341403171

## CLEANING TOOLS

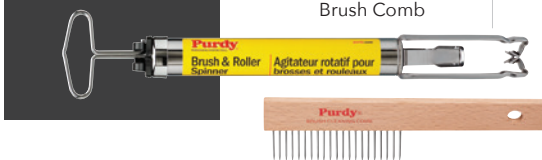

Brush and Roller Spinner dries brushes and rollers quickly and thoroughly while Brush Comb makes cleaning paint out of bristles easier and extends life of paintbrushes.

Description	Item No.	Type	Case	UPC
Brush and Roller Spinner	140755200	Fits 1 1/2" and 1 3/4" Diameter Roller Covers	4	716341403140
Brush Comb	144068010	7" Wooden	12	716341006501

# Contractor Series

**GREAT QUALITY  
& A GREAT VALUE.**

- Comfort thumb grip handle
- High carbon steel blades

## Contractor JOINT KNIVES



Item No.	Blade Style	Size	Case	UPC
14A900340	Flexible Blade	4"	5	716341008482
140900660	Flexible Blade	6"	10	716341400866
14A900360	Flexible Blade	6"	5	716341008222

## Contractor PUTTY KNIVES



Item No.	Blade Style	Size	Case	UPC
14A900415	Stiff Blade	1 1/2"	5	716341008062
140900715	Stiff Blade	1 1/2"	10	716341400774
14A900315	Flexible Blade	1 1/2"	5	716341008055
140900615	Flexible Blade	1 1/2"	10	716341400767

## Contractor SCRAPER



Item No.	Blade Style	Size	Case	UPC
14A900430	Stiff Chiseled Blade	3"	5	716341008079

## Contractor 5-IN-1 TOOL



Item No.	Case	UPC
14A900510	5	716341008994

## Contractor BRUSH AND ROLLER CLEANER



Item No.	Case	UPC
14A900520	5	716341008260



# FAUX FINISH TOOLS

*Turning hard work  
into **ARTWORK***

Purdy® faux finish tools leave an exceptional and durable finish on all faux projects. Specially created to produce beautiful effects with ease, Purdy has a product for every faux project.

# Brushes Rollers & Sponges

**SYMPHONY™  
VEINING  
BRUSH  
SABLE  
DAGGER**



This veining brush, or Sable Dagger, is made with the finest quality sableline hair for easy paint and glaze application.

Item No.	Size	Case	UPC
503170000	N/A	3	033572317009

**SYMPHONY  
RAG  
ROLLER**



For creating professional rag rolling effects. Rag rolling is fast and easy to master with this cotton 9" rag roller cover.

Item No.	Size	Case	UPC
513240900	9"	6	033572324090

**SYMPHONY  
NATURAL  
SEA  
SPONGE**



Sponging includes the more popular and easier techniques in decorative painting and finishing. Only the finest and softest grade natural sea wool sponge is used, allowing easy application and minimal fraying.

Item No.	Size	Case	UPC
503192400	Small	3	033572319249

**MAKE IT PERFECT.  
MAKE SURE IT'S**

**Purdy**<sup>®</sup>

PROFESSIONAL PAINTING TOOLS



# Index

## BRUSHES

Black Bristle Adjutant™	24
Black Bristle Extra Oregon™	24
Black Bristle Sprig™	25
Black Bristle Swan™	25
DuPont® Chinex® Elite™ Bow™	10
DuPont Chinex Elite Dale™	10
DuPont Chinex Elite Glide™	11
DuPont Chinex Elite Sprig	11
DuPont Chinex Elite Swan	11
Clearcut® Dale	17
Clearcut Elite™ Angular Pip™	7
Clearcut Elite Bow	7
Clearcut Elite Glide	8
Clearcut Elite Pip	8
Clearcut Elite Sprig	9
Clearcut Elite Swan	9
Clearcut Glide	17
Clearcut Sprig	18
Clearcut Swan	18
Nylo-Peacock™	28
Nylo-Scooter™	28
Nylox™ Dale	29
Nylox Elasco™	29
Nylox Glide	30
Nylox Mode™	30
Nylox Moose™	30
Nylox Pip	31
Nylox Sprig	31
Nylox Swan	31
Ox-o-Angular™	34
Ox-o-Thin™	34
Pro-Extra® Dale	14
Pro-Extra Elasco	14
Pro-Extra Glide	15
Pro-Extra Monarch™	15
Pro-Extra Moose	15
Pro-Extra Pip	16
Pro-Extra Sprig	16
Pro-Extra Swan	16
Syntox® Angular	32
Syntox Flat™	32
Syntox Sprig	33
White Bristle Adjutant	26
White Bristle Extra Oregon	26
White Bristle Plato™	27
White Bristle Sprig	27

XL® Blue Heron™ B.T.™	19
XL Bow™	19
XL Cub™	20
XL Dale	20
XL Elasco	20
XL Elite Dale	12
XL Elite Glide	12
XL Elite Sprig	13
XL Glide	21
XL High Capacity	23
XL Nylonia™	21
XL Moose	21
XL Pip	22
XL Sprig	22
XL Swan	22

## ROLLER COVERS

Colossus™ Jumbo Mini Roller Covers	43
Colossus Pro-Extra® Roller Covers	43
Colossus Roller Covers	43
Contractor 1st™ Kit	40
Contractor 1st Multi-packs	40
Contractor 1st Roller Covers	40
GoldenEagle™ Jumbo Mini Roller Covers	41
GoldenEagle Multi-packs	41
GoldenEagle Roller Covers	41
GoldenEagle Wire Mini Roller Covers	41
Lambskin Roller Covers	45
Non-Bevel™ Roller Covers	45
Marathon® Jumbo Mini Roller Covers	42
Marathon Multi-packs	42
Marathon Roller Covers	42
Marathon Wire Mini Roller Covers	42
Parrot™ Jumbo Mini Roller Covers	44
Parrot Roller Covers	44
Roadrunner™ 50/50 Roller Covers	45
Ultra Finish® Jumbo Mini Roller Covers	37
Ultra Finish Multi-packs	37
Ultra Finish Roller Covers	37
WhiteDove™ Jumbo Mini Kits	46
WhiteDove Jumbo Mini Roller Covers	39
WhiteDove Multi-packs	38
WhiteDove Premium Professional Kits	46
WhiteDove Pro-Extra Roller Covers	39
WhiteDove Roller Covers	38
WhiteDove Wire Mini Roller Covers	39

## TRAYS, STORAGE, FRAMES & POLES

NEST™ Dual Roll-Off Bucket.....	48
NEST Dual Roll-Off Bucket Lid.....	49
NEST Dual Roll-Off Bucket Liner .....	49
NEST 18" Paint Tray.....	48
NEST 18" Paint Tray Liner.....	48
NEST 9" Paint Tray.....	48
NEST 9" Paint Tray Liner.....	48
Metal Trays & Plastic Liners.....	54
Pail .....	50
Pail Liners .....	50
Painter's Backpack .....	51
Plated Metal Bucket Grids .....	54
Power Lock® Extension Pole .....	53
Quick Connects Adapters .....	52
Revolution™ Frames .....	50
Revolution Premium Adjustable Frame.....	50
Revolution Jumbo Mini Frame.....	51
Revolution Jumbo Mini Frame and Cover.....	51
Replacement End Caps.....	50
5-Wire Ring Kage™ Frames.....	52
Wire Mini Roller Frame & Cover .....	51

## SURFACE PREP TOOLS

Brush and Roller Spinner .....	57
Brush Comb .....	57
Contractor 5-in-1 Tool.....	58
Contractor Brush and Roller Cleaner.....	58
Contractor Joint Knives.....	58
Contractor Putty Knives.....	58
Contractor Scraper .....	58
Premium 4-Edge Scraper.....	57
Premium 6 in-1 Tool.....	56
Premium 8-in-1 Tool.....	56
Premium 10-in-1 Tool.....	56
Premium Bent Pole Scraper.....	57
Premium Carbide Scrapers .....	57
Premium Carbide Scraper Replacement Blades.....	57
Premium Folding Tool .....	56
Premium Joint Knives .....	56
Premium Putty Knives.....	56
Premium Stiff Chisel Scraper.....	57
Premium Wire Brushes.....	57

## FAUX FINISHING TOOLS

Symphony™ Color Washing Brush .....	60
Symphony Natural Sea Sponge .....	60
Symphony Rag Roller.....	60
Symphony Veining Brush Sable Dagger.....	60

**Quality.  
Integrity.  
Value.**



101 Prospect Ave., Cleveland, OH 44115  
**P: 800.547.0780 | F: 800.380.9422 | INFO@PURDY.COM**  
**PURDY.COM**

810-0211-000  
A102263PD  
© Purdy  
09/20 PURD 773/19