


ADJUSTABLE-HEIGHT ONE-STEP WORK PLATFORM

Features:

- 800 lb. rated capacity
- Heavy gauge steel construction
- Powder coat finish
- Powder coat gray finish - Serrated
- Powder with yellow finish - Ergo Matting
- Complies with applicable OSHA & ANSI standards



Grip Strut

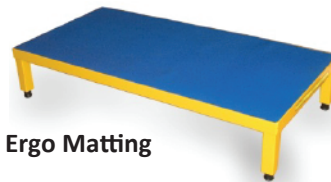

Ergo Matting

ADJUSTABLE-HEIGHT ONE-STEP WORK PLATFORM					
SERRATED			ERGO MATTING		
Tri-Arc Model #	Platform Length	Platform Width	Tri-Arc Model #	Platform Length	Platform Width
5" - 8" HEIGHT ADJUSTMENT			5" - 8" HEIGHT ADJUSTMENT		
WLOS524242	24"	24"	MCOS24195	24"	19"
WLOS536242	36"	24"	MCOS24245	24"	24"
WLOS548242	48"	24"	MCOS36195	36"	19"
WLOS559242	59"	24"	MCOS36245	36"	24"
WLOS571242	71"	24"	MCOS48195	48"	19"
WLOS597242	97"	24"	MCOS48245	48"	24"
			MCOS72245	72"	24"
9" - 14" HEIGHT ADJUSTMENT			9" - 14" HEIGHT ADJUSTMENT		
WLOS924242	24"	24"	MCOS24199	24"	19"
WLOS936242	36"	24"	MCOS24249	24"	24"
WLOS948242	48"	24"	MCOS36199	36"	19"
WLOS959242	59"	24"	MCOS36249	36"	24"
WLOS971242	71"	24"	MCOS48199	48"	19"
WLOS997242	97"	24"	MCOS48249	48"	24"
			MCOS72249	72"	24"