



U.S. Tsubaki Power Transmission, LLC

301 E. Marquardt Dr.

Wheeling, IL 60090


Phone: 847.459.9500 or 800.323.7790

Fax: 847.459.9515

Email: sales@ustsubaki.com

Website: www.ustsubaki.com

NO. 40 - 1/2" PITCH - PLAIN BORE SPROCKETS

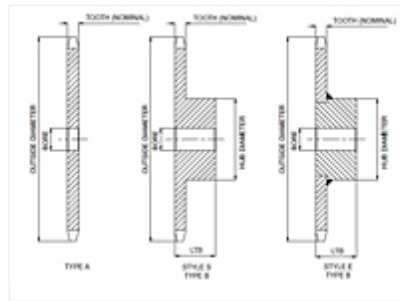

1 2 3 4 5

Item #	Stock Bore Diameter	Style	Chain Size	No. Teeth	Max. Bore	Weight	Quantity
40A12	0.500 in	A	40	12	N/A	0.180 lb	<input type="text" value="1"/>
40A13	0.500 in	A	40	13	N/A	0.220 lb	<input type="text" value="1"/>
40A14	0.500 in	A	40	14	N/A	0.250 lb	<input type="text" value="1"/>
40A15	0.625 in	A	40	15	N/A	0.300 lb	<input type="text" value="1"/>
40A16	0.625 in	A	40	16	N/A	0.340 lb	<input type="text" value="1"/>
40A17	0.625 in	A	40	17	N/A	0.360 lb	<input type="text" value="1"/>

<u>Item #</u>	<u>Stock Bore Diameter</u>	<u>Style</u>	<u>Chain Size</u>	<u>No. Teeth</u>	<u>Max. Bore</u>	<u>Weight</u>	<u>Quantity</u>
<u>40A18</u>	0.625 in	A	40	18	N/A	0.440 lb	<input type="text" value="1"/>
<u>40A19</u>	0.625 in	A	40	19	N/A	0.460 lb	<input type="text" value="1"/>
<u>40A20</u>	0.625 in	A	40	20	N/A	0.560 lb	<input type="text" value="1"/>
<u>40A21</u>	0.625 in	A	40	21	N/A	0.580 lb	<input type="text" value="1"/>
<u>40A22</u>	0.625 in	A	40	22	N/A	0.660 lb	<input type="text" value="1"/>
<u>40A23</u>	0.625 in	A	40	23	N/A	0.720 lb	<input type="text" value="1"/>
<u>40A24</u>	0.625 in	A	40	24	N/A	0.820 lb	<input type="text" value="1"/>
<u>40A25</u>	0.625 in	A	40	25	N/A	0.880 lb	<input type="text" value="1"/>
<u>40A26</u>	0.625 in	A	40	26	N/A	0.940 lb	<input type="text" value="1"/>
<u>40A27</u>	0.625 in	A	40	27	N/A	0.980 lb	<input type="text" value="1"/>
<u>40A28</u>	0.625 in	A	40	28	N/A	1.100 lb	<input type="text" value="1"/>
<u>40A29</u>	0.594 in	A	40	29	N/A	1.220 lb	<input type="text" value="1"/>
<u>40A30</u>	0.594 in	A	40	30	N/A	1.250 lb	<input type="text" value="1"/>
<u>40A31</u>	0.594 in	A	40	31	N/A	1.400 lb	<input type="text" value="1"/>
<u>40A32</u>	0.594 in	A	40	32	N/A	1.480 lb	<input type="text" value="1"/>
<u>40A33</u>	0.594 in	A	40	33	N/A	1.560 lb	<input type="text" value="1"/>
<u>40A34</u>	0.594 in	A	40	34	N/A	1.640 lb	<input type="text" value="1"/>
<u>40A35</u>	0.594 in	A	40	35	N/A	1.700 lb	<input type="text" value="1"/>
<u>40A36</u>	0.594 in	A	40	36	N/A	1.840 lb	<input type="text" value="1"/>

