



U.S. Tsubaki Power Transmission, LLC

301 E. Marquardt Dr.

Wheeling, IL 60090

Phone: 847.459.9500 or 800.323.7790

Fax: 847.459.9515


Email: sales@ustsubaki.com

Website: www.ustsubaki.com

ITEM # 40B35, NO. 40 - 1/2" PITCH - PLAIN BORE SPROCKETS

No. 40, B Style, .625" plain bore

All dimensions are nominal values and for reference only

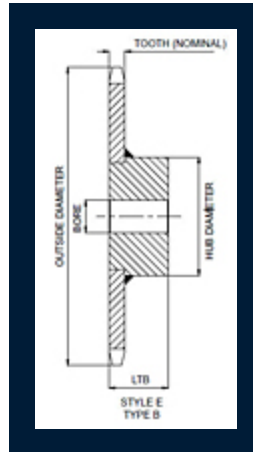

[Specifications](#) | [Chain Technical Data](#)

Specifications

| | |
|----------------------------|----------|
| Stock Bore Diameter | 0.625 in |
| Hub Diameter | 3.250 in |
| LTB | 1.000 in |
| Style | B |
| No. Teeth | 35 |

| | |
|------------------------------|--------------|
| Outside Diameter | 5.860 in |
| Pitch Diameter | 5.578 in |
| Caliper Diameter | 5.260 in |
| Max. Bore¹ | 2.250 in |
| Weight | 3.460 lb |
| Tooth Nominal Width | 0.284 in |
| Hardened Teeth | Yes |
| UPC Code | 097039314949 |

Chain Technical Data

| | |
|-------------------|----------|
| Pitch | 0.500 in |
| Chain Size | 40 |

¹ Dimensions shown allow for standard keyway with set screw at 90°