

# ACTIVARMR®

PERSONAL PROTECTIVE GEAR

## 97002



Cut



Medium Duty

## Professional HVAC technicians told us what they needed... and we delivered.

- Stainless steel and Kevlar® fibres protect against snips, screws and sheet metal
- Twice as thin as standard leather with 6 times the cut protection
- Foam nitrile-dipped palm for a grip that withstands wet and dry conditions
- Ergonomic design and breathable construction offer superior comfort and dexterity



### Industries

- Automotive
- Food Processing
- Machinery and Equipment
- Metal fabrication

### Applications

- Handling metal sheets & panels
- Picking, fastening components
- Adjusting parts, systems
- Equipment repair & maintenance
- Equipment maintenance and repair
- Adjusting systems and screwing
- Processing sheets, coils, tubes
- Fabricating metal parts, glass sheets

[WWW.ANSELL.COM](http://WWW.ANSELL.COM)

**Ansell**

# ACTIVARMR®

PERSONAL PROTECTIVE GEAR


## 97002

### Key Features

- ◊ Foam nitrile coating provides excellent grip and breathability for all day wear
- ◊ Seamless knit design molds to your hand to maximize tactility
- ◊ Velcro cuff enclosure ensures the right fit

### Performance Standards & Regulatory Compliance

#### REACH Compliant

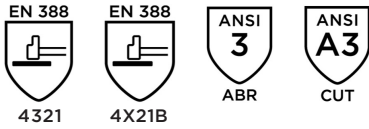

### Specifications

BRAND   STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	PACKAGE
ActivArm® 97-002	<b>Finishing:</b> Palm Coated <b>Coating Material:</b> Nitrile <b>Liner Material:</b> Nylon, Spandex, Stainless steel, Kevlar® <b>Cuff Style:</b> Velcro®	18	9, 10, 11	226 - 269 mm, 8-10"	<ul style="list-style-type: none"><li>• 12 pairs in a carton</li><li>• 72 pairs in a carton</li></ul>

### Technologies



For additional information visit us at [www.ansell.com](http://www.ansell.com), or call us at

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Australia

Ansell Limited  
Level 3, 678 Victoria Street,  
Richmond, Vic, 3121  
Australia  
T: +61 1800 337 041  
F: +61 1800 803 578

#### Asia Pacific Region

Ansell Global Trading Center  
(Malaysia) Sdn Bhd  
Prima 6, Prima Avenue  
Block 3512, Jalin Teknokrat 6  
T: +603 8310 6688  
F: +603 8310 6699

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### Canada

Ansell Canada  
105 Lauder  
Cowansville, QC J2K 2K8  
Canada  
T: +1 800 363 8340  
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
[www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

