



# WEARWELL<sup>®</sup>

Anti-Fatigue Matting And Flooring Solutions

Ask any  
**Industrial  
Athlete**

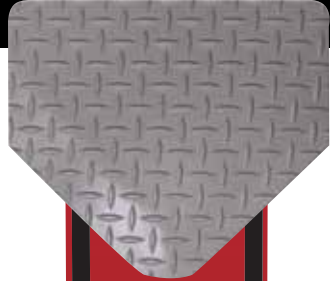

# What type of field do you send your industrial athletes out to work on?

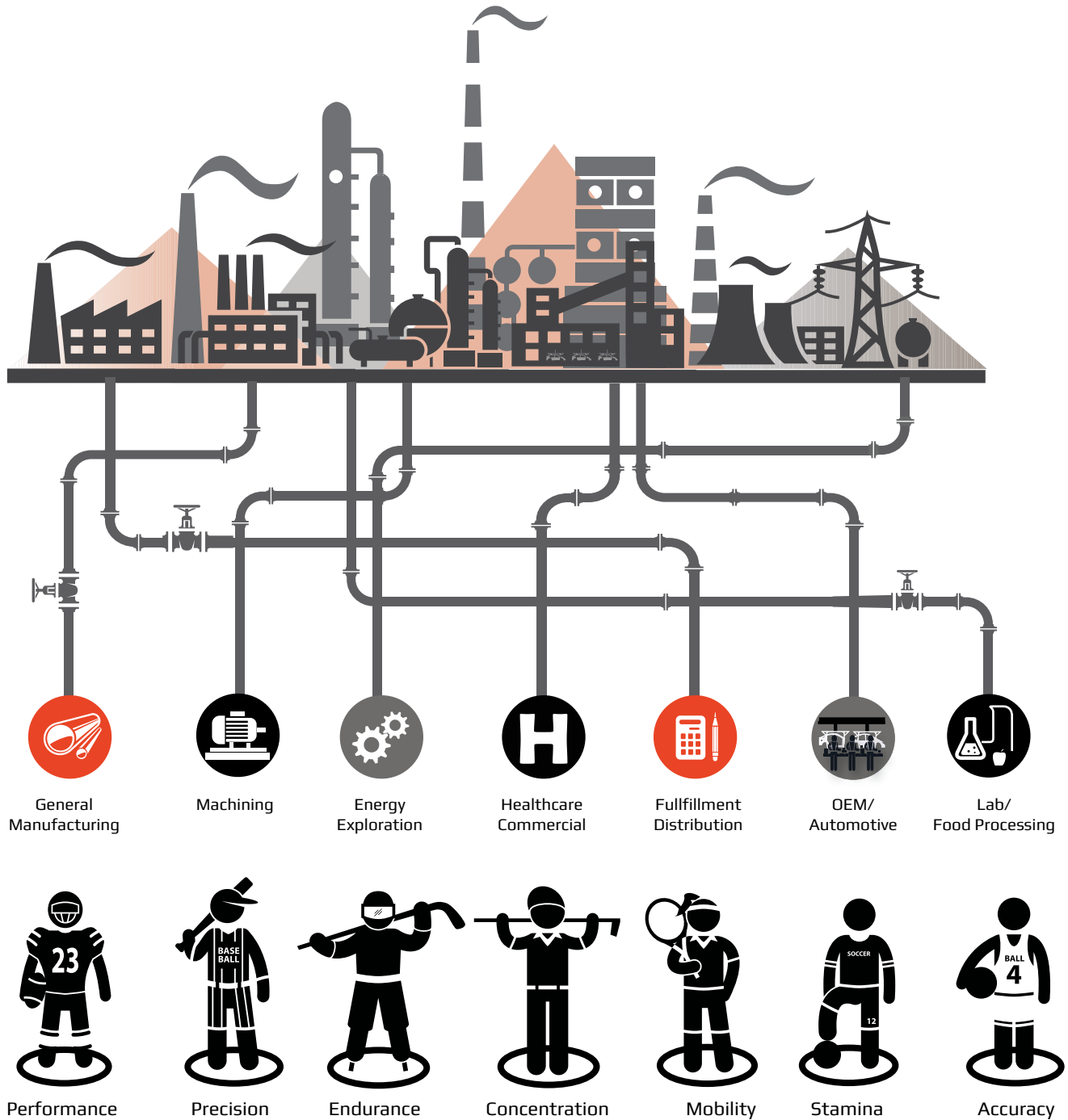

We provide matting, flooring and other facility solutions so you can provide the best designed field of play in your facility.





# Product Guide Index

Group Name	Group Code	Page	Environment				Customizable			Additional Benefits						Common Industries												
			Dry	Wet	Oily	Slippery	Cut Length	Width & Length	Len./Wid./Shape	Cart Friendly	Grate Friendly	Modular	Anti-Fatigue	Non-Conductive	Static-Dissipative	Welding	Machining	Gen. Mfg	Auto / OEM	Tech Mfg/Data Ctr	Transportation	Energy/Oil/Gas	Fulfillment/Dstr.	Maintenance	Lab/Pharmacy	Food Processing	Retail / Hospitality	Healthcare
F.I.T.™ Kits w/GS	545	34		◆		◆									◆	◆	◆											
F.I.T.™ Open	540	23, 34				◆									◆	◆	◆								◆			
F.I.T.™ Open w/GS	542	23, 34				◆									◆	◆	◆											
F.I.T.™ ComfortDeck	548	22, 34				◆									◆	◆	◆								◆			
F.I.T.™ Solid	541	23	◆												◆	◆	◆				◆							
F.I.T.™ Solid w/GS	543	23				◆									◆	◆	◆				◆							
Grade "A"®	482	44				◆																		◆	◆	◆	◆	
H.T. Runner	347	81	◆																									
HD Corrugated	305	81	◆							◆											◆							
Industrial WorkSafe® GR	476-GR	40		◆		◆									◆	◆	◆	◆										
Industrial WorkSafe® NBR	476-NBR	40				◆	◆								◆	◆	◆											
KleenSweep	391	82	◆							◆											◆		◆					
Kushion Walk	475	80		◆						◆	◆																	
LightWorks Inspection Mat	438	28	◆							◆													◆					
Marbelized Military Switchboard Mat	710	55	◆							◆										◆								
Modular D-P ESD	788	60	◆							◆					◆	◆	◆						◆					
Modular D-P GP	470-DP	37				◆									◆	◆	◆											
Modular D-P GR	470-GR	37		◆											◆	◆	◆				◆							
Modular WorkSafe® Light ESD	789	60	◆							◆					◆	◆	◆	◆					◆					
Modular WorkSafe® Light GP	472-GP	41				◆									◆	◆	◆											
Modular WorkSafe® Light GR	472-GR	41		◆											◆	◆	◆											
Mud Chucker™	229	69, 85		◆																◆		◆						
Ortho Stand™	454	37		◆																								
Perma Tack	92	68, 76	◆							◆													◆				◆	
Radial Runner	356	82	◆							◆											◆		◆					
Rejuvenator® Domed	503	12, 48, 72	◆												◆	◆	◆				◆		◆					
Rejuvenator® Squared	502	12, 48, 72	◆												◆	◆	◆				◆		◆					
ROVER™ 3-IN-1	515	66	◆												◆	◆	◆				◆	◆						
ROVER™	514	66	◆												◆	◆	◆				◆	◆						
Sanitizing Footbath Mat	222	45		◆																			◆	◆				
SMART® D-P UltraSoft	497	26-27	◆																		◆						◆	
SMART® Tile-Top™	496	74-75	◆																		◆						◆	
Smooth Military Switchboard Mat	711	55	◆							◆											◆							
Soft Rock	423	28, 77	◆																		◆		◆			◆	◆	
Soft Step	427	51	◆																		◆						◆	
Sole-Solution Foot Bath	223	45, 69	◆	◆	◆	◆									◆	◆	◆				◆		◆	◆			◆	
Static Dissipative Anti-Fatigue	791	61	◆																					◆				
Std Corrugated Vinyl	381	82	◆							◆											◆							
Textured Kleen-Rite	383	82	◆							◆											◆							
Tile-Top Spongecote™ AM	420	74-75	◆																		◆			◆				
Tile-Top Spongecote™ Select	494	74-75	◆																		◆			◆				
Tuf Sponge	451	50	◆																		◆							
UltraSoft D-P	414	26-27, 48	◆																		◆			◆	◆			
UltraSoft Electrically Conductive Mat	786	59	◆																		◆		◆		◆			
UltraSoft Tile-Top Spongecote™ AM	419	74-75	◆																		◆			◆	◆	◆	◆	
Ultra-Tred ArmorCote	440	49	◆																		◆							
WeldSafe®	447	28	◆																		◆		◆					
WorkRite	474	45		◆																					◆			
WorkRite II	468	37	◆	◆																					◆			
WorkSafe® GR	477	41		◆																	◆			◆				
WorkSafe® Light CFR	478	40			◆																◆							

# Assess Your Field, Build Your Game Plan




Safety: Falls, Slips,  
Or Trips



DEFINE THE  
PLAYING  
FIELD





DETERMINE  
WORKFLOW

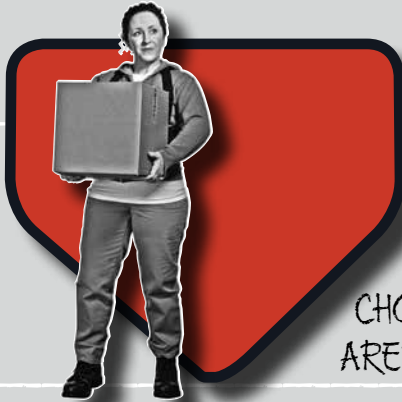

CHOOSE THE  
ARENA



  CONSIDER UNIQUE NEEDS



See Product Guide Index Inside

## TERMS AND DEFINITIONS

**COF (Coefficient of Friction)** — The degree of traction provided by a surface. It is a measurement of the force that must be exerted before an object slips. The higher the number, the better the traction. OSHA recommends a COF of .5 in dry areas and .25 in wet. The ADA recommends .6 on flat surfaces and .8 on ramps.

**Compression Deflection** — The softness or comfort level of a sponge mat. A higher number indicates a softer material. Wearwell considers .10-.20 the ideal range.

**Customization** — Providing flooring and matting products with special (1) lengths, (2) lengths and widths, or (3) shapes and configurations (also referred to as Full Custom — this is a Wearwell specialty!

**GRITSHIELD™** — Our unique grit system that improves traction and is even available over colors!

**Resilience** — A material's ability to return to its original form after being compressed.

**Taber Abrasion** — A way of measuring how well a mat's surface withstands wear. The less weight a sample loses during a Taber abrasion test, the more durable the product tends to be.

**Tensile Strength** — A measure of the tear strength of a material. The higher the psi, the stronger the mat.



24/SEVEN® Mat - Pg 38



Diamond-Plate - Pg 26



ErgoDeck® Smooth- Pg 17



Rejuvenator® Runner Square - Pg 13



Tile Top - Pg 74



ErgoDeck® w/Integrated No-Slip Cleats Open - Pg 20

## PRODUCT CATEGORY INDEX

### Pg Types / Industry / Specs

<b>2</b>	<b>INDUSTRY / APPLICATION ICONS</b>
<b>6</b>	<b>COST OF OWNERSHIP</b>
<b>8</b>	<b>WATCH OUT!</b>
<b>9</b>	<b>PROVEN COST REDUCTION</b>
<b>10</b>	<b>MANUFACTURING</b>
<b>12</b>	Flooring
<b>24</b>	Matting/Dual Layer
<b>30</b>	PVC and Rubber
<b>50</b>	Sponge
<b>42</b>	<b>FOOD PROCESSING</b>
<b>46</b>	<b>FULLFILLMENT</b>
<b>52</b>	<b>SWITCHBOARD</b>
<b>56</b>	<b>ESD</b>
<b>64</b>	<b>MAINTENANCE</b>
<b>70</b>	<b>LAB/PHARMACEUTICAL</b>
<b>78</b>	<b>COMMERCIAL BUILDINGS</b>
<b>80</b>	Runners
<b>84</b>	Entrance
<b>86</b>	<b>ACCESSORIES</b>
<b>88</b>	<b>PRODUCT SPECIFICATIONS</b>















FOR CLEANING INSTRUCTIONS AND  
CHEMICAL RESISTANCE

visit [wearwell.com](http://wearwell.com)


## The Right Step

We organized this catalog with the industrial facility in mind. Different areas have unique working conditions and surfaces. We matched products that solve the challenges for the specific area and coded them accordingly. We hope it helps you find what you need easily.

### Industry Icons

	Airlines
	Agriculture
	Assembly and Fulfillment
	Contractor/MRO
	Data Center/Electronic Mfg
	Food Processing
	Health/Lab/Pharmacy
	Hospitality
	Machining
	Manufacturing
	Oil, Gas, Mining, Energy
	Retail, Office, Education
	Restaurant
	Transportation

### Application Icons

	Wet
	Dry
	Slippery
	Oily
	Recycled Material
	Custom 1 (Length)
	Custom 2 (Length/Width)
	Custom 3 (Full Custom)

### Abbreviations used in this catalog

<b>D-P:</b> Diamond-Plate	<b>CFR:</b> Cutting Fluid Resistant Rubber
<b>HD:</b> Heavy Duty	<b>NBR:</b> Nitrile Rubber
<b>GR:</b> Grease Resistant	<b>w/GS:</b> with GRITSHIELD™
<b>GP:</b> Grease Proof	

#### With Borders

<b>BYL</b> black w/yellow
<b>BOR</b> black w/orange
<b>CHV</b> black w/chevron
<b>GNYL</b> green w/yellow
<b>RDYL</b> red w/yellow
<b>CHYL</b> charcoal w/yellow


#### Color Chart

<b>BK</b> black	<b>SB</b> sky blue
<b>BL</b> blue	<b>TC</b> terra cotta
<b>CH</b> charcoal	<b>WH</b> white
<b>GY</b> gray	<b>YL</b> yellow
<b>OR</b> orange	<b>GN</b> green
<b>RD</b> red	

**Note:** Colors may vary slightly from lot to lot

### Easy To Understand Part Numbers

Part numbers are divided into four sections. The first is the code for the product family; the second is the thickness of the product; the third describes width and length; and the code at the end indicates unique characteristics (when applicable) and color.

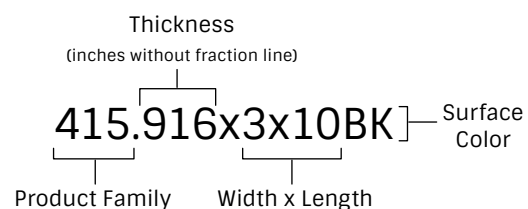



## Why Wearwell

It's a highly unpredictable world that we live in, now more than ever. Baby Boomers are retiring in record numbers. By 2025 [only 7 years away], Millennials will comprise over 50% of the workforce. Geographic labor inequities plague us, with jobs in competitive labor markets almost impossible to fill. The productivity increases that we've become accustomed to are increasingly challenging to achieve. The world's economies are cooperating and colliding in unprecedented ways. It is quite a roller coaster out there!

This is a world in which Wearwell excels. Amidst all the uncertainty and volatility, our mission remains steadfast and unwavering. We remain champions of the standing worker, the loyal and hard-working Industrial Athletes who make our economies tick. These folks are the lifeblood of our economy. It is for them—and the world class companies they work for—that Wearwell designs and produces the most highly-engineered matting and ergonomic flooring products on the market.

At Wearwell, it's our job to give your team of Industrial Athletes the perfect "field of play" on "game day"...when productivity, safety, and performance are essential. In this 2018 catalog, you'll find a range of ergonomic flooring and matting solutions that are tried and tested for even the toughest industrial environments. Our customers have unique problems and demand innovative solutions. Wearwell works with them to eliminate slips and falls, reduce absenteeism, improve performance, heighten morale, and enhance the aesthetics of the workplace.

At Wearwell, we create a better workday and deliver results that improve your bottom line from day one. Invite us in and let us show you firsthand how we've proven ourselves to thousands of companies worldwide, for nearly 70 years. Our products provide immediate impact both on your bottom line and the performance of your workforce. It's a certain WIN in an increasingly uncertain world!


We look forward to taking YOUR team of Industrial Athletes to new heights!  
Thank you.



Elliot Greenberg  
Chairman, Wearwell, Inc.

## Check Out the NEW Wearwell Innovations!


Pg. 14 ErgoDeck MAX

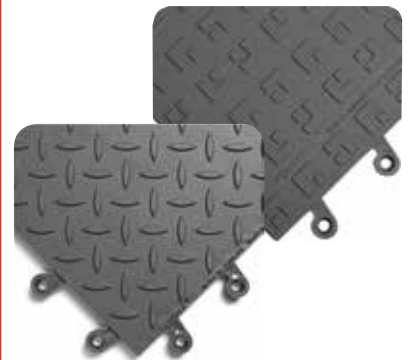


Pg. 17 ErgoDeck Smooth Heavy Duty




Pg. 22 F.I.T.™ Comfort Deck Open

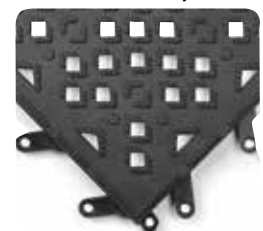

Pg. 36 Elevate XTREME Elevate OR

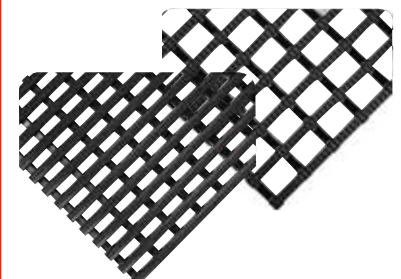

Pg. 83 Elevate Sport

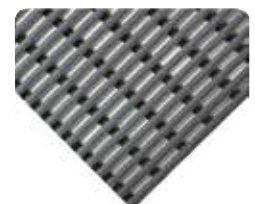



## A Vision, A Story, A Philosophy. . .

We're champions for the standing worker. To us, they're athletes on the job. And just like a professional athlete, the Industrial Athlete deserves and needs the best possible field conditions.

Virtually every sport takes place on a specially designed surface, whether it's a court, a field, or a rink. Like athletes, manufacturing workers exert themselves every day. These industrial athletes deserve to test their limits on surfaces that have been engineered to support them and their work.


We design the world's best surfaces to give them a competitive edge while they're on the clock, reducing aches, pains, fatigue, and potential for injury, so they can enjoy their life *on* and *off* the clock.

### Decades of Innovation

1987 478 WorkSafe® Light	1989 415 Diamond-Plate Spongecote®	1992 786 Electrically Conductive Anti-Fatigue	1994 414 UltraSoft Diamond-Plate	1994 Free Facility Surveys SITE-SURVEY	1996 447 WeldSafe®	1997 GritShield™ on Molded Rubber	1998 502 Rejuvenator® Mat	1999 Mat products specs Specifications
2002 416 Diamond-Plate w/GritShield™	2004 CFR Cutting Fluid Resistant Rubber	2005 560-566 ErgoDeck®	2006 227 Outfront Reversible Scraper Mat	2006 482Grade A	2007 420 Tile-Top Spongecote™ AM Anti-Microbial	2007 580 Autoclavable Mat	2008 502 Rejuvenator® Flooring	2009 710 Marbelized Switchboard Matting
2010 452 Diamond Tuf Sponge	2010 513 SubStance	2011 ErgoDeck® Colors	2011 Lightworks Inspection Mat	2012 541 F.I.T.™ Interlocking Tiles	2012 497 SMART® Diamond-Plate Mat	2012 419 SMART® Tile-Top SpongeCote™ Mat	2012 702 Corrugated Switchboard Mat	2012 720 Double-Duty Switchboard Mat
2013 503 Rejuvenator® Domed	2013 556/558 ErgoDeck® Comfort	2013 515 Rover®	2013 110 InVision Custom Mats	2014 552/553 ErgoDeck® Integrated No-Slip Cleats	2015 476 Industrial WorkSafe®	2016 223 Sole-Solution Foot Bath	2016 423 SoftRock™	2016 514 Rover® Knee Mat
2016 568 ErgoDeck® Smooth	2016 468 WorkRite II	2016 347 H.T. Runner	2017 541 F.I.T.™ Comfort Deck Tiles	2017 590 ErgoDeck® Diamond-Plate	2018 598/599 ErgoDeck® MAX	Our dedication to innovation, safety and productivity for the Industrial Athlete is why Wearwell is the category leader in industrial and safety matting. Proper design can be the difference between a mat that fails and one that's perfectly suited to the job.		

# Matting isn't a cost. It's an investment.

7 simple questions reveal how much money you can save!

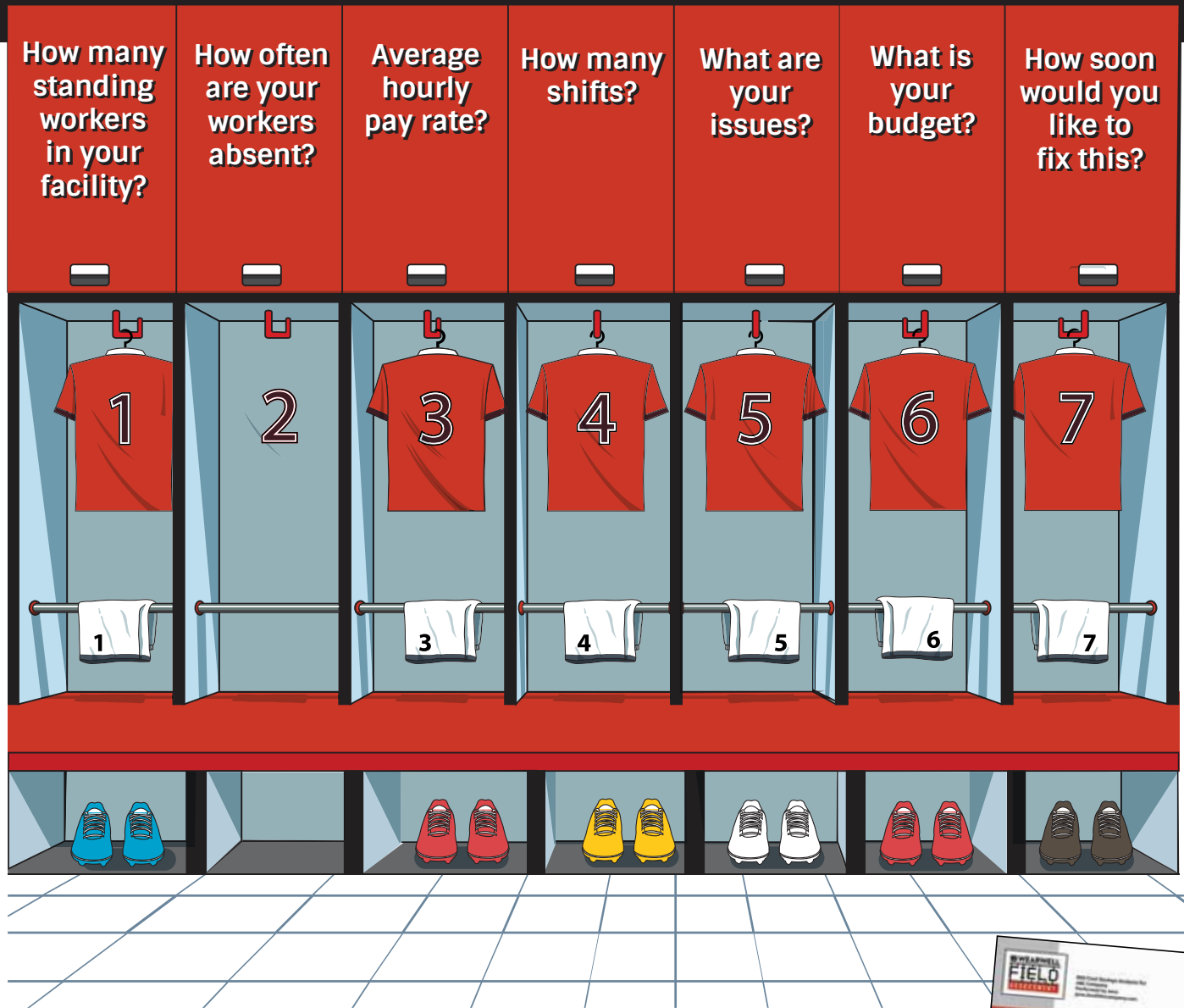

Our one of a kind Field Assessment app delivers a customized report based on your unique operations and workforce. Let us show you how much Wearwell matting and flooring can save you, and how quickly you can see a return on the investment.



**Why wait? Contact your local representative  
and learn today how you could be working toward saving tomorrow.**

[Wearwell.com/relocator](http://Wearwell.com/relocator)

# A Product For Every Budget!

Wearwell manufactures so many different types of products, because there are so many unique applications for their use. But when they're intended for the same environment which is the better value?

Divide the price of the product per square foot by the expected wear of the product.



#442  
**Tuf Sponge**  
**\$6.43 / 1**  
Per Sq. Ft. / YR  
**Value \$6.43**




#415  
**Diamond-Plate  
Spongecote®**  
**\$9.96 / 3**  
Per Sq. Ft. / YRS  
**Value \$3.32**




#502  
**Rejuvenator®**  
**\$18.89 / 8**  
Pr Sq. Ft. / YRS  
**Value \$2.36**

**★ Best Value**

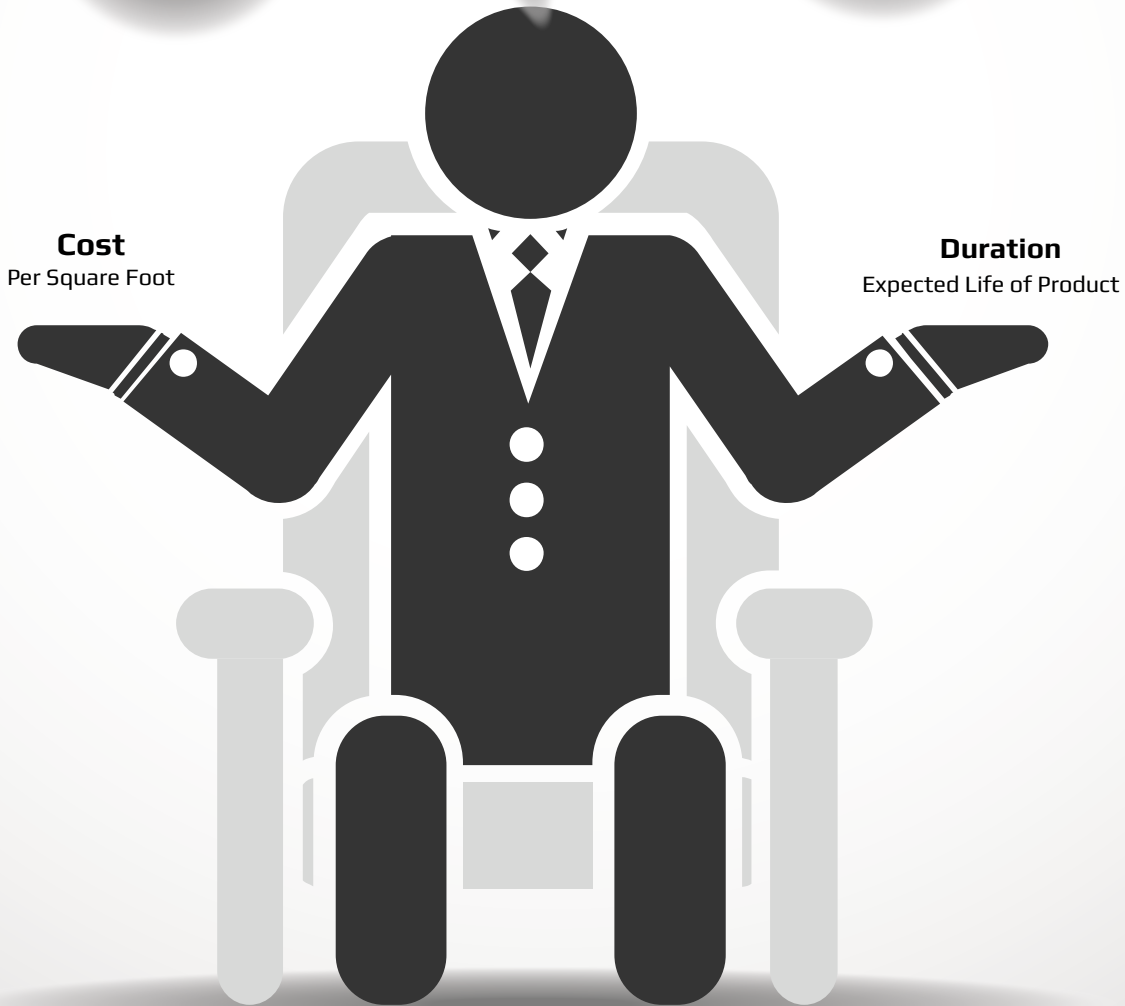

The specifics of each application and suitable products will vary.  
Your Wearwell Sales Professional is happy to assist in completing a comparison for your specific needs.

# Why Are The Number Of Warranty & Wear Years Different?

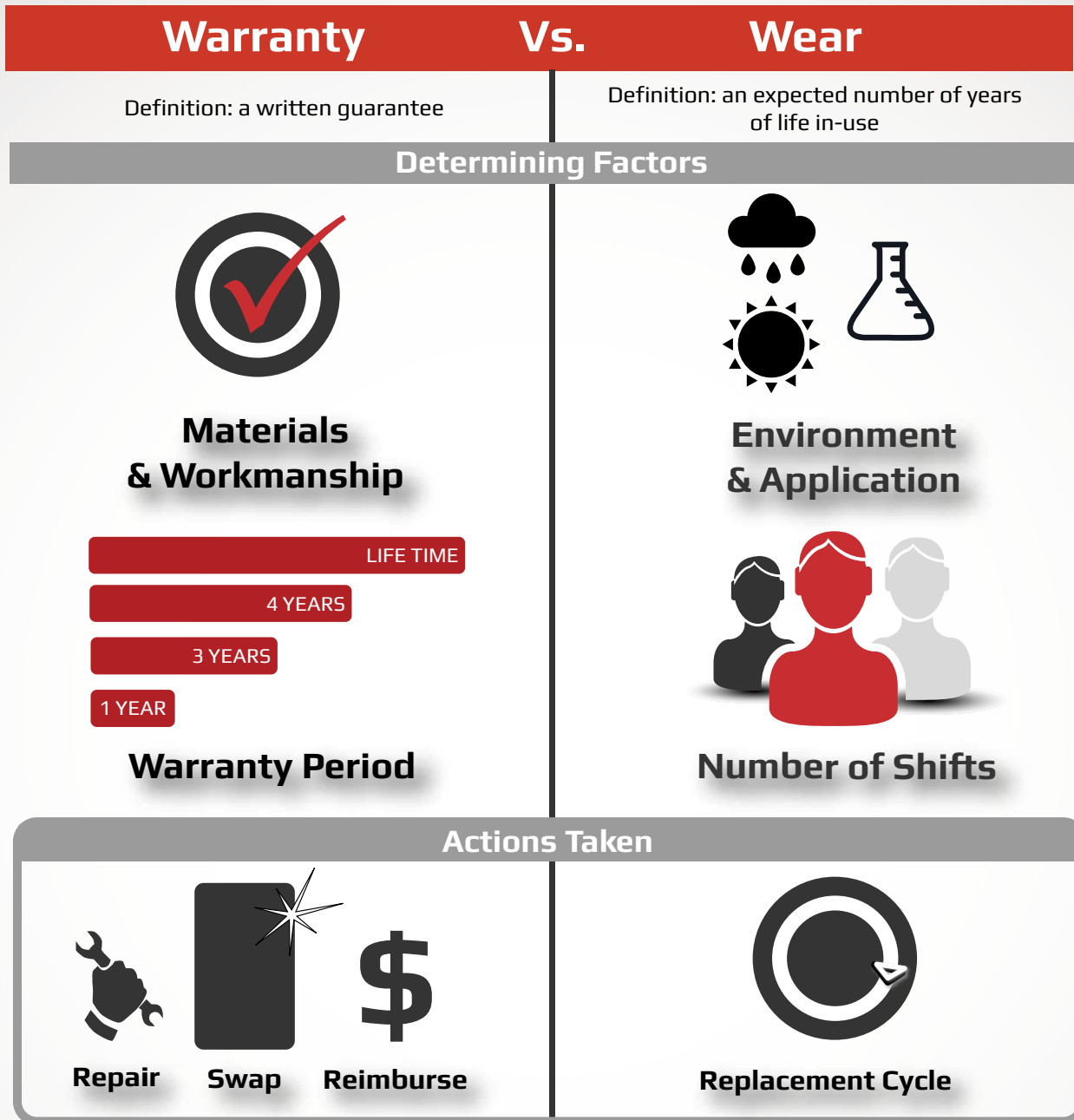

## THE WEARWELL LIFETIME WARRANTY

We're so confident in the quality and craftsmanship that we back our most popular products with a Lifetime warranty! Look for this symbol throughout the catalog and rest assured that we have you covered!

### Don't Be Confused

A lifetime warranty is a statement of confidence in our manufacturing expertise and the quality of materials we use. Every application is different so replacement cycles will vary.

### Let's Be Real

No matting or flooring product is indestructible.

If a competitor's warranty seems too good to be true, it probably is! Read the fine print.

# WATCH OUT!


Match the right ergonomic matting and flooring solutions for the job

## WATCH can:

1. Improve employee productivity
2. Reduce lost time
3. Reduce injuries and incidents
4. Upgrade facility aesthetics
5. Save money

## The Right CHOICE

Knowing what to WATCH for provides knowledge for not only what to purchase, but when to replace

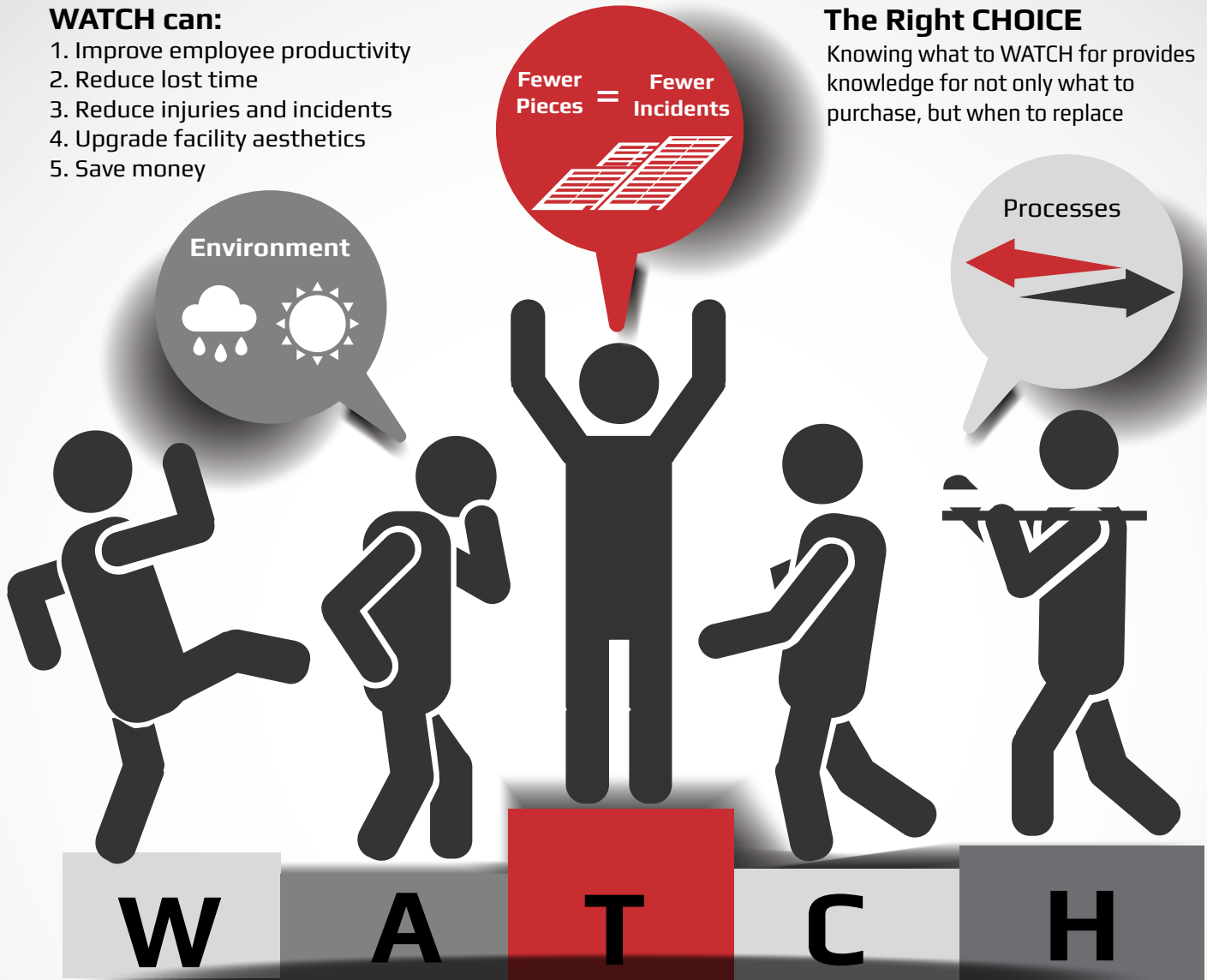

**W**

**Wet**



**Visual Cues:** pooling water, workers are slipping or are not sure-footed  
**Concerns:** loss of productivity, slips or falls, and possible micro bacterial growth

**A**

**Applications**



**Visual Cues:** high-voltage signs, handling of static-sensitive products, presence of welding equipment or paint and finishing equipment  
**Concerns:** employee safety, quality control, and productivity

**T**

**Tile Separation**



**Visual Cues:** Modular matting components that were once connected are now loose, haphazard pieces, interlocks torn  
**Concerns:** trip hazards, work disruption and productivity loss due to constant repositioning

**C**

**Caution**



**Visual Cues:** Stacked mats, cardboard, pallets, or use of unconventional materials are clear indicators that the workforce is looking for standing relief. Mats that are torn or badly worn, or used in the wrong application  
**Concerns:** trip hazards, lack of support, poor aesthetics, worker morale

**H**

**How**



**Visual Cues:** Workers are moving between workstations. If mat(s) are present, workers repeatedly step off and back onto mat(s).  
**Concerns:** trip hazards, heel strike, and severe impacts if falls occur

Consider a Wearwell Site Survey.

Our Wearwell sales professionals are WATCH experts so you don't have to be!

# Proven Cost Reduction

## Anti-fatigue Matting

Reduces Costs And Increases Worker Productivity.

Before Installation

Surface: Concrete  
Injury Rate > 3 per month  
Absent Rate > 5.2%

After Installation

Surface: Anti-Fatigue Mat  
Injury Rate < 1 per month  
Absent Rate 4%

Improvement With Mats

Injury Reduced 70%  
Absenteeism Reduced 23%




### COST SAVINGS RELATED TO THE INSTALLATION OF ANTI-FATIGUE MATS

Productivity

Insurance Premium Reduction

Total Cost Savings

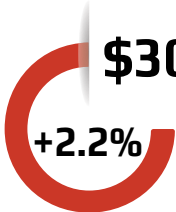

One Year Study




**From The Line Of Scrimmage To The End Zone, Increase  
The Performance of Your Industrial Athletes.**

**33%**

**Occupational Injuries**

are musculoskeletal resulting from over exertion or bodily reaction caused from an incident or repetition.

# Manufacturing

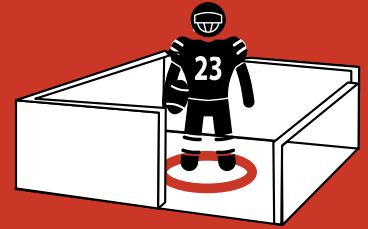

## FLOORING

### What is ergonomic flooring?

Ergonomic flooring is made up of interlocking tiles. This modular design lets users replace damaged sections easily and expand or contract ergonomic work areas as needed. Tight seams, dependable installation, and a patented fastening system hold tiles so they stay put in application until unzipped for easy replacement and reconfiguration. That can't be said for modular matting.

### Why choose ergonomic flooring?

Because your team doesn't just stand — they move — ergonomic flooring is your team's best defense against slips, trips, falls, heel strike, back pain, and muscle aches. Available in multiple styles. You can create the right field of play for your field of work. You can even incorporate color to define paths, heighten safety, and use in place of temporary tapes.

### How do I install ergonomic flooring?

Installing Wearwell ergonomic flooring is a snap. Each of our ergonomic flooring tiles has male connectors on two sides and female connectors on the other two sides. Simply connect the tiles and trim them to accommodate any space. No adhesives or fasteners required.

# REJUVENATOR® FLOORING

Rejuvenator is a quality line of urethane matting and flooring — the undisputed record-holder when it comes to comfort, resilience, and long-term value.

PATENT US D653893


Rejuvenator® flooring, runners, and workstation mats will help your team stand stronger, longer. This ultimate product delivers the combination of durability, ergonomics, and awesome good looks! Manufactured from 100% polyurethane, this perennial all-star features an unparalleled lifetime-warranty. Simply put, we've engineered it to outlast and outperform any would-be rivals.

## 502/503

## Flooring



Available in domed and squared designs, Rejuvenator® Flooring features large, 3' x 3' (91cm x 91cm) and 1' x 3' (30cm x 91cm) modules — that interlock on all four sides to customize on-site virtually any flooring configuration. The interlock is incredibly effective and also hidden so the ergonomic floor you've created is seamless and stable underfoot. Having the ability to customize in one-foot increments and finish off with beveled ramps (yellow or black) sets it apart from all other polyurethane "wannabes."

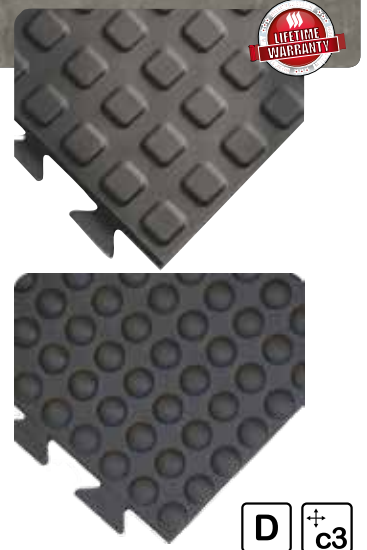

502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
1' x 3' (30cm x 91cm)	5/8" (16mm)	BK	502.58x1x3BK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	502.58x3x3BK
503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
1' x 3' (30cm x 91cm)	5/8" (16mm)	BK	503.58x1x3BK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	503.58x3x3BK


### SPECIFICATIONS

**Compound:** Polyurethane  
**Edges:** Optional 2" (5cm) - Wide Safety Edging  
**Warranty:** Lifetime

UNIVERSAL REJUVENATOR® RAMPS			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2" x 39" (5cm x 96cm)	5/8" (16mm)	BK, YL	502.58x2x39F
2" x 39" (5cm x 96cm)	5/8" (16mm)	BK, YL	502.58x2x39M

F: Female connector M: Male connector  
 Rejuvenator® edging is universal to all Rejuvenator® tiles

Rejuvenator flooring has 2" (5cm) wide ramps that provide a visual cue and transition for on-off access and are compatible with 502 and 503 flooring tiles.

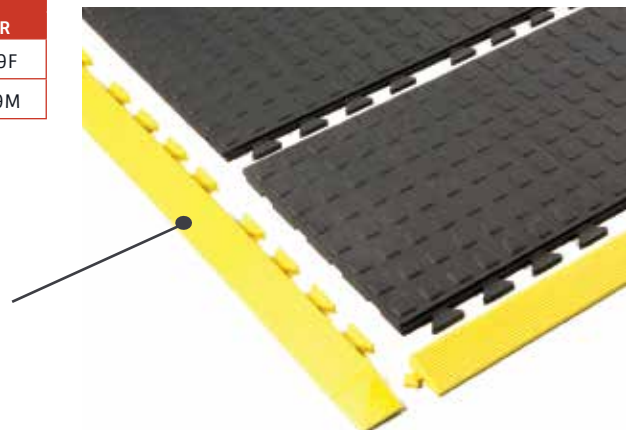



# 502/503

## Runner



Rejuvenator® Runners give you the option to create 2' (61cm) and 3' (91cm) wide runs of ergonomic matting. With a female end and a male end, all that's left is to connect as many centers as you need for your space. The molded-in ramps reduce installation time and costs.

 


502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EMBK

503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EMBK



C: Center  
EF: End, Female  
EM: End, Male



### SPECIFICATIONS

Compound: Polyurethane  
Edges: Molded-in Safety Bevel  
Warranty: Lifetime

### Need a longer runner?

Simply add more 5' center mats for unlimited length!



# 502/503

## Workstation Mat




Rejuvenator® Workstation Mats provide an out-of-the-box anti-fatigue solution for workers who spend most of their shift standing at one station. Rejuvenator® Workstation Mats feature the same awesome aesthetics as the rest of the Rejuvenator® products, so your facility can look clean and consistent.



502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK	502.58x2x3BK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5BK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5BK

503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK	503.58x2x3BK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5BK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5BK

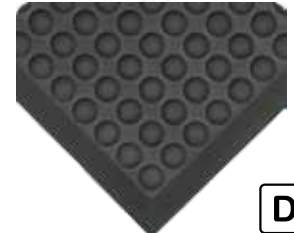

### SPECIFICATIONS

Compound: Polyurethane  
Edges: Molded-in Safety Bevel  
Warranty: Lifetime

# ERGODECK<sup>®</sup> MAX FLOORING

ErgoDeck<sup>®</sup> flooring was engineered with the evolving workplace in mind and can be used to cover large workspaces or custom work cells where traditional matting products fail. Think of ErgoDeck<sup>®</sup> as your "floor above a floor" — a high-performance field for your hardworking industrial athletes.

PATENT US 8,006,443B2 PATENT US D5210,650S

ErgoDeck<sup>®</sup> tiles have patented LockSafe<sup>®</sup> technology, that holds secure but can be taken apart and reconnected on demand. Available in a wide variety of styles, ErgoDeck<sup>®</sup> MAX is a combination of Nitricell<sup>®</sup> sponge and silicone-free PVC while other ErgoDeck<sup>®</sup> Flooring products are made of 100% silicone-free PVC.

The robust 7/8" (22mm)-thick tiles install quickly with no tools required. Tiles from the different ErgoDeck<sup>®</sup> models can be combined.

Reduce costs and improve safety! Easily replace single tiles or sections as needed. Reduce slips, trips, and falls and severity of impact. Avoid costly floor repairs, cover cracks that may pose hazards, and improve aesthetics.

## 598/599 MAX NEW

- Our greatest innovation to date, combining ErgoDeck with our premium Nitricell<sup>®</sup> sponge to create ErgoDeck<sup>®</sup> MAX offers structural support AND impact absorption for healthier and more productive employees, even in multi-shift operations.
- ErgoDeck<sup>®</sup> MAX is best suited for dry environments, including manufacturing, transportation, automotive or fulfillment, anywhere workers stand on hard, cold, unforgiving concrete.
- 



598



599

Whether it's assembly lines, CNC workstations or quality control inspection, ErgoDeck<sup>®</sup> MAX will outperform expectations to reduce safety incidents and absenteeism, resulting in improved morale and productivity.

SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	598.78x18x18CH-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	BK	598.78x18x18BK-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	599.78x18x18CH-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	BK	599.78x18x18BK-CS10



**SPECIFICATIONS**

- Compound: PVC/Sponge
- Edges: Optional 6" (15cm) -
- Wide Safety Ramps
- Warranty: Lifetime



Underside

**ErgoDeck<sup>®</sup> MAX** carries our Limited-Lifetime Warranty.




## ErgoDeck® MAX A True Champion!

### Easy To Install

Large 18" x 18" (46 cm x 46 cm) tiles cover large areas quickly.

### Flexible PVC Foundation

Provides structural ergonomic support and impact absorption.

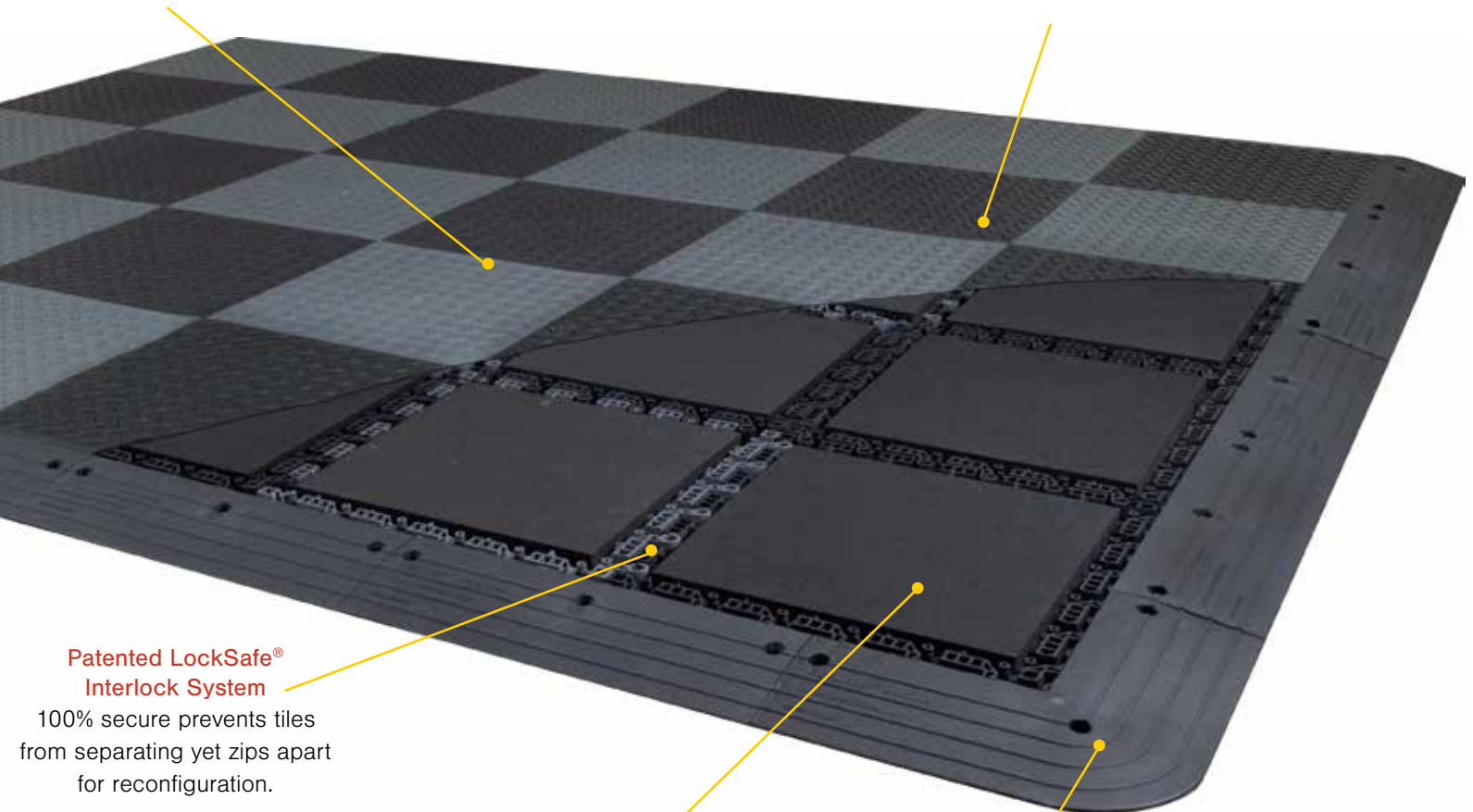

### Patented LockSafe® Interlock System

100% secure prevents tiles from separating yet zips apart for reconfiguration.

### Nitricell® Premium Sponge Core

Formulated for crush resistance and unmatched performance. Absorbs repeated compression and bounces back to its original form, at a rate that can't be beat by any other sponge in the industry.

### Universal Ramps

The 6" (15 cm) wide safety ramps work on our entire line of ErgoDeck® tiles.

**Wall-To-Wall ErgoDeck®** - All styles of ErgoDeck® connect together. So go ahead, mix and match.

**Value** - Easily replace single tiles or sections as needed. This keeps replacement costs down!

# ERGODECK® FLOORING

ErgoDeck® flooring has a patented LockSafe® mechanism guarantees secure connections that can be "zipped" apart when needed. If a tile wears out, simply pop it out and replace it.

PATENT US 8,006,443B2 PATENT US D5210,650S

ErgoDeck® Flooring boasts an amazing box spring underside design all the way through, offering amazing anti-fatigue properties. Patented LockSafe® technology, holds secure but can be taken apart and reconnected on demand. Available in a wide variety of styles, ErgoDeck® Flooring is made of 100% silicone-free PVC and has the versatility to perform well in any position.

The robust 7/8" (22mm)-thick tiles install quickly with no tools required. Tiles from the different ErgoDeck® models can be combined and cut to size in 3" (8cm) increments, making ErgoDeck® a highly customizable ergonomic flooring solution.

**590**

**Diamond-Plate**

**NEW**



Our two most popular products rolled into one! A double hitter, ErgoDeck General Purpose with Diamond-Plate surface scores across the board. The box-spring foundation compresses under foot providing anti-fatigue benefits and the necessary structure for rolling carts. The All-Star Diamond-Plate surface pattern provides traction and gives you the Industrial look your facility needs.



Additionally, you get all the benefits of having modular floor tiles:

- Quick installation with little downtime
- Patented LockSafe technology so tiles go together and stay together
- Ability to customize tiles on-site to build any shape or configuration that you need
- Tiles can be cut every 3" (7.5cm) and still connect
- Replace single tiles or sections as the work need changes or tiles get damaged

**SPECIFICATIONS**

Compound: PVC  
Edges: Optional 6" (15cm) - Wide Safety Ramps  
Warranty: Lifetime



SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	590.78x18x18CH-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	BK	590.78x18x18BK-CS10

## SLIPS, TRIPS, AND FALLS\*


**\$41,531**  
the average cost of a slip and fall claim

**42% INCREASE**  
in workers' compensation costs for slips and falls over the past 11 years

**3<sup>RD</sup> LEADING CAUSE**  
of missed work days

**\$13.5 BILLION**  
the national total for same level-fall workers' compensation claims

Watch The Video  
On ErgoDeck

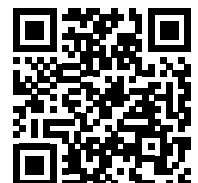

\* Source: National Safety Council Injury Facts, 2012 Ed.



# 568

## Smooth General Purpose



Ideal for light cart traffic and pivoting, ErgoDeck® Smooth™ offers the original general purpose compound, and has a high performance anti-fatigue surface that makes rolling, stopping and starting movements easier than ever. Unlike soft mats that deform under load, ErgoDeck Smooth features a firm, lightly textured, smooth surface without compromising traction. Optional 6" (22cm) wide ramps are cart friendly, allowing easy on-off access.



### SPECIFICATIONS

Compound: PVC  
Edges: Optional 6" (15cm) -  
Wide Safety Ramps  
Warranty: Lifetime

SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	BK	568.78x18x18BK-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	568.78x18x18CH-CS10

# 569

## Smooth Heavy Duty



ErgoDeck® Smooth™ Heavy Duty is a robust, high performance solution for wheeled-traffic that lightens your load to move heavy loads easily. It is definitely the heavy duty work horse for your environment. Optional 6" (22cm) wide ramps are cart friendly, allowing easy on-off access.



### SPECIFICATIONS

Compound: PVC  
Edges: Optional 6" (15cm) -  
Wide Safety Ramps  
Warranty: Lifetime

SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	BK	569.78x18x18BK-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	569.78x18x18CH-CS10

# 556/558

## Comfort



ErgoDeck® Comfort is the optimum defense for fatigue in work areas where there is a lot of foot traffic but little or no cart traffic. The softer compound and spring-back underside compress and rebound underfoot for a "rubber-like" feel. Comfort Solid is especially suited to work areas that remain relatively dry or that have slight over-spray.



With its flexible PVC compound and springy underside, ErgoDeck® Comfort Open is engineered with 15/16" (24mm) holes to cushion the impact of long-term standing and foot traffic in wet areas, providing resilient support underfoot and slip prevention.

*Also available in convenient kits for workstations! See page 33 for more details.*



### SPECIFICATIONS

Compound: PVC  
Edges: Optional 6" (15cm) -  
Wide Safety Ramps  
Warranty: Lifetime

556 ErgoDeck® Comfort Solid			
SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	556.78x18x18CH-CS10
558 ErgoDeck® Comfort Open			
SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	558.78x18x18CH-CS10



# ERGODECK® FLOORING

ErgoDeck® flooring has a patented LockSafe® mechanism guarantees secure connections that can be "zipped" apart when needed. If a tile wears out, simply pop it out and replace it.

PATENT US 8,006,443B2 PATENT US D5210,650S

## 564-567

## General Purpose



ErgoDeck® General Purpose is the best surface for team health and safety in areas with foot and light cart traffic. The softer compound compresses more underfoot, delivering enhanced fatigue relief, while the box-spring underside provides the necessary structure for rolling carts.



Designed for medium-duty work environments, ErgoDeck® General Purpose features a raised-texture surface that provides sure footing while enhancing workplace aesthetics. Regularly spaced with 15/16" (24mm) openings in the Open variation remove moisture from the surface, facilitating drainage. GRITSHIELD™ material can be added to both the Solid and Open models to increase traction.



SIZE	THICKNESS	COLOR	ITEM NUMBER
564 ErgoDeck® General Purpose Open			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	564.78x18x18BK-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	564.78x18x18CH-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	WH	564.78x18x18WH-CS10
565 ErgoDeck® General Purpose Open with GRITSHIELD™			
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	565.78x18x18CH-CS10
566 ErgoDeck® General Purpose Solid			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	566.78x18x18BK-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	566.78x18x18CH-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	YL	566.78x18x18YL-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	GN	566.78x18x18GN-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	RD	566.78x18x18RD-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	BL	566.78x18x18BL-CS10
18" x 18" (46cm x 46 cm)	7/8" (22mm)	WH	566.78x18x18WH-CS10
567 ErgoDeck® General Purpose Solid with GRITSHIELD™			
18" x 18" (46cm x 46 cm)	7/8" (22mm)	CH	567.78x18x18CH-CS10

### SPECIFICATIONS

Compound: PVC  
 Edges: Optional 6" (15cm) - Wide Safety Ramps  
 Warranty: **Lifetime** (564, 566)  
 1 Year (565, 567)



566 Stocked Colors!



White (WH) Blue (BL)



Green (GN) Yellow (YL)



Red (RD)



# 560-563

## Heavy Duty



ErgoDeck® Heavy Duty is designed for work areas with heavy foot traffic. The firmer compound supports heavier loads, while the underside box-spring design provides structural support and impact absorption to reduce heel strike, even in multi-shift operations.



In the Open variation, the perforated design facilitates drainage with 15/16" (24mm) holes, while the firm structure of the 100% silicone-free PVC compound provides a solid foundation for carts and workers. GRITSHIELD™ can be added to both the Solid and Open models for added traction.



SIZE	THICKNESS	COLOR	ITEM NUMBER
<b>560 ErgoDeck® Heavy Duty Open</b>			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	560.78x18x18BK-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	CH	560.78x18x18CH-CS10
<b>561 ErgoDeck® Heavy Duty Open w/GRITSHIELD™</b>			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	561.78x18x18BK-CS10
<b>562 ErgoDeck® Heavy Duty Solid</b>			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	562.78x18x18BK-CS10
18" x 18" (46cm x 46cm)	7/8" (22mm)	CH	562.78x18x18CH-CS10
<b>563 ErgoDeck® Heavy Duty Solid w/GRITSHIELD™</b>			
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	563.78x18x18BK-CS10

### SPECIFICATIONS

**Compound:** PVC  
**Edges:** Optional 6" (15cm) - Wide Safety Ramps  
**Warranty:** Lifetime (560, 562)  
 1 Year (561, 563)



 
## ErgoDeck® Custom Colors



White (WH)



Blue (BL)




Green (GN)



Yellow (YL)



 Orange (OR)



Red (RD)

### PROGRAM COLOR GUIDELINES

We can make any custom color to meet your needs. Just provide us a Pantone Color. There is a required minimum order quantity of 50 cases per part number. Ramps and corners are also available in colors with a 150 case minimum order quantity. Lead time is 4-6 weeks.

# ERGODECK® FLOORING

Cleats are tried-and-true gear for professional athletes who want winning performance and safety on the field. Whether on an oil rig or an engine line, ErgoDeck with No-Slip Cleats provides long-lasting traction and can endure harsh conditions and cleaning — even pressure washing! PATENT US 8,006,443B2 PATENT US D5210,650S

## 552/553


## Integrated No-Slip Cleats



ErgoDeck® flooring with Integrated No-Slip Cleats delivers a sure-footed work surface for maximum productivity, performance, and safety — even in the most demanding workplace conditions. The cleated design — modeled after the cleats that professional athletes wear for traction — overcomes harsh and slick workplace conditions.



While gritted mats provide some temporary traction, they wear with use and become slippery with saturation over time. ErgoDeck® with Integrated No-Slip Cleats, on the other hand, is built to last. Unlike gritted mats — which cannot be maintained and cleaned — ErgoDeck® with Integrated No-Slip Cleats can withstand power washing, scrubbing, and aggressive cleaning. Available in a closed design and an open with 15/16" (24mm) holes, for areas that have a lot of fluids.

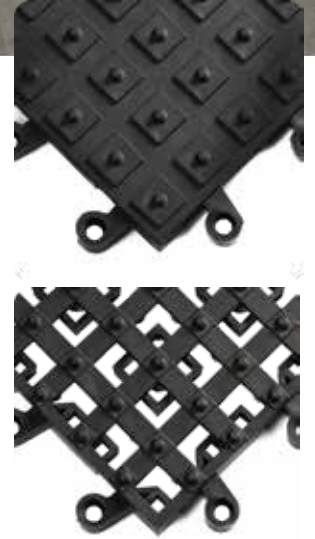

SIZE	THICKNESS	COLOR	ITEM NUMBER
<b>552 ErgoDeck® w/Integrated No-Slip Cleats Solid</b>			
18" x 18" (46cm X 46cm)	7/8" (22mm)	BK	552.78x18x18BK-CS10
18" x 18" (46cm X 46cm)	7/8" (22mm)	CH	552.78x18x18CH-CS10
<b>553 ErgoDeck® w/Integrated No-Slip Cleats Open</b>			
18" x 18" (46cm X 46cm)	7/8" (22mm)	BK	553.78x18x18BK-CS10
18" x 18" (46cm X 46cm)	7/8" (22mm)	CH	553.78x18x18CH-CS10

### SPECIFICATIONS

Compound: PVC  
 Edges: Optional 6" (15cm) - Wide Safety Ramps  
 Warranty: 3 Years






# 560/561/564

## Ramps / Corners





ErgoDeck® ramps and corners are compatible with all ErgoDeck® styles. Robust 6" (15cm) -wide ramps prevent trip hazards and allow easy access for wheeled traffic. Available with GRITSHIELD™ for additional traction.

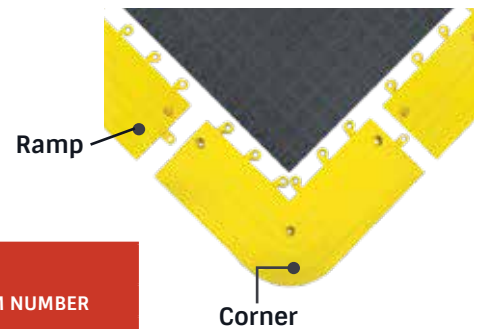

ERGODECK® RAMPS AND CORNERS				
SIZE	DESCRIPTION	COLOR	UOM	ITEM NUMBER
<b>OUTSIDE CORNERS</b>				
6" x 15" x 15" (15cm x 38cm x 38cm)	Heavy Duty	BK, YL	CS of 4	560.78x6x15x15-CS4
6" x 15" x 15" (15cm x 38cm x 38cm)	w/ GRITSHIELD	BK, YL	CS of 4	561.78x6x15x15-CS4
6" x 15" x 15" (15cm x 38cm x 38cm)	Heavy Duty	WH	CS of 4	564.78x6x15x15-CS4
<b>INSIDE CORNERS</b>				
6" x 9" x 9" (15cm x 23cm x 23cm)	Heavy Duty	BK, YL	EA	560.78x6x9x9
6" x 9" x 9" (15cm x 23cm x 23cm)	w/ GRITSHIELD	BK, YL	EA	561.78x6x9x9
6" x 9" x 9" (15cm x 23cm x 23cm)	Heavy Duty	WH	EA	564.78x6x9x9
<b>RAMPS</b>				
6" x 18" (15cm x 46cm)	Heavy Duty	BK, YL	CS of 10	560.78x6x18-CS10
6" x 18" (15cm x 46cm)	w/ GRITSHIELD	BK, YL	CS of 10	561.78x6x18-CS10
6" x 18" (15cm x 46cm)	Heavy Duty	WH	CS of 10	564.78x6x18-CS10

Be sure to specify color

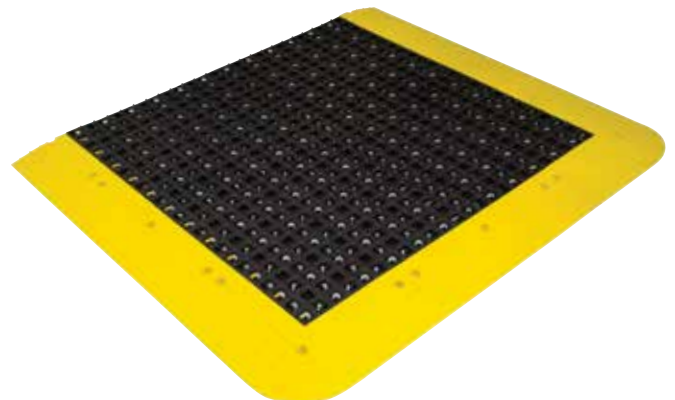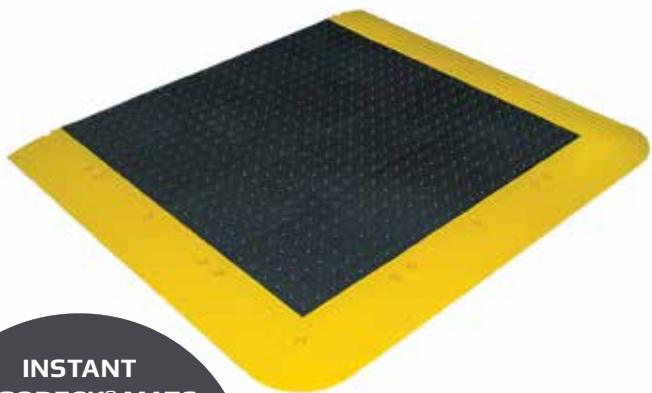

**INSTANT ERGODECK® MATS**  
 Need a workstation mat with tons of traction? Check out our ErgoDeck Integrated No-Slip Kits on page 32

**Universal to all ErgoDeck® products on pages 14-21**

# WEARWELL F.I.T.™ SYSTEM

F.I.T.™ Tiles are the most versatile 12" x 12" (30cm x 30cm) interlocking ergonomic flooring system on the market. Its patented LockSafe® connections and lightweight design make handling and maintenance a snap. US REG NO. 3,739,71



Today, workspaces are designed in a wide variety of shapes and sizes. That's where an easy, customizable solution like F.I.T.™ (Functional Interlocking Tiles) comes into play. The F.I.T.™ Tiles are 5/8" (16mm) thick, 12" (30cm) x 12" (30cm) interconnecting, 100% silicone free and feature a lightweight, flexible design that allows tiles to be cut and reconnected every three inches. While the LockSafe® Positive Interlocking System prevents separation during use, one can easily unzip tiles to replace single pieces or sections as needed.

Thanks to versatility and durability, the F.I.T.™ system can be used for many otherwise challenging applications. Cover a less-than-ideal floor (such as cracked concrete) with a F.I.T.™ system to provide standing relief, safety underfoot, and traction for workers — not to mention world-class aesthetics. Assemblies of the F.I.T.™ Tiles can also be rolled up without coming apart, making it an ideal solution for areas that require frequent cleaning.

See F.I.T. Kits on Pg. 34

## 548

## F.I.T.™ Comfort Deck

**NEW**



Out with the old and in with the new and improved!




Comfort Deck was a well-loved Wearwell product, but it had a few flaws. There were size limitations, it lacked anti-fatigue benefits and couldn't be customized. We set out to find a better solution.



F.I.T.™ Comfort Deck has the surface pattern loved by all with the benefits of F.I.T.!!




The highly textured surface design provides extra traction in slippery conditions. The tiles feature an open-hole design that allows for quick drainage resulting in a drier standing area. The unique nub pattern provides the ultimate comfort and anti-fatigue surface for your Industrial Athletes to stand on.

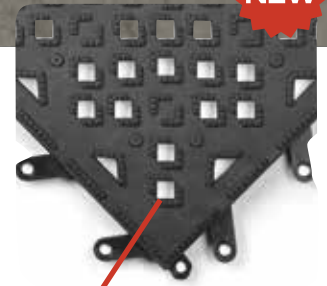

SIZE	THICKNESS	COLOR	ITEM NUMBER
12" x 12" (30cm x 30cm)	5/8" (16mm)	BK	548.58x12x12BK-CS20

**Who says you can't have it all!  
High traction and comfort in  
the all new F.I.T. Comfort Deck!**

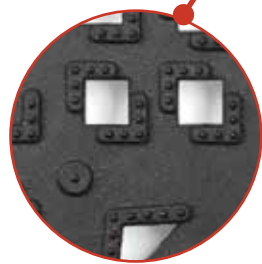

Unique high traction design

Slip Resistant  
Surface Pattern

**SPECIFICATIONS**

Compound: PVC

Edges: Optional 3" (8cm) Wide

Warranty: 1 Year



# 541/543

## F.I.T.™ Solid



F.I.T.™ Solid features a solid-top surface design for dry-area applications. Best for workspaces with only modest moisture and over-spray, these tiles are strong enough to withstand modest cart traffic while still delivering enough cushion to provide an ergonomic work surface for standing and mobile workers. Available with GRITSHIELD™ for extra traction.



SIZE	THICKNESS	COLOR	ITEM NUMBER
12" x 12" (30cm x 30cm)	5/8" (16mm)	BK	541.58x12x12BK-CS20
12" x 12" (30cm x 30cm)	5/8" (16mm)	BK	543.58x12x12BK-CS20*

\* GRITSHIELD™ option



### SPECIFICATIONS

Compound: PVC  
Edges: Optional 3" (8cm) Wide  
Warranty: 1 Year



# 540/542

## F.I.T.™ Open



F.I.T.™ Open features an open-11/16" (17mm) hole design for rapid and complete drainage of fluids. The surface slants towards the holes in the tiles to facilitate quick drainage and ensure a safe, dry standing area for workers. Use F.I.T.™ Open to convert wet and dirty floor areas into ergonomic work zones for your team. Available with GRITSHIELD™ for extra traction.



SIZE	THICKNESS	COLOR	ITEM NUMBER
12" x 12" (30cm x 30 cm)	5/8" (16mm)	BK	540.58x12x12BK-CS20
12" x 12" (30cm x 30 cm)	5/8" (16mm)	GN	540.58x12x12GN-CS20
12" x 12" (30cm x 30 cm)	5/8" (16mm)	RD	540.58x12x12RD-CS20
12" x 12" (30cm x 30 cm)	5/8" (16mm)	BK	542.58x12x12BK-CS20 *

\* GRITSHIELD™ option



### SPECIFICATIONS

Compound: PVC  
Edges: Optional 3" (8cm) Wide  
Warranty: 1 Year



# 540

## UNIVERSAL F.I.T.™ EDGING




SIZE	THICKNESS	COLOR	ITEM NUMBER
3" x 12" (8cm x 30cm)	5/8" (16mm)	BK	540.58x3x12BK-CS20
3" x 12" (8cm x 30cm)	5/8" (16mm)	YL	540.58x3x12YL-CS20
3" x 15" (8cm x 30cm)	5/8" (16mm)	BK	540.58x3x15BK-CS4*
3" x 15" (8cm x 30cm)	5/8" (16mm)	YL	540.58x3x15YL-CS4*

\*Ramp with corner

**All F.I.T.™ edging is universal to all F.I.T.™ tiles**

F.I.T. Tiles have 3" (8cm) - wide ramps that provide a visual cue and transition for on-off access. Compatible with all F.I.T. products.

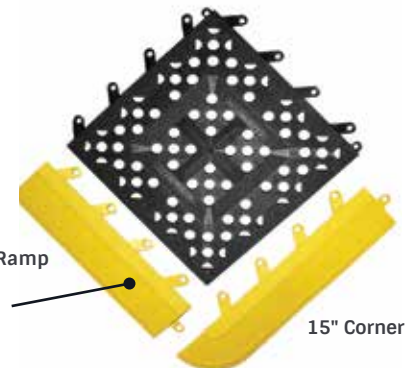

12" Ramp

15" Corner




**The goal is simple. Drive Up Performance While Upholding High Safety Standards.**

**50% IMPROVEMENT**  
in circulation and musculoskeletal health from  
standing on an anti-fatigue mat\*

\* Source: [medicalbillingandcoding.org](http://medicalbillingandcoding.org) and the University of Loughborough

# Manufacturing

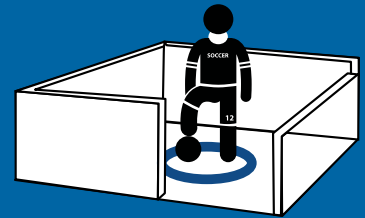

## MATTING

### What is ergonomic matting?

Ergonomic matting is the tried-and-true anti-fatigue solution for workstations and assembly lines. Made up of two layers — a surface and a sponge foundation — a mat should never be judged by its cover. Only Wearwell offers three types of sponge, giving you degrees of cushion, rebound, and resilience to choose from.

### Why ergonomic matting?

Ergonomic matting provides support to standing workers throughout your facility. Specially designed mats also act as a safety measure, defending against workplace dangers such as slips, trips, and falls, as well as contamination and high voltage. Studies show, too, that matting delivers quantifiable improvements in productivity and lost time.

### How do I install ergonomic matting?

Ergonomic matting comes in basic geometric shapes sized to fit in most standard workstation layouts. Manageable in size, they can be simply laid down or rolled out. Mats can also be cut to specified lengths, widths, and shapes. For larger and custom mats, consider handling and access to the area in question.

### Dual layer mats

We have a variety of familiar top surfaces, but the difference lies beneath. Only Wearwell gives you a choice of three sponges. The Dual-layer, laminated mat has a place on your field if:

- The area is dry with medium to heavy foot traffic
- Life expectancy in use is important
- Goals include heightened morale, productivity, health, and safety



# DIAMOND-PLATE

Wearwell was the first to introduce Diamond-Plate in 1989. Since then, we've continued to innovate. Today we offer more diamond-plate options than any competitor.

Prioritize your mat's features by importance and use the star treatment to choose the diamond plate that best fits the needs for your industrial athlete.



**GOOD**

**BETTER**

**BEST**



Compound	Urethane US REG. NO: 3,739,714	PVC	Nitrile Rubber
Product Family	497	495	414, 415, 416
Description	Made from 100% recycled urethane sponge, SMART® is a durable matting base that combines comfort, ecology, and economy. Best suited for dry commercial and industrial applications, this green material is a Wearwell exclusive.	Flex-Link™ is a PVC sponge comparable to those used by our competitors, at a similar price point. The difference is our tapered Flex-Link™ base, which offers a larger usable ergonomic area, reduces trip hazards, and keeps our mats from sliding.	No. 1 in customer satisfaction for over 20 years, Nitricell® is the industry original. Consistently outperforming competitors in critical categories, including comfort, customization, performance, rebound, and standing area. Available with GRITSHIELD™ for improved traction.
Standing Area	★	★★	★★★
Rebound	★★★	★	★★★
Life Expectancy	★	★★	★★★
Bevel	★	★★	★★★
Green	★★★	★	★
Price Point	★★★	★★	★
Value	★	★★	★★★
Customization	★	★	★★★
Warranty	1 Year	3 Years	Lifetime (414, 415 Standard) 4-Year (414, 415 Custom Mat) 1-Year (416)
Application			
Industry			
Colors			

Watch The Video On Diamond-Plate



# 415/414

## Nitricell® Diamond-Plate SpongeCote®

415 Nitricell® Diamond-Plate SpongeCote® 9/16" (14mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL, CHV, GY	415.916x2x3
2' x 75' (61cm x 23m)	BK, BYL, CHV, GY	415.916x2x75
3' x 5' (91cm x 1.5m)	BK, BYL, CHV, GY	415.916x3x5
3' x 10' (91cm x 3m)	BK, BYL, CHV, GY	415.916x3x10
3' x 20' (91cm x 6.1m)	BK, BYL, CHV, GY	415.916x3x20
3' x 75' (91cm x 23m)	BK, BYL, CHV, GY	415.916x3x75
4' x 75' (122cm x 23m)	BK, BYL, CHV, GY	415.916x4x75
5' x 75' (152cm x 23m)	BK, BYL	415.916x5x75
6' x 75' (1.9m x 23m)	BK, BYL	415.916x6x75

414 Nitricell® Diamond-Plate SpongeCote® UltraSoft 15/16" (24mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL, CHV, GY	414.1516x2x3
2' x 75' (61cm x 23m)	BK, BYL, CHV, GY	414.1516x2x75
3' x 5' (91cm x 1.5m)	BK, BYL, CHV, GY	414.1516x3x5
3' x 10' (91cm x 3m)	BK, BYL, CHV, GY	414.1516x3x10
3' x 20' (91cm x 6.1m)	BK, BYL, CHV, GY	414.1516x3x20
3 x 75' (91cm x 23m)	BK, BYL, CHV, GY	414.1516x3x75
4' x 75' (122cm x 23m)	BK, BYL, CHV, GY	414.1516x4x75
5' x 75' (152cm x 23m)	BK, BYL	414.1516x5x75
6' x 75' (1.9m x 23m)	BK, BYL	414.1516x6x75

# 416

## Nitricell® Diamond-Plate w/GRITSHIELD™

9/16" (14mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	416.916x2x3
2' x 75' (61cm x 23m)	BK	416.916x2x75
3' x 5' (91cm x 1.5m)	BK	416.916x3x5
3' x 10' (91cm x 3m)	BK	416.916x3x10
3' x 75' (91cm x 23m)	BK	416.916x3x75
4' x 75' (122cm x 23m)	BK	416.916x4x75

15/16" (14mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	416.1516x2x3
2' x 75' (61cm x 23m)	BK	416.1516x2x75
3' x 5' (91cm x 1.5m)	BK	416.1516x3x5
3' x 10' (91cm x 3m)	BK	416.1516x3x10
3' x 75' (91cm x 23m)	BK	416.1516x3x75
4' x 75' (122cm x 23m)	BK	416.1516x4x75

# 495

## Flex-Link™ Diamond-Plate Select

9/16" (14mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	495.916x2x3
2' x 75' (61cm x 23m)	BK, BYL	495.916x2x75
3' x 5' (91cm x 1.5m)	BK, BYL	495.916x3x5
3' x 75' (91cm x 23m)	BK, BYL	495.916x3x75
4' x 75' (122cm x 23m)	BK, BYL	495.916x4x75

15/16" (24mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	495.1516x2x3
2' x 75' (61cm x 23m)	BK, BYL	495.1516x2x75
3' x 5' (91cm x 1.5m)	BK, BYL	495.1516x3x5
3' x 75' (91cm x 23m)	BK, BYL	495.1516x3x75
4' x 75' (122cm x 23m)	BK, BYL	495.1516x4x75

# 497

## SMART® Diamond-Plate

5/8" (16mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	497.58x2x3
2' x 75' (61cm x 23m)	BK, BYL	497.58x2x75
3' x 5' (91cm x 1.5m)	BK, BYL	497.58x3x5
3' x 75' (91cm x 23m)	BK, BYL	497.58x3x75
4' x 75' (122cm x 23m)	BK, BYL	497.58x4x75

1" (25mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	497.1x2x3
2' x 75' (61cm x 23m)	BK, BYL	497.1x2x75
3' x 5' (91cm x 1.5m)	BK, BYL	497.1x3x5
3' x 75' (91cm x 23m)	BK, BYL	497.1x3x75
4' x 75' (122cm x 23m)	BK, BYL	497.1x4x75

All are available in cuts up to 75' (23m)

# 423

# Soft Rock



The modern and adaptable matting solution for labs, hotels, retail outlets and other facilities where workers stand on hard tiles and concrete. Easy to clean, Soft Rock is an affordable, anti-microbial solution that helps keep the workplace germ-free, meets ASTM G21-13 standards and is available in a wide array of colors.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x2x3
3' x 5' (91cm x 152cm)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x3x5
3' x 75' (91cm x 23m)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x3x75

Available in cuts up to 75'



SANDSTONE (SA)



BLUESTONE (BL)



TRAVERTINE (TR)



SLATE (SL)



GRANITE (GT)



COAL (CL)

### SPECIFICATIONS

**Compound:** PVC over Nitricell® Sponge

**Edges:** Machine Beveled

**Warranty:** 4 Years



# 447

# WeldSafe®



WeldSafe® has a specially formulated rubber surface that repels sparks and hot metal shards. With a melting point of over 500° Fahrenheit, the surface is perfect for welding workstations. WeldSafe® is backed with a nitrile-enhanced Nitricell® sponge base that absorbs repeated compression and bounces back to its original form better than any PVC sponge alternative. Available in 3/8" (9.5mm) and 3/4" (19mm) thicknesses, Accept no substitutes in your critical welding applications!



9/16" (14mm)-THICK		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	447.916x2x3
2' x 75' (61cm x 23m)	BK	447.916x2x75
3' x 5' (91cm x 1.5m)	BK	447.916x3x5
3' x 75' (91cm x 23m)	BK	447.916x3x75
4' x 75' (122cm x 23m)	BK	447.916x4x75

7/8" (22mm)-THICK		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	447.78x2x3
2' x 75' (61cm x 23m)	BK	447.78x2x75
3' x 5' (91cm x 1.5m)	BK	447.78x3x5
3' x 75' (91cm x 23m)	BK	447.78x3x75
4' x 75' (122cm x 23m)	BK	447.78x4x75

Available in cuts up to 75' (23m)

### SPECIFICATIONS

**Compound:** Rubber over Nitricell® Sponge

**Edges:** Machine Beveled

**Warranty:** 4 Years



# 438

# LightWorks Inspection Mat



LightWorks Inspection Mat is designed to enhance visual quality-control areas. The highly reflective white surface maximizes available light so imperfections don't go unnoticed during visual inspection. The clean aesthetic makes it a good choice for non-industrial environments, or for poorly lit areas where available light needs to be maximized. The Nitricell® sponge bounces back better than any PVC sponge alternative.



SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 5' (91cm x 152cm)	1/2" (13mm)	WH	438.12x3x5WH
3' x 50' (91cm x 15m)	1/2" (13mm)	WH	438.12x3x50WH

Available in cuts up to 50' (15m)

### SPECIFICATIONS

**Compound:** PVC over Nitricell® sponge

**Edges:** Machine Beveled

**Warranty:** 4 Years



# 431

# Corrugated SpongeCote® Mat



Corrugated SpongeCote® is a classic matting solution that offers durability and productivity enhancement. Popular long before Diamond-Plate surfaces became widely available, the signature surface pattern provides extra traction underfoot. The Flex-Link™ PVC sponge base is a budget-friendly fatigue-fighting solution.



1/2" (13mm) THICKNESS		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	431.12x2x3
2' x 60' (61cm x 18m)	BYL	431.12x2x60BYL
2' x 75' (61cm x 23m)	BK	431.12x2x75BK
3' x 5' (91cm x 152cm)	BK, BYL	431.12x3x5
3' x 60' (91cm x 18m)	BYL	431.12x3x60BYL
3' x 75' (91cm x 23m)	BK	431.12x3x75BK
4' x 75' (122cm x 23m)	BK	431.12x4x75BK

7/8" (22mm) - THICKNESS		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BYL	431.78x2x3
2' x 60' (61cm x 18m)	BYL	431.78x2x60BYL
2' x 75' (61cm x 23m)	BK	431.78x2x75BK
3' x 5' (91cm x 152cm)	BK, BYL	431.78x3x5
3' x 60' (91cm x 18m)	BYL	431.78x3x60BYL
3' x 75' (91cm x 23m)	BK	431.78x3x75BK
4' x 75' (122cm x 23m)	BK	431.78x4x75BK

## SPECIFICATIONS

**Compound:** PVC over Flex-Link™ Sponge

**Edges:** Safety Beveled

**Warranty:** 1 Year




Available in cuts up to 75' (23m) in Black and up to 60' (18m) in Black/Yellow

# 433

# ComfortPro™ Mat



ComfortPro™ is the best solution when a round-ribbed surface is a must. Easy to clean, the round-rib pattern provides good traction and is effective against slip hazards caused by spills. The Flex-Link™ PVC sponge base is a budget-friendly fatigue-fighting solution.

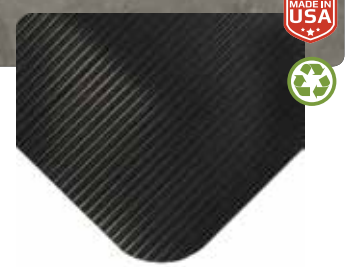

7/8" (22mm) THICKNESS		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	433.78x2x3
2' x 75' (61cm x 23m)	BK	433.78x2x75
3' x 5' (91cm x 152cm)	BK	433.78x3x5
3' x 75' (91cm x 23m)	BK	433.78x3x75
4' x 75' (122cm x 23m)	BK	433.78x4x75

1/2" (13mm) THICKNESS		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK	433.12x2x3
2' x 75' (61cm x 23m)	BK	433.12x2x75
3' x 5' (91cm x 152cm)	BK	433.12x3x5
3' x 75' (91cm x 23m)	BK	433.12x3x75
4' x 75' (122cm x 23m)	BK	433.12x4x75

## SPECIFICATIONS

**Compound:** PVC over Flex-Link™ Sponge

**Edges:** Safety Beveled

**Warranty:** 1 Year



Available in cuts up to 75' (23m)



## TOP PERFORMANCE DOESN'T HAPPEN BY LUCK


Productivity, efficiency and safety are part of every successful team's winning strategy. Your industrial athletes need to stay focused and at the top of their game with the best surface under-foot. Hit it out of the park with high-quality, ergonomic mats and flooring.

OVER  
**17%**

**Of All Disabling Workplace  
Injuries Result From Falls\***

\* Source: OSHA, Identification And Prevention of Slips, Trips & Falls

# Manufacturing

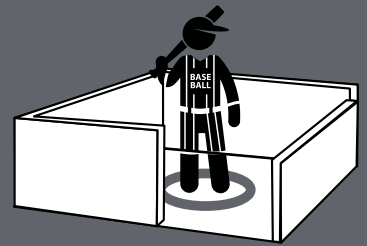

## PVC AND RUBBER

Today's workers are being asked to perform in a range of environments. Give your industrial athletes a competitive advantage with the right surface. PVC and rubber matting is the right call if:

- The area is wet, dry, or slippery
- Chemical resistance and water resistance are important
- Goals include drainage and elevation above fluids and delivering safety and support to workers

# ERGODECK® KITS



Each ErgoDeck® Kit has everything you need to set up an ergonomic workstation in minutes. ErgoDeck® rivals most rubber mats for maintenance, chemical resistance, and performance. No other interlock can touch the secure LockSafe® system! Regardless of the conditions, ErgoDeck® delivers!

## 552

### Integrated No-Slip Cleats Solid Kit



ErgoDeck® with Integrated No-Slip Cleats kits have all of the components necessary to create a non-slip workstation mat. No tools or cutting needed! Embedded in the tiles, No-Slip Cleats withstand pressure washing and other heavy-duty cleaning methods. These ultra-rugged kits are perfect for individual workstations that reside in some of the toughest industrial environments.

SIZE	THICKNESS	COLOR	ITEM NUMBER
42" x 48" (107cm x 122cm)	7/8" (22mm)	BYL	552.78x42x48BYL
42" x 66" (107cm x 1.7m)	7/8" (22mm)	BYL	552.78x42x66BYL
42" x 84" (107cm x 2.1m)	7/8" (22mm)	BYL	552.78x42x84BYL



#### SPECIFICATIONS

**Compound:** PVC  
**Edges:** 6" (15cm) - Wide YL Safety Ramps on 3 Sides  
**Warranty:** 3 Years



## 553

### Integrated No-Slip Cleats Open Kit




ErgoDeck® with Integrated No-Slip Cleats Open Kit is an easy and effective solution to the most slippery, wet work conditions. Built-in cleats deliver wear-resistant traction while the open-15/16" (24mm) hole design wicks away water from the work surface.

SIZE	THICKNESS	COLOR	ITEM NUMBER
42" x 48" (107cm x 122cm)	7/8" (22mm)	BYL	553.78x42x48BYL
42" x 66" (107cm x 1.7m)	7/8" (22mm)	BYL	553.78x42x66BYL
42" x 84" (107cm x 2.1m)	7/8" (22mm)	BYL	553.78x42x84BYL



#### SPECIFICATIONS

**Compound:** PVC  
**Edges:** 6" (15cm) - Wide YL Safety Ramps on 3 Sides  
**Warranty:** 3 Years

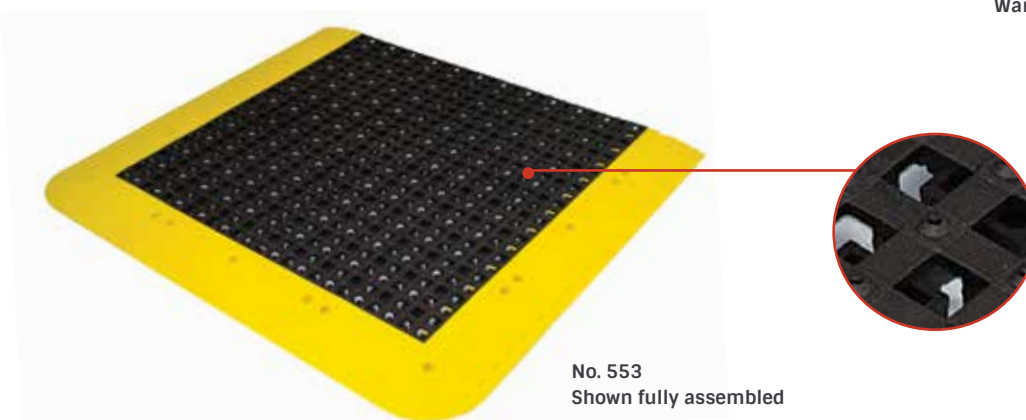

No. 553  
Shown fully assembled

# 556

## Comfort Kit



ErgoDeck® Comfort Kit includes everything you need to create a safe, long-lasting, ergonomic workstation. 7/8" (22mm) -thick PVC, they are engineered to be as resilient as rubber. No cutting, gluing, or tools are required for assembly thanks to our LockSafe® Positive Interlocking System. Just snap the components together and you've got a high-performance standing solution versatile enough to cover wet or dry work areas.

SIZE	THICKNESS	COLOR	ITEM NUMBER
42" x 48" (107cm x 122cm)	7/8" (22mm)	CHYL	556.78x42x48CHYL
42" x 66" (107cm x 1.7m)	7/8" (22mm)	CHYL	556.78x42x66CHYL
42" x 84" (107cm x 2.1m)	7/8" (22mm)	CHYL	556.78x42x84CHYL



### SPECIFICATIONS

**Compound:** PVC  
**Edges:** 6" (15cm) - Wide YL Safety Ramps on 3 Sides  
**Warranty:** Lifetime



# 566

## General Purpose Kit



ErgoDeck® General Purpose (GP) provides a stable, solid, and resilient foundation underfoot. It features a raised textured design that provides sure footing while enhancing workplace aesthetics. ErgoDeck General Purpose has the same box-spring foundation as ErgoDeck Heavy Duty, but is made with a softer compound for greater anti-fatigue benefit. 6" (15cm) wide yellow borders on 3 sides offers trip and safety prevention through a gradual slope for easy on/off access.

SIZE	THICKNESS	COLOR	ITEM NUMBER
42" x 48" (107cm x 122cm)	7/8" (22mm)	CHYL	566.78x42x48CHYL
42" x 66" (107cm x 1.7m)	7/8" (22mm)	CHYL	566.78x42x66CHYL
42" x 84" (107cm x 2.1m)	7/8" (22mm)	CHYL	566.78x42x84CHYL



### SPECIFICATIONS

**Compound:** PVC  
**Edges:** 6" (15cm) - Wide YL Safety Ramps on 3 Sides  
**Warranty:** Lifetime



**NEED A LARGER SIZE?**  
 Check out pages 14-21 for a highly customizable solution for any size area!

# F.I.T.™ KITS



Each F.I.T.™ Kit contains everything you need to create a complete workstation mat. Assemble the kit in minutes without any cutting or gluing — no tools required!

US REG. NO. 3,739,710

## 544/545/548

## F.I.T.™ Kit



A F.I.T.™ Kit is a remarkably simple and versatile matting solution for nearly any environment. Each kit contains everything you need to create an ergonomic workstation. No tools or cutting required! Snap it together in five minutes and use it for years.

PRODUCT	SIZE	THICKNESS	COLOR	ITEM NUMBER
F.I.T.™ Open	27" x 30" (69cm x 76cm)	5/8" (16mm)	BYL	544.58x27x30BYL
F.I.T.™ Open	27" x 42" (69cm x 107cm)	5/8" (16mm)	BYL	544.58x27x42BYL
F.I.T.™ Open	27" x 54" (69cm x 137cm)	5/8" (16mm)	BYL	544.58x27x54BYL
F.I.T.™ Open	27" x 66" (69cm x 1.7m)	5/8" (16mm)	BYL	544.58x27x66BYL
F.I.T.™ Open	27" x 90" (69cm x 2.3m)	5/8" (16mm)	BYL	544.58x27x90BYL
F.I.T.™ Open	39" x 66" (99cm x 1.7m)	5/8" (16mm)	BYL	544.58x39x66BYL
F.I.T.™ Open	27" x 30" (69cm x 76cm)	5/8" (16mm)	BYL	545.58x27x30BYL *
F.I.T.™ Open	27" x 42" (69cm x 107cm)	5/8" (16mm)	BYL	545.58x27x42BYL *
F.I.T.™ Open	27" x 54" (69cm x 1.4m)	5/8" (16mm)	BYL	545.58x27x54BYL *
F.I.T.™ Open	27" x 66" (69cm x 1.7m)	5/8" (16mm)	BYL	545.58x27x66BYL *
F.I.T.™ Open	27" x 90" (69cm x 2.3m)	5/8" (16mm)	BYL	545.58x27x90BYL *
F.I.T.™ Open	39" x 66" (99cm x 1.7m)	5/8" (16mm)	BYL	545.58x39x66BYL *
F.I.T.™ Comfort Deck	27" x 30" (69cm x 76cm)	5/8" (16mm)	BYL	548.58x27x30BYL
F.I.T.™ Comfort Deck	27" x 42" (69cm x 107cm)	5/8" (16mm)	BYL	548.58x27x42BYL
F.I.T.™ Comfort Deck	27" x 54" (69cm x 137cm)	5/8" (16mm)	BYL	548.58x27x54BYL
F.I.T.™ Comfort Deck	27" x 66" (69cm x 1.7m)	5/8" (16mm)	BYL	548.58x27x66BYL
F.I.T.™ Comfort Deck	27" x 90" (69cm x 2.3m)	5/8" (16mm)	BYL	548.58x27x90BYL
F.I.T.™ Comfort Deck	39" x 66" (99cm x 1.7m)	5/8" (16mm)	BYL	548.58x39x66BYL

### SPECIFICATIONS

**Compound:** PVC

**Edges:** 3" (8cm) -Wide Safety Ramps on 3 Sides

**Warranty:** 1 Year




w/GS

\* GRITSHIELD™ option



Angled surface design routes fluids through 11/16" (17mm) holes for quick drainage!

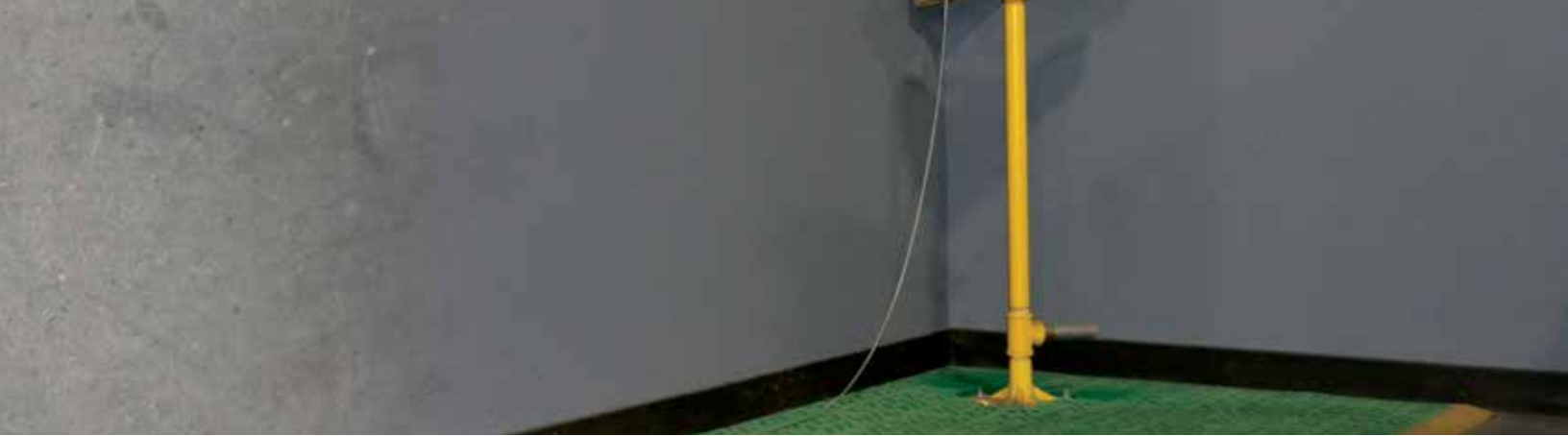

# 546 F.I.T.™ Emergency Eyewash Kit




F.I.T.™ Emergency Eyewash Kit is a remarkably simple, compact, and versatile matting solution that enables you to designate an eyewash station properly.



The kit's green tiles and yellow borders ensure high visibility for the station once assembled. Conforms to ANSI Z535.1-1998 Standard



SIZE	THICKNESS	COLOR	ITEM NUMBER
27" x 30" (69cm x 76cm)	5/8" (16mm)	GNYL	546.58x27x30GNYL
27" x 42" (69cm x 107cm)	5/8" (16mm)	GNYL	546.58x27x42GNYL

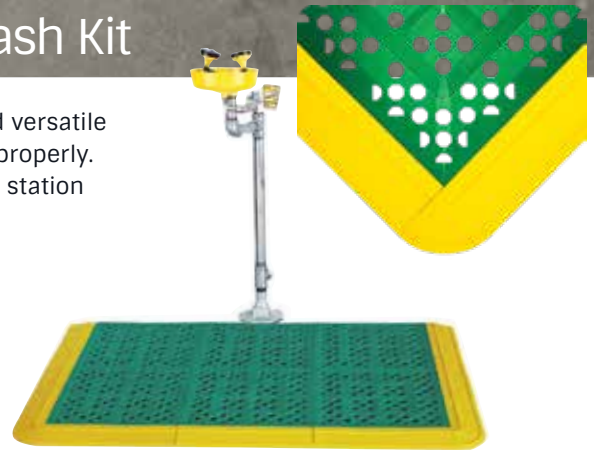

### SPECIFICATIONS

**Compound:** PVC

**Edges:** 3" (8cm) -Wide Safety

Ramps on 3 Sides

**Warranty:** 1 Year



# 546 F.I.T.™ Emergency Shower Kit



F.I.T.™ Emergency Shower Kit is a compact, simple way to make your workplace's emergency shower visible. The kit ships with red F.I.T.™ Tiles and yellow borders that, once assembled, will clearly identify the station in case of an emergency. Conforms to ANSI Z535.1-1998 Standard



SIZE	THICKNESS	COLOR	ITEM NUMBER
27" x 30" (69cm x 76cm)	5/8" (16mm)	RDYL	546.58x27x30RDYL
27" x 42" (69cm x 107cm)	5/8" (16mm)	RDYL	546.58x27x42RDYL



### SPECIFICATIONS

**Compound:** PVC

**Edges:** 3" (8cm)-Wide Safety


Ramps on 3 Sides

**Warranty:** 1 Year



# 373

# Elevate XTREME

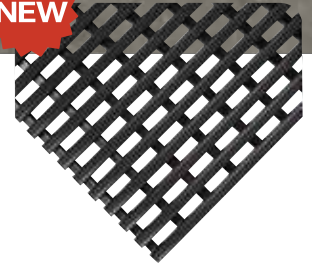

Elevate XTREME is engineered to perform in oily, slippery environments where traditional products fail. Coming in at a **robust 7/8" thick**, it elevates Industrial Athletes above any pooling fluids and delivers reliable slip resistance. Elevate XTREME excels in a wide range of operations and installations – even **over grating!**

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 33' (91cm x 10m)	7/8" (22mm)	BK	373.78x3x33BK
Connector Clips		BK	373.XTREMECLIP-PK10
Aluminum Edging 2.5" x 78" (63.5mm x 198cm)		AL	373.2.5x78AL

### SPECIFICATIONS

Compound- PVC  
Edges- Square  
Warranty- 3 years



### CUSTOMIZABLE ON-SITE


Wider, longer, over-sized mats have never been easier or more economical than with the use of Elevate XTREME connector clips.



Easy snap connectors

# 371

# Elevate OR

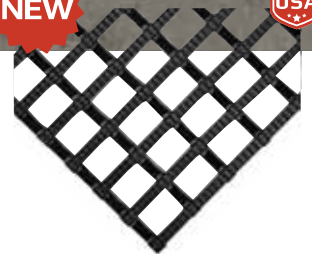


Finally! A lightweight, out of the box solution for wet, slippery areas that you've been waiting for! Whether it is oils or liquids, indoors or out, the hazards and challenges are the same for hard-working Industrial Athletes. They want to do their best, but how can they in wet, slippery conditions? It's time to "Elevate" Industrial Athletes everywhere with the newest innovation from Wearwell. Elevate OR was designed to solve a variety of challenges across multiple industries.

Available in cuts 10' (3m) up to 33' (10m)

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 33' (91cm x 10m)	5/8" (16mm)	BK	371.58x3x33BK
Connectors		BK	370.Connector-PK10
Floor Hook		BK	370.FloorHook-PK10

### SPECIFICATIONS

 Compound- PVC  
Edges- Square  
Warranty- 3 years



Overall thickness  
5/8" (16mm)




Easy snap connectors

*"We have a moral, as well as a legal, responsibility to send our employees home at the end of the workday in a condition no worse than when they come in that morning" — Ed. G Mohr, C.S.P. Coordinator, Ergonomics and Safety Engineering, General Motors Corporation, Auburn Hills, MI*

# 468

## WorkRite II

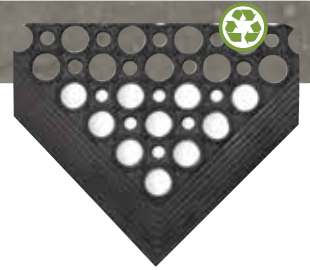

WorkRite II has all of the great features of our popular WorkRite rubber mat, lightweight 1/2" (16mm) -thick design, plus a unique molded-in stepped beveled edge for an easier transition. Still perfect for caustic wet and dry areas, and simple to keep clean with its hygienic open design with 7/8" (22mm) holes.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 5' (91cm x 152cm)	1/2" (12mm)	BK	468.12x3x5BK
3' x 10' (91cm x 3m)	1/2" (12mm)	BK	468.12x3x10BK
3' x 20' (91cm x 6.1m)	1/2" (12mm)	BK	468.12x3x20BK

**SPECIFICATIONS**  
**Compound:** GR: Natural Rubber  
**Edges:** Molded-in Safety Bevel  
**Warranty:** 1 Year



# 470

## Modular Diamond-Plate



Modular Diamond-Plate brings a popular look to the world of rubber mats. Available in both Grease Resistant (GR) and Grease Proof (GP) 3' x 3' (91cm x 91cm) interlocking tiles it is 1/2" (12mm) thick — below the OSHA recommended 5/8" (16mm) threshold for trip hazards — and has rounded edges.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 3' (91cm x 91cm)	1/2" (12mm)	BK	470.12x3x3GPBK
3' x 3' (91cm x 91cm)	1/2" (12mm)	BK	470.12x3x3GRBK

**SPECIFICATIONS**  
**Compound:** GP: 50% Nitrile Rubber or GR: Natural Rubber  
**Edges:** Safety Rounded  
**Warranty:** 1 Year



# 454

## Ortho Stand™



Ortho Stand™ has a distinctive bubble surface design that provides great performance at an economical price point. Constructed of durable natural rubber, Ortho Stand™ is a solid contender in the battle against fatigue.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (12mm)	BK, BYL	454.12x2x3
3' x 4' (91cm x 122cm)	1/2" (12mm)	BK, BYL	454.12x3x4

**SPECIFICATIONS**  
**Compound:** GR: Natural Rubber  
**Edges:** Molded-in Safety Bevel  
**Warranty:** 1 Year



# 24/SEVEN®



The 24/Seven® modular mat is a family of high-performance, interconnecting rubber anti-fatigue mats available in three distinct rubber formulations: GR (Grease Resistant), for areas with water or dry debris; CFR (Cutting-Fluid Resistant), for areas with mineral oil-based fluids; and NBR (Nitrile Rubber), for maximum effectiveness in areas with petroleum-based fluids.

## 24/SEVEN®

The 24/Seven® is a collection of high performance, 3' (91cm) x 3' (91cm), interconnecting rubber anti-fatigue mats. These resilient modular mats are 5/8" (16mm) thick and tough enough to handle 24/7 shift operations, while still being supple enough to provide cushioned support where it's needed. Because of its modularity, mats in this family can be combined and positioned to cover large flooring areas quickly. Also use them for single workstations and assembly lines. 24/Seven® mats are available with a wide variety of options. Three different rubber compounds provide resistance against grease (GR), cutting fluid (CFR), and petroleum-based fluids (NBR). Choose from a solid mat design for drier areas or a perforated 15/16" hole variation to maximize drainage in wet workspaces. GRITSHIELD™ material can also be added to increase traction, if needed.



## 570CFR-576CFR

## Cutting-Fluid Resistant



24/Seven® Cutting-Fluid Resistant (CFR) is made of a specially formulated rubber engineered to resist mineral oil. It is also effective against silicone-based brake fluid, boric acid, and ethylene glycol. 24/Seven® mats made with the CFR compound are available in solid and drainage variations, as well as with GRITSHIELD™.



### SPECIFICATIONS

**Compound:** CFR:  
Cutting-Fluid Resistant

**Edges:** Optional 3" (8cm) - Wide Male and Female Safety Ramps


**Warranty:** 1 Year



w/GS

SIZE	THICKNESS	COLOR	ITEM NUMBER
<b>570CFR 24/Seven® Solid Cutting-Fluid Resistant</b>			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	570.58x3x3CFRBK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	*574.58x3x3CFRBK
<b>572CFR 24/Seven® Open Cutting-Fluid Resistant</b>			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	572.58x3x3CFRBK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	*576.58x3x3CFRBK
<b>24/Seven® Cutting-Fluid Resistant Edging</b>			
3" x 39" (8cm x 99cm)	5/8" (16mm)	BK, YL	572.EdgingFCFR
3" x 39" (8cm x 99cm)	5/8" (16mm)	BK, YL	572.EdgingMCFR

\* GRITSHIELD™ option

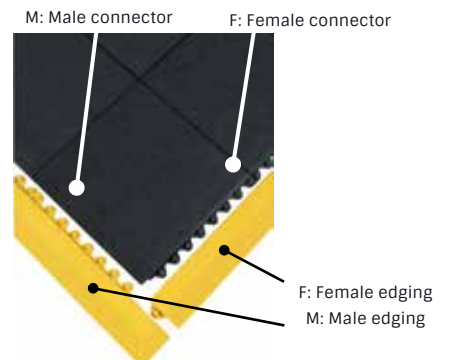



## 570GR/572GR

## Grease Resistant



24/Seven® Grease Resistant (GR) is made of high-quality molded rubber. Designed for areas with water and dry debris, it is also resistant to boric acid and ethylene glycol. 24/Seven® mats made with the GR compound are available in solid and drainage variations.



SIZE	THICKNESS	COLOR	ITEM NUMBER
570GR 24/Seven® Solid Grease Resistant			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	570.58x3x3GRBK
572GR 24/Seven® Open Grease Resistant			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	572.58x3x3GRBK
24/Seven® Grease Resistant Edging			
3" x 39" (8cm x 100cm)	5/8" (16mm)	BK, YL	572.EdgingFGR
3" x 39" (8cm x 100cm)	5/8" (16mm)	BK, YL	572.EdgingMGR

### SPECIFICATIONS

**Compound:** GR:  
Grease Resistant

**Edges:** Optional 3" (8cm) - Wide Male and Female Safety Ramps

**Warranty:** 1 Year



F: Female connector  
M: Male connector

## 570NBR-576NBR

## Nitrile Rubber



24/Seven® Nitrile Rubber's (NBR) compound is the most resistant in the 24/Seven® family. It stands up to all of the fluids resisted by the GR and CFR formulations, as well as animal fats, brake fluid, chlorine solution, diesel oil, petroleum-based hydraulic oil, salt water, and vegetable oil. 24/Seven® mats made with the NBR compound are available in solid and drainage variations, as well as with GRITSHIELD™.



SIZE	THICKNESS	COLOR	ITEM NUMBER
570NBR 24/Seven® Solid Nitrile Rubber			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	570.58x3x3NBRBK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	*574.58x3x3NBRBK
572NBR 24/Seven® Open Nitrile Rubber			
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	572.58x3x3NBRBK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	*576.58x3x3NBRBK
24/Seven® Nitrile Rubber Edging			
3" x 39" (8cm x 99cm)	5/8" (16mm)	BK, YL	572.EdgingFNBR
3" x 39" (8cm x 99cm)	5/8" (16mm)	BK, YL	572.EdgingMNBR

\* GRITSHIELD™ option

### SPECIFICATIONS

**Compound:** NBR: Nitrile Rubber

**Edges:** Optional 3" (8cm) - Wide Male and Female Safety Ramps

**Warranty:** 1 Year



w/GS

F: Female connector  
M: Male connector



# WORKSAFE®

Work safe in areas that have oily environments. Independent machine and tool shops, as well as in-house departments will benefit from WorkSafe® matting solutions.

## 476


## Industrial WorkSafe®



Industrial WorkSafe® now comes equipped with more options to fit today's demanding workplaces and budgets. Lighter, 5/8" (16mm) thick, 7/8" holes and upgraded rubber formulations, the reworked WorkSafe® features an array of price points and performance options.

SIZE	THICKNESS	COMPOUND	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	GR, NBR*	BYL, BOR, BK	476.58x2x3
3' x 4' (91cm x 122cm)	5/8" (16mm)	GR, NBR*	BYL, BOR, BK	476.58x3x4
3' x 5' (91cm x 152cm)	5/8" (16mm)	GR, NBR*	BYL, BOR, BK	476.58x3x5
3' x 9.8' (91cm x 3m)	5/8" (16mm)	GR, NBR*	BYL, BOR, BK	476.58x3x9.8

\*NBR available in BYL only

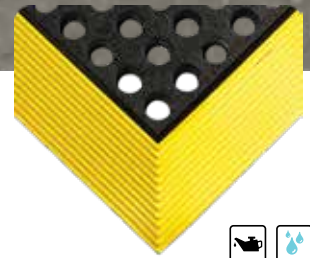


### SPECIFICATIONS

**Compound:** GR: Natural Rubber or NBR: Nitrile Rubber

**Edges:** Molded-in Safety Borders

**Warranty:** 1 Year

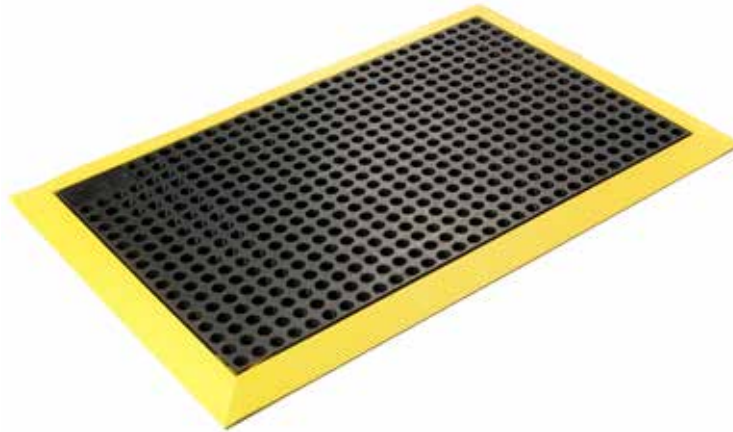


## 478

## WorkSafe® Light



WorkSafe® Light is an invaluable matting solution for cutting-fluid environments where sure footing, quick drainage, and fatigue reduction are essential. 7/8" holes, this mat is popular for its versatility and dependability, WorkSafe® Light will never let you down, and always lifts you up!

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 5' (91cm x 152cm)	1/2" (12mm)	GY	478.12x3x5GY
3' x 10' (91cm x 3m)	1/2" (12mm)	GY	478.12x3x10GY
3' x 20' (91cm x 6m)	1/2" (12mm)	GY	478.12x3x20GY

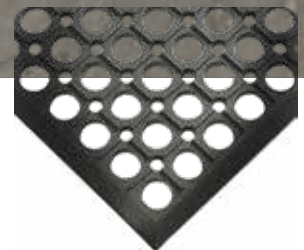

### SPECIFICATIONS

**Compound:** CFR: Cutting-Fluid Resistant Rubber

**Edges:** Molded-in Safety Bevel

**Warranty:** 1 Year






# 477

## WorkSafe® Grease Resistant



WorkSafe® is a veteran All-Pro who remains unfazed. Thick and resilient, tough as all get-out, WorkSafe® is still versatile enough to fit most any workstation. Never underestimate this top seller – the gentle giant among rubber standing mats!

SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 24" (46cm x 61cm)	7/8" (22mm)	BK	477.78x18x24GRBK
18" x 48" (46cm x 122cm)	7/8" (22mm)	BK	477.78x18x48GRBK
28" x 40" (71cm x 102cm)	7/8" (22mm)	BOR, BYL	477.78x28x40
2' x 3' (61cm x 91cm)	7/8" (22mm)	BK	477.78x2x3GRBK
3' x 30" (91cm x 76cm)	7/8" (22mm)	BK	477.78x3x30GRSBK
3' x 4' (91cm x 122cm)	7/8" (22mm)	BK	477.78x3x4GRBK
3' x 5' (91cm x 152cm)	7/8" (22mm)	BK	477.78x3x5GRSBK
40" x 124" (102cm x 3m)	7/8" (22mm)	BOR, BYL	477.78x40x124
40" x 52" (102cm x 132cm)	7/8" (22mm)	BOR, BYL	477.78x40x52
40" x 64" (102cm x 1.7m)	7/8" (22mm)	BOR, BYL	477.78x40x64
2" x up to 65' (5cm x up to 20m)	3/4" (19mm)	OR	477.EdgingOR
2" x 65' (5cm x 20m)	3/4" (19mm)	OR	477.EdgingRollOR
2" x 65' (5cm x 20m)	3/4" (19mm)	YL	477.EdgingRollIYL
2" x up to 65' (5cm x up to 20m)	3/4" (19mm)	YL	477.EdgingYL
Connectors	—	—	Connector.WSH.BK

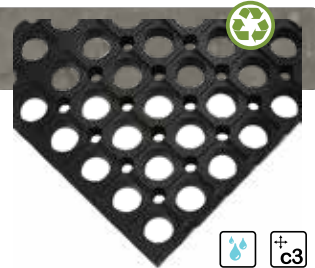


**SPECIFICATIONS**

**Compound:** GR: Natural Rubber  
**Edges:** Optional Attached Safety Edging  
**Warranty:** 1 Year



Connector

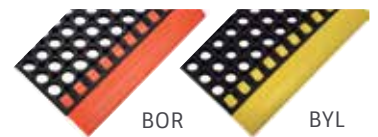

BOR

BYL


# 472

## Modular WorkSafe® Light



These innovative 3' x 3' (91cm x 91cm) mats interlock with no additional attachments. At 1/2" (12mm) thick, the mat features rounded outer edges that eliminate the need for beveled ramps and built-in connectors that allow you to easily assemble a larger ergonomic mat that works in wet, dry, or even greasy environments.

SIZE	THICKNESS	COMPOUND	COLOR	ITEM NUMBER
3' x 3' (91cm x 91cm)	1/2" (12mm)	GP	BK	472.12x3x3GPBK
3' x 3' (91cm x 91cm)	1/2" (12mm)	GR	BK	472.12x3x3GRBK

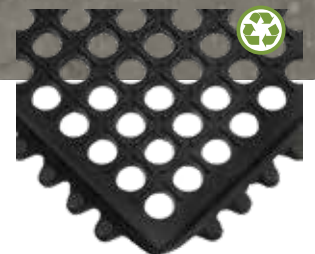

**SPECIFICATIONS**

**Compound:** GP: 50% Nitrile Rubber or GR: Natural Rubber

**Edges:** Safety Rounded

**Warranty:** 1 Year



GR

GP

c3




An Ounce of Prevention is a slam dunk.

Over  
**2,600** illnesses

In **2015** from **food contamination**  
that occurred during processing\*

\*Food Safety News Compilation - The 10 Biggest U.S. Food-borne Illness Outbreaks of 2015

# Food Prep/ Processing

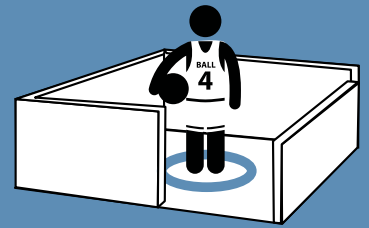

## Prevention

You know the saying . . . an ounce of prevention . . .

The stakes are higher in food prep and processing areas. Sanitary environments are non-negotiable for the prevention of contamination.

Keep your industrial athletes safe in wet or slick areas, alert through anti-fatigue properties, all with flooring and matting solutions made specially for prevention of contamination, from one end of the playing field to the other.

# 370

# Elevate AFR

**NEW**



Finally! A lightweight, out of the box solution for wet, slippery areas that you've been waiting for! Whether it's oils or liquids, indoors or out, the hazards and challenges are the same for hard-working Industrial Athletes. They want to do their best, but how can they in wet, slippery conditions? It's time to "Elevate" Industrial Athletes everywhere with the newest innovation from Wearwell. Elevate was designed to solve a variety of challenges across multiple industries.



Elevate AFR (Animal Fat Resistant) is the right call if you're in the food processing and preparation industry. It is made from a flexible animal fat resistant PVC specifically designed to perform in these tough environments. The anti-microbial and anti-fungal additives provide a hygienic surface for employees to work on. The widely spaced grid design allows fluids and by-products to fall through while elevating employees above it. The aggressive diamond cut surface pattern gives much needed traction in wet and greasy environments. It's up to 1/3 the weight of conventional rubber drainage mats so it is easy to roll-up and move out of the way for routine maintenance.

Elevate is also available in (OR) Oil Resistant, see page 36.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 33' (91cm x 10m)	1/2" (13mm)	TC	370.58x3x33TC
Connectors		BK	370.Connector-PK10
Floor Hook		BK	370.FloorHook-PK10

Available in cuts 10' (3m) up to 33' (10m)




**SPECIFICATIONS**


**Compound:** Animal Fat Resistant PVC infused w/anti-microbial and anti-fungal additives

**Edges:** Square

**Warranty:** 3 Years

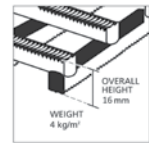

Overall thickness 5/8" (16mm)

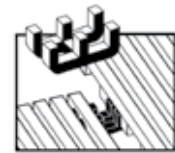


Easy snap connectors



**LIGHTWEIGHT**  
Made with Animal Fat Resistant PVC

**QUICK DRAIN DESIGN**  
Delivers sure-footed workflow in wet or slippery conditions.

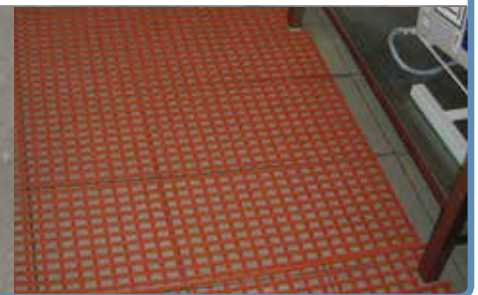

*Wearwell makes the grade in food processing with mats for wide/long areas and individual workstations!*

# 482

# Grade "A"®



Grade "A"® mats combat fatigue while addressing issues specific to food production environments. Lightweight with built-in handles, these mats are easy to maintain. The proprietary nitrile compound passes NSF test ASTM G21-96 (2002), has GRAS status, and is CFIA approved. PATENT US D609,050S

SIZE	THICKNESS	COLOR	ITEM NUMBER
30" x 36" (76cm x 91cm)	1/2" (13mm)	TC	482.12x30x36TC
30" x 60" (76cm x 152cm)	1/2" (13mm)	TC	482.12x30x60TC




**SPECIFICATIONS**

**Compound:** GP: Nitrile Rubber

**Edges:** Molded Safety Edges


**Warranty:** 2 years

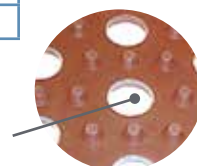

Open underside allows fluids and particles to pass freely

# 474

## WorkRite

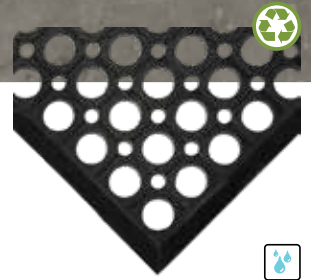

WorkRite's lightweight 1/2" (13mm) -thick design and molded-in beveled edges set the standard for all other rubber mats. It is economical, suitable for both non-caustic wet and dry areas, and simple to keep clean with its hygienic open design.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 5' (91cm x 152cm)	1/2" (13mm)	BK	474.12x3x5BK
3' x 10' (91cm x 3m)	1/2" (13mm)	BK	474.12x3x10BK
3' x 20' (91cm x 6.1m)	1/2" (13mm)	BK	474.12x3x20BK

**SPECIFICATIONS**  
**Compound:** GR: Natural Rubber  
**Edges:** Molded-in Safety Bevel  
**Warranty:** 1 Year


# 223
 
## Sole-Solution Foot Bath Mat



Optimal solution for facilities where contamination or grease build-up prevention is a necessity. With deep 2.5" (6cm) walls and 5-gallon (18.9 liter) capacity, the Sole-Solution foot bath is an affordable, effective solution that helps improve safety and fight cross-contamination. Resists bacteria growth and swipe pattern provides traction while eliminating collection points for debris.

SIZE	THICKNESS	COLOR	ITEM NUMBER
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	BK	223.2.5x31x38BK
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	BL	223.2.5x31x38BL
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	BYL	223.2.5x31x38YL



**SPECIFICATIONS**  
**Compound:** HDPE  
 (High-density polyethylene)  
**Edges:** Molded Containment Walls  
**Warranty:** 1 Year

*This lightweight packs a heavy punch! Sole-Solution holds 5 gallons (18.9 liters) of solution, bringing the total weight to 46 lbs (20.86 Kg), making this lightweight a heavy hitter!*

# 222

## Sanitizing Footbath Mat



The Sanitizing Footbath Mat decontaminates shoes and boots, which can spread harmful germs and bacteria in food-production facilities. Fill the mat's 1/2" (16mm) - or 2 1/2" (6cm) -deep well with disinfectant solution and then step in to clean footwear.

SIZE	THICKNESS	COLOR	ITEM NUMBER
24" x 32" (61cm x 81cm)	1/2" (13mm)	BK	222.12x24x32BK
32" x 39" (81cm x 99cm)	2 1/2" (6cm)	BK	222.2.5x32x39BK
32" x 39" (81cm x 99cm)	2 1/2" (6cm)	BYL	222.2.5x32x39BYL

**SPECIFICATIONS**  
**Compound:** GR: Natural Rubber  
**Edges:** Molded Containment Walls  
**Warranty:** 1 Year



## Serving The Customer


More than ever before, customers demand delivery that's accurate and fast. The number of distribution focused companies trying to meet those needs is growing. Get an edge on the competition by installing the right ergonomic surface to maximize the productivity and stamina of your industrial athletes.

**\$360,000**

**in average annual savings related to anti-fatigue mats for a company with 175 standing workers.\***

\* Source: Wearwell independent study  
see infographic on page 9 for more information

# Fulfillment & Shipping

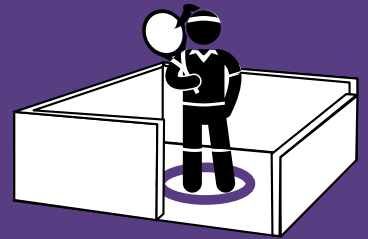

## ANTI-FATIGUE RUNNERS

There are various styles available, but conventional blown PVC sponge has the same open-cell structure throughout. While sponge products offer the lowest purchase price, they have the least amount of wear protection and tear strength. For improved wear, choose sponges with added compounds.

These products are a safe call if:

- The area is dry with light to heavy foot traffic
- You need an easily customizable solution to heel strike
- Work flow requires long lengths of continuous anti-fatigue surface

# 502/503


# Rejuvenator® Runner



Rejuvenator® Runners give you the option to create 2' (61cm)- and 3' (91cm) -wide runs of ergonomic matting. With a female end and a male end, all that's left is to connect as many centers as you need for your space. The molded-in ramps reduce installation time and costs.



SIZE	THICKNESS	COLOR	ITEM NUMBER
<b>502 Rejuvenator® Squared</b>			
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EMBK
<b>503 Rejuvenator® Domed</b>			
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EMBK

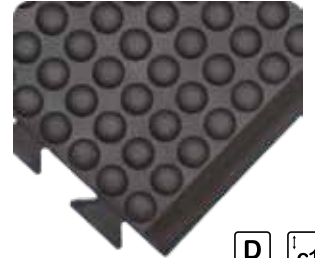

C: Center  
EF: End, Female  
EM: End, Male




### SPECIFICATIONS

 Compound: Polyurethane  
Edges: Molded-in Safety Bevel  
Warranty: Lifetime

## Need a longer runner?

Simply add more center mats for unlimited length!



*"Wearwell was able to make a huge mat in a very unusual configuration for our parts assembly department. We didn't even know that could be done. Because our employees had to move around a lot, they were always tripping over the small mats we used to have. When we mentioned that to Wearwell, they immediately offered us a custom solution. We're so glad we went with Wearwell."*

— A fulfillment facility that brings to mind a rain-forest

# 414/415

# Diamond-Plate SpongeCote®



The Original Diamond-Plate is available in extraordinarily long lengths and delivers performance that outlasts all others. See page 26 or visit our website for more information on our full line of Diamond-Plate products.



414 Nitricell® Diamond-Plate SpongeCote® UltraSoft 15/16" (24mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	BK, BYL, CHV, GY	414.1516x2x75
3' x 10' (91cm x 3m)	BK, BYL, CHV, GY	414.1516x3x10
3' x 20' (91cm x 6.1m)	BK, BYL, CHV, GY	414.1516x3x20
3 x 75' (91cm x 23m)	BK, BYL, CHV, GY	414.1516x3x75
4' x 75' (122cm x 23m)	BK, BYL, CHV, GY	414.1516x4x75
5' x 75' (152cm x 23m)	BK, BYL	414.1516x5x75
6' x 75' (1.8m x 23m)	BK, BYL	414.1516x6x75

415 Nitricell® Diamond-Plate SpongeCote® 9/16" (14mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	BK, BYL, CHV, GY	415.916x2x75
3' x 10' (91cm x 3m)	BK, BYL, CHV, GY	415.916x3x10
3' x 20' (91cm x 6.1m)	BK, BYL, CHV, GY	415.916x3x20
3' x 75' (91cm x 23m)	BK, BYL, CHV, GY	415.916x3x75
4' x 75' (122cm x 23m)	BK, BYL, CHV, GY	415.916x4x75
5' x 75' (152cm x 23m)	BK, BYL	415.916x5x75
6' x 75' (1.8m x 23m)	BK, BYL	415.916x6x75

# 440

## Ultra-Tred ArmorCote



Ultra-Tred ArmorCote has a durable urethane outer skin so that it can continue to work where other entry-level PVC blown-sponge mats fail. With a thickness of 3/8" (10mm), it is especially suited for applications where abrasion is a concern.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	3/8" (10mm)	BYL	440.38x2x3BYL
2' x 60' (61cm x 18m)	3/8" (10mm)	BYL	440.38x2x60BYL
3' x 5' (91cm x 152cm)	3/8" (10mm)	BYL	440.38x3x5BYL
3' x 12' (61cm x 3.7m)	3/8" (10mm)	BYL	440.38x3x12BYL
3' x 60' (91cm x 18m)	3/8" (10mm)	BYL	440.38x3x60BYL
4' x 60' (122cm x 18m)	3/8" (10mm)	BYL	440.38x4x60BYL

Available in cuts up to 60' (18m)



### SPECIFICATIONS

**Compound:** Blown PVC sponge w/urethane coating

**Edges:** Safety Rounded

**Warranty:** 1 Year



# 568

## ErgoDeck Smooth




**Looking for a better alternative for fulfillment areas?**

**See ErgoDeck® Smooth flooring on Page 17.**

Ideal for cart traffic and pivoting, plus has the anti-fatigue benefits your team needs!

# 451

## Tuf Sponge

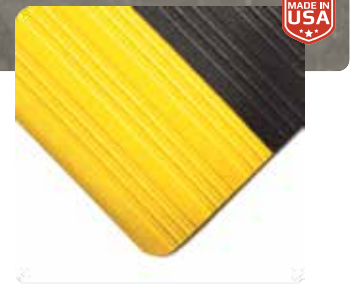

Tuf Sponge provides an economical PVC blown-sponge barrier for hard floors. With an attractive ribbed surface, this mat can be purchased in rolls and easily cut to length on site for quick replacement if damaged.

SIZE	THICKNESS	COLOR	ITEM NUMBER
27' x 36' (68cm x 91cm)	3/8" (10mm)	BK, BYL, GY	451.38x27x36
27' x 60" (68cm x 1.5m)	3/8" (10mm)	BK, BYL, GY	451.38x27x60
2' x 3' (61cm x 91cm)	3/8" (10mm)	BK, BYL, GY	451.38x2x3
2' x 60' (61cm x 18m)	3/8" (10mm)	BK, BYL, GY	451.38x2x60
3' x 5' (91cm x 1.5m)	3/8" (10mm)	BK, BYL, GY	451.38x3x5
3' x 12' (91cm x 3.7m)	3/8" (10mm)	BK, BYL, GY	451.38x3x12
3' x 60' (91cm X 18m)	3/8" (10mm)	BK, BYL, GY	451.38x3x60
4' x 60' (122cm X 18m)	3/8" (10mm)	BK, BYL, GY	451.38x4x60
6' x 60' (1.8m x 18m)	3/8" (10mm)	BK	451.38x6x60BK

Available in cuts up to 60' (18m)

### SPECIFICATIONS

Compound: Blown PVC Sponge

Edges: Safety Rounded

Warranty: 1 Year



# 442

## Deluxe Tuf Sponge



Deluxe Tuf Sponge comes with all the standard benefits of Tuf Sponge and is backed with 5/8"(16mm)-thick PVC sponge. It can also be purchased in rolls and easily cut to length on-site for quick replacement if damaged.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK, BYL, GY	442.58x2x3
2' x 60' (61cm x 18m)	5/8" (16mm)	BK, BYL, GY	442.58x2x60
3' x 5' (91cm x 1.5m)	5/8" (16mm)	BK, BYL, GY	442.58x3x5
3' x 60' (91cm x 18m)	5/8" (16mm)	BK, BYL, GY	442.58x3x60
4' x 60' (122cm x 18m)	5/8" (16mm)	BK, BYL, GY	442.58x4x60

Available in cuts up to 60' (18m)

### SPECIFICATIONS

Compound: Blown PVC Sponge

Edges: Safety Rounded

Warranty: 1 Year



# 452

## Diamond Tuf Sponge



Like the other Tuf Sponge models, Diamond Tuf Sponge provides an economical PVC blown sponge barrier for hard floors. With a popular Diamond-Plate surface pattern, Diamond Tuf Sponge also provides additional abrasion and chemical resistance.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	BK, BYL	452.12x2x3
2' x 60' (61cm x 18m)	1/2" (13mm)	BK, BYL	452.12x2x60
3' x 5' (91cm x 152cm)	1/2" (13mm)	BK, BYL	452.12x3x5
3' x 60' (91cm x 18m)	1/2" (13mm)	BK, BYL	452.12x3x60
4' x 60' (122cm x 18m)	1/2" (13mm)	BK, BYL	452.12x4x60

Available in cuts up to 60' (18m)

### SPECIFICATIONS

Compound: Blown PVC Sponge

Edges: Safety Rounded

Warranty: 1 Year



# 459

## Endurable



With an overall thickness of 1/2" (13mm), Endurable outlasts other blown-sponge products thanks to its "dual layer" construction. The mat's dense PVC surface top layer withstands abrasion and foot traffic while the softer under-layer provides ergonomic relief.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	BK	459.12x2x3BK
2' x 60' (61cm x 18m)	1/2" (13mm)	BK	459.12x2x60BK
3' x 5' (91cm x 152cm)	1/2" (13mm)	BK	459.12x3x5BK
3' x 12' (91cm x 366)	1/2" (13mm)	BK	459.12x3x12BK
3' x 60' (91cm x 18m)	1/2" (13mm)	BK	459.12x3x60BK
4' x 60' (122cm x 18m)	1/2" (13mm)	BK	459.12x4x60BK

Available in cuts up to 60' (18m)

### SPECIFICATIONS

**Compound:** Blown PVC Sponge w/  
Vinyl Coating  
**Edges:** Stock Sizes: Safety Rounded;  
Cut Lengths: Beveled  
**Warranty:** 1 Year



# 427

## Soft Step



Soft Step is an economical PVC blown-sponge barrier for hard floors that reduces worker fatigue and the impact of heel strike. It can be purchased in rolls and easily cut to length on site for quick replacement when damaged.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	3/8" (10mm)	BK, BYL, GY	427.38x2x3
2' x 60' (61cm x 18m)	3/8" (10mm)	BK, BYL, GY	427.38x2x60
3' x 5' (91cm x 152cm)	3/8" (10mm)	BK, BYL, GY	427.38x3x5
3' x 12' (91cm x 3.7m)	3/8" (10mm)	BK, BYL, GY	427.38x3x12
3' x 60' (91cm x 18m)	3/8" (10mm)	BK, BYL, GY	427.38x3x60
4' x 60' (122cm x 18m)	3/8" (10mm)	BK, BYL, GY	427.38x4x60

Available in cuts up to 60' (18m)

### SPECIFICATIONS

**Compound:** Blown PVC Sponge  
**Edges:** Safety Rounded  
**Warranty:** 1 Year



# 444

## Deluxe Soft Step



Deluxe Soft Step is backed by 5/8" (16mm) of PVC blown sponge. Like Soft Step, it features an attractive pebbled surface and can be purchased in rolls and easily cut to length on site for quick replacement when damaged.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK, BYL, GY	444.58x2x3
2' x 60' (61cm x 18m)	5/8" (16mm)	BK, BYL, GY	444.58x2x60
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK, BYL, GY	444.58x3x5
3' x 60' (91cm x 18m)	5/8" (16mm)	BK, BYL, GY	444.58x3x60
4' x 60' (122cm x 18m)	5/8" (16mm)	BK, BYL, GY	444.58x4x60

Available in cuts up to 60' (18m)

### SPECIFICATIONS

**Compound:** Blown PVC Sponge  
**Edges:** Safety Rounded  
**Warranty:** 1 Year





## There's No Room For A Penalty


High Risk areas are prone to cause injuries, and in some cases fatalities. The costs are too high for sub-standard products.

**311 DEATHS**

**due to electrical current in just one year in the United States.\***

\* Source: National Safety Council Injury Facts 2014 Edition

# Switchboard

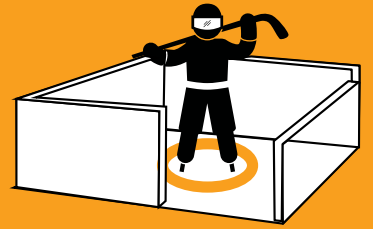

# SWITCHBOARD

Switchboard matting has a singular purpose: to protect personnel from life-threatening electrical shocks. Often referred to as "insulated" or "non-conductive" matting, these products insulate workers from high voltages up to 30,000 volts.

Recognize the need for non-conductive matting if:

- Team members are exposed to high-voltage electricity
- The work area has high-voltage signs that indicate electrical danger
- The goal, first and foremost, is to ensure the safety of personnel

# OUR SWITCHBOARD MATTING MEETS INDUSTRY STANDARDS

## Industry Standard: ANSI/ASTM D178-01

**Type I:** made using any properly vulcanized elastomer

**Type II:** made using any properly vulcanized elastomer AND has additional properties such as Ozone Resistance, Flame Resistance, and Oil Resistance

**Class 2 and 3** defines the dielectric strength: the higher the class, the greater the dielectric strength.

## Navy/Defense Dept.

**Standard: MIL. SPEC. 15562-G**


**Type I:** Sheet, smooth surface

**Type II:** Mat, runner type, smooth surface

**Type III:** Mat, runner type, raised diamond-pattern surface

## 701

### Diamond-Plate Switchboard Matting

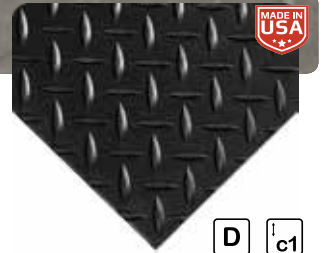

Featuring a tough but attractive diamond-plate surface design, Diamond-Plate Switchboard Matting is an essential safety product for mining, utility, and other heavy-industry facilities — any industrial space where potentially lethal shocks can be encountered, it has a recommended max voltage of 17,000 volts.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	1/4" (6mm)	BK	701.14x2x75
3' x 75' (91cm x 23m)	1/4" (6mm)	BK, BYL	701.14x3x75
4' x 75' (122cm x 23m)	1/4" (6mm)	BK	701.14x4x75

Available in cuts up to 75' (23m)

#### SPECIFICATIONS


**Compound:** Non-Conductive Vinyl

**Edges:** Square

**Warranty:** 1 year

## 702

### Corrugated Switchboard Matting

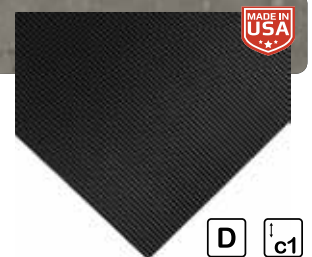

Corrugated Switchboard Matting is an essential safety product for a wide range of industries such as mining, utilities, and heavy industry — anywhere the danger of lethal shock is prevalent. Features a tough corrugated surface for extra traction. 1/4" (6mm) has a recommended max voltage of 17,000 volts and 3/8" (10mm) up to 26,000 volts.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	1/4" (6mm)	BK	702.14x2x75
3' x 75' (91cm x 23m)	1/4" (6mm)	BK, BYL	702.14x3x75
4' x 75' (122cm x 23m)	1/4" (6mm)	BK	702.14x4x75
3' x 75' (91cm x 23m)	3/8" (10mm)	BK	702.38x3x75*

\*Roll Only

Available in cuts up to 75' (23m)

#### SPECIFICATIONS

**Compound:** Non-Conductive Vinyl

**Edges:** Square

**Warranty:** 1 Year

## 720 Double Duty Switchboard Corrugated Mat



While insulating standing workers from high-voltage shock, Double Duty Switchboard also provides standing relief. The premium Nitricell® sponge base is ideal for workers who stand for extended periods of time — such as those who work in many military, mining and industrial facilities.



SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK, BYL	720.58x3x5
3' x 75' (91cm x 23m)	5/8" (16mm)	BK, BYL	720.58x3x75

Available in cuts up to 75' (23m)

#### SPECIFICATIONS

**Compound:** Non-Conductive Vinyl over Nitricell® Sponge

**Edges:** Lay-Flat Bevel

**Warranty:** 1 Year

Product Family	Conforming Standards
701	Conforms to ANSI/ASTM D178-01, , Type II, Class 2 standards
702 - 1/4" (6mm)	1/4" thickness conforms to ANSI/ASTM D178-01, Type II, Class 2
702 - 3/8" (10mm)	3/8" thickness conforms to ANSI/ASTM D178-01, Type II, Class 3
710	Conforms to Mil. Spec. 15562-G, Type I
711	Conforms to Mil. Spec. 15562-G Amend 3, Type II
712	Conforms to Mil. Spec. 15562-G Amend 3, Type III
720	Conforms to ANSI/ASTM D178-01, Type II, Class 2

## 710 Marbleized Military Switchboard Matting



Specially engineered for military applications, Marbleized Military Switchboard Matting meets Mil. Spec. 15562-G, Type I. Max.7,500 volts. Designed for permanent flooring installation, this non-conductive mat has Dielectric Strength up to 30,000 volts and can be secured in place by using any vinyl-mastic adhesive. For installations of multiple mats that require seaming, Wearwell offers compatible welding thread. When installing several widths of Marbleized Military Switchboard Matting side-by-side, it is important to seal the seams to ensure reliable and consistent insulation. For best results, professional floor installers are recommended.



ITEM	SIZE	THICKNESS	COLOR	ITEM NUMBER
Matting	3' x 75' (91cm x 23m)	1/8" (3mm)	BL, GN	710.18x3x75M
Thread	50' (15m)	1/8" (3mm)	BL, GN	710.18x50
Thread	150' (46m)	1/8" (3mm)	BL, GN	710.18x150
Thread	300' (91m)	1/8" (3mm)	BL, GN	710.THREADROLL

Available in cuts up to 75' (23m)



### SPECIFICATIONS

**Compound:** Non-Conductive Vinyl  
**Edges:** Square  
**Warranty:** 1 Year



Thread

## 711 Smooth Military Switchboard Matting




Designed to meet strict Mil. Spec 15562-F Amend. 3, Type II military standards, Smooth Military Switchboard Matting has a dielectric strength of 30,000 volts and a recommended usage up to 3,000 volts. Also passes federal flammability standard 501.



SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 75' (91cm x 23m)	1/8" (3mm)	BK	711.18x3x75BK

Available in cuts up to 75' (23m)

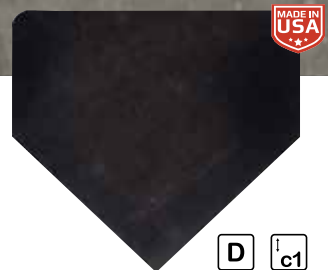

### SPECIFICATIONS

**Compound:** Non-Conductive PVC  
**Edges:** Square  
**Warranty:** 1 Year

## 712 Diamond-Plate Military Switchboard




Diamond-Plate Military Switchboard meets Mil. Spec 15562-F Amend. 3, Type III military standards. It has dielectric strength of up to 30,000 volts, and is perfect for use around high-voltage apparatuses and in heavily trafficked areas, the Diamond-Plate pattern offers additional traction and abrasion resistance.




SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 75' (91cm x 23m)	3/16" (5mm)	GY	712.316x3x75GY

Available in cuts up to 75' (23m)

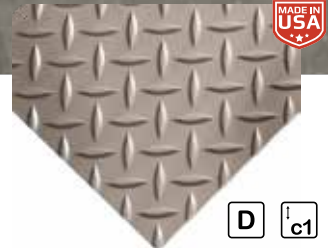

### SPECIFICATIONS

**Compound:** Non-Conductive PVC  
**Edges:** Square  
**Warranty:** 1 Year

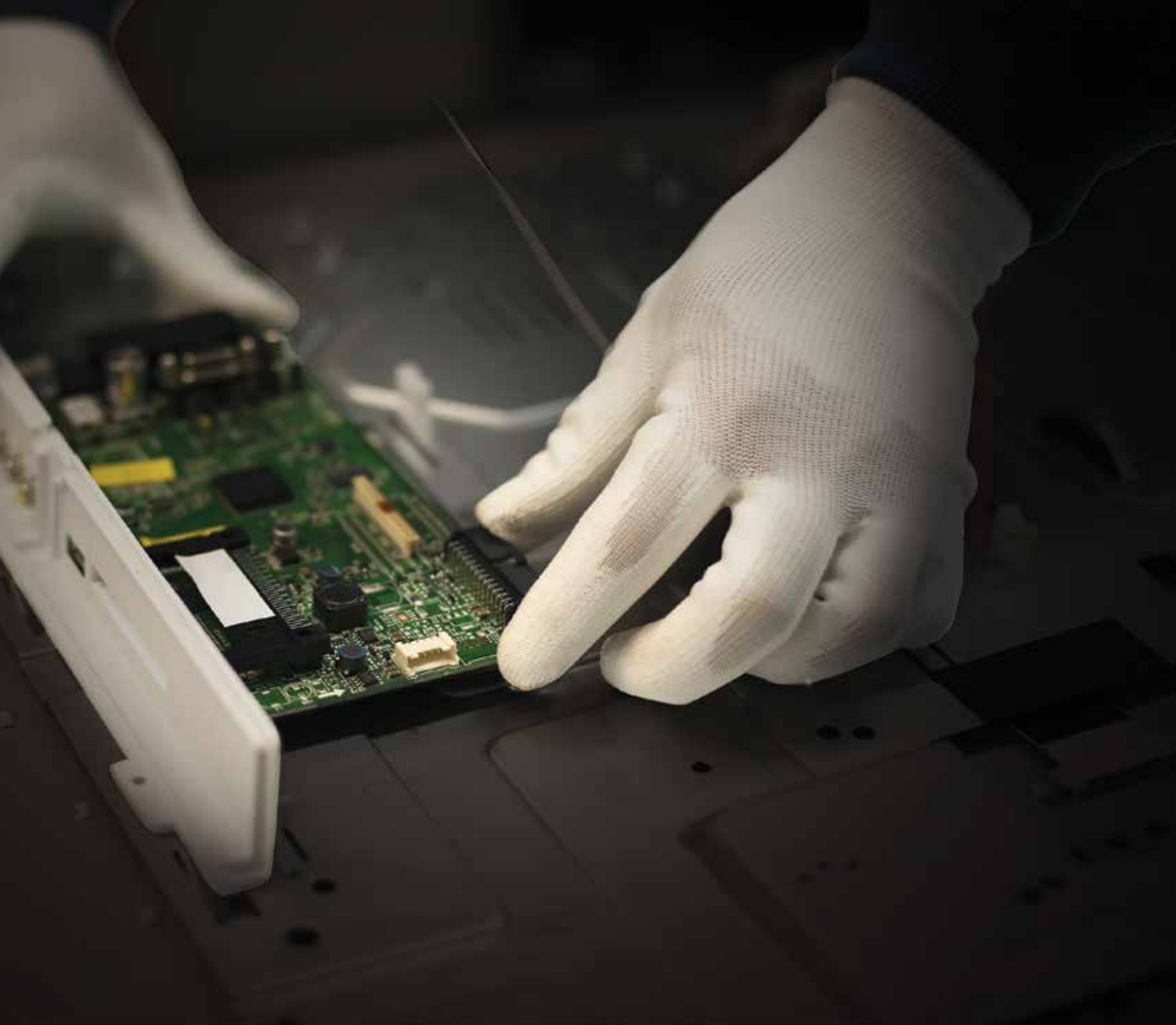


## **Chain Reaction**

The costs are too high for sub-standard products. Once the cue ball is released there's no stopping the end result.

# **ELECTRONIC FAILURE**

**Computer parts, boards, relays are used in just about everything. Don't risk the entire product with damaged parts.**

ESD

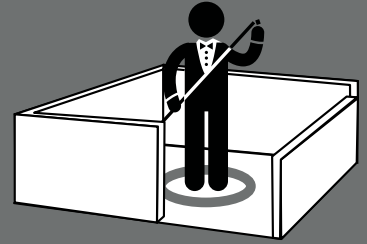

ESD

Wearwell offers both conductive and static dissipative mats designed to eliminate static shock. These products promote improved team performance and assure product quality.

Your field needs ESD defense if:


- Products being handled or produced are sensitive to static shock
- The air in the workspace has high levels of combustible fumes or particulates
- Your team is annoyed at the frequency of static shock

# Electrical Static Dissipative (ESD) 101:


Electro static dissipation (ESD) can destroy sensitive electronic components, erase or alter magnetic media, and even set off fires or explosions. Conductive, anti-static and static dissipative mats and accessories are used to minimize this risk.

Electrical resistance is measured in ohms; the smaller the rating, the more conductive the material.

Think of static resistance as water running through a pipe. With nothing blocking the pipe, the water is free to flow very quickly. If the pipe is blocked by debris, the water can't flow as fast because it meets resistance.

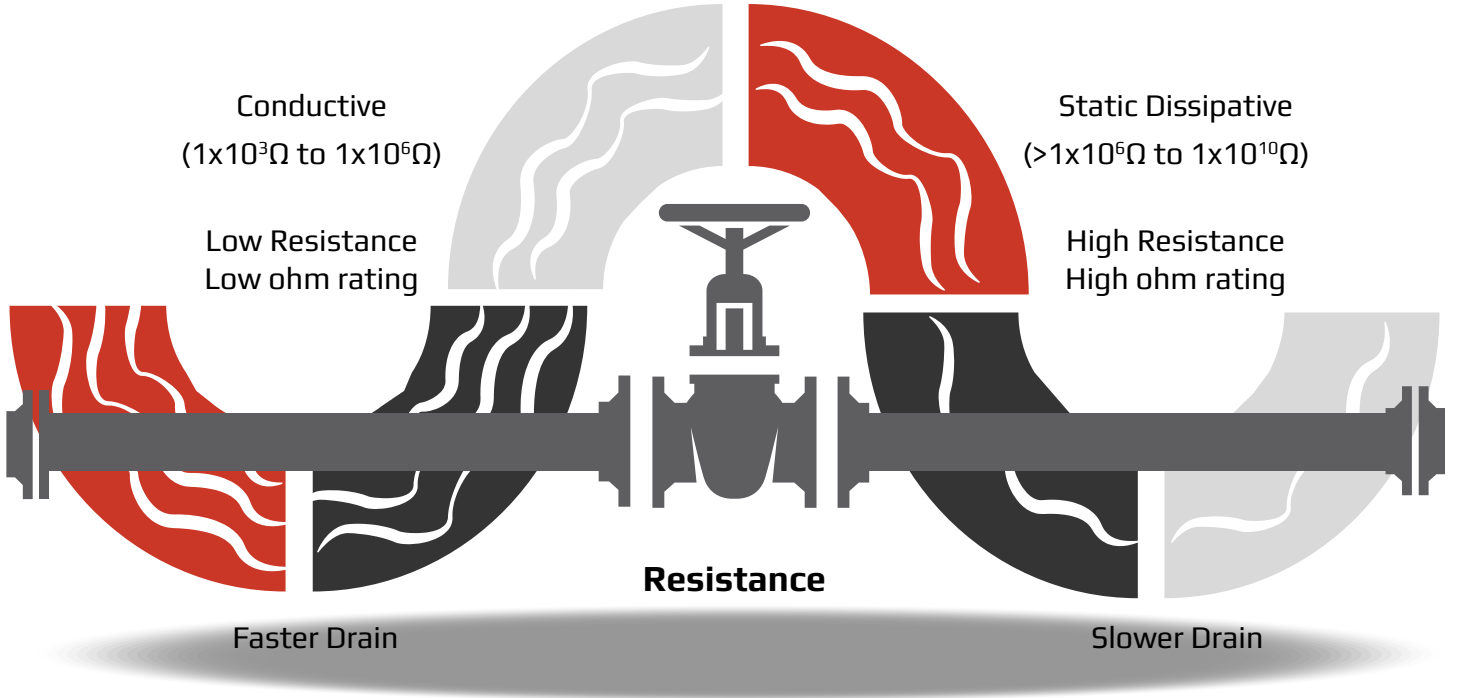

## Critical Accessories For ESD

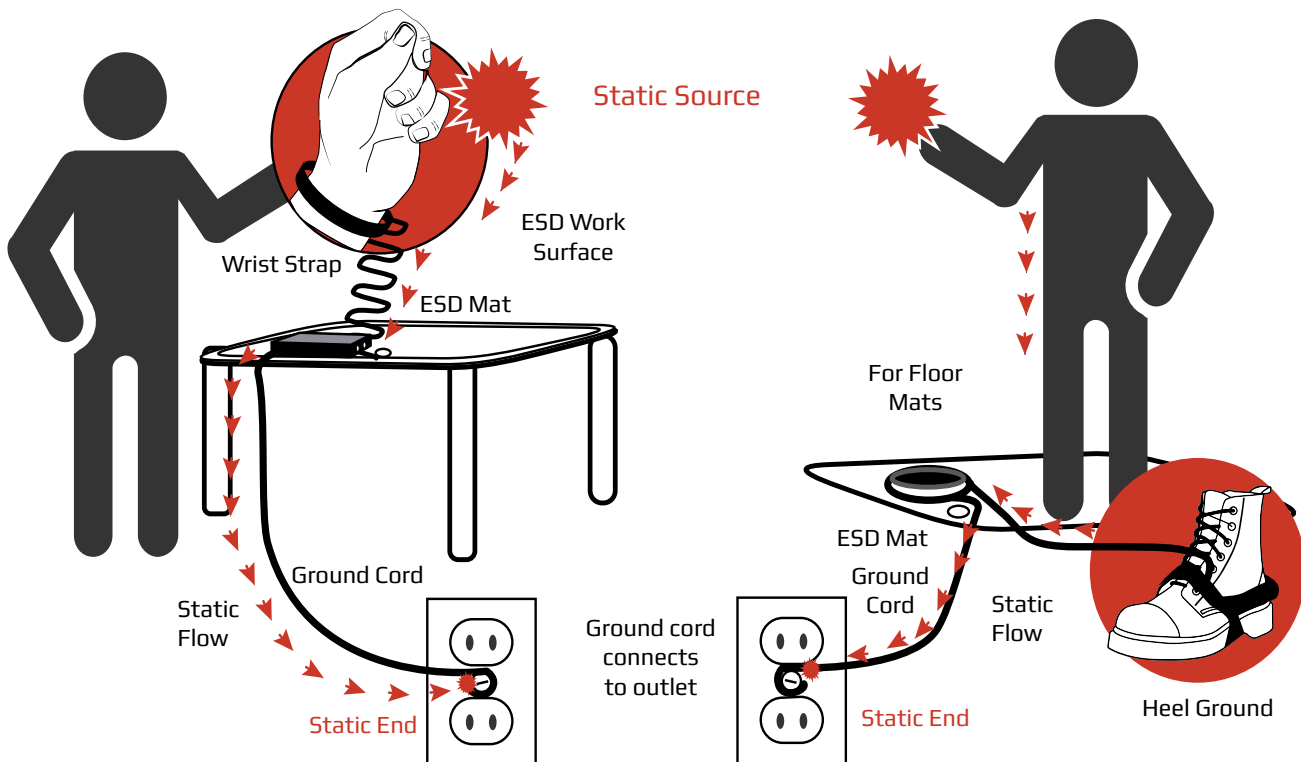

# 557

## ErgoDeck® ESD



When static electricity builds up, it seeks a path to ground — often through the human body or through sensitive, conductive equipment. The best way to eliminate these risks is to create a static-dissipative environment. ErgoDeck® ESD — a comprehensive flooring solution — offers the best defense. Used over conductive sub-flooring, ErgoDeck® ESD is your best defense against both worker fatigue and static shock that could compromise the quality of your products. Made of a proprietary TPO/carbon blend, ESD properties permeate the entire tile. No snaps or additional grounding is necessary when used over conductive flooring. Positive interlocks stay secure, ensuring areas of any size are protected. When installed wall-to-wall, ramps and corners aren't necessary. For transition areas, use ErgoDeck® standard universal ramps. PATENT US 8,006,443B2 US D5210,650S

SIZE	THICKNESS	COLOR	ITEM NUMBER
18" x 18" (46cm x 46cm)	7/8" (22mm)	BK	557.78x18x18BK-CS10

### SPECIFICATIONS

**Compound:** TPO  
**Edges:** Optional 6" (15cm) -Wide Safety Ramps




**Warranty:** Lifetime

EOS/ESD S7.1: 1x10^6 - 1x10^10

See page 21 for the universal ErgoDeck® ramps and corners.


# 785

## Electrically Conductive Runner

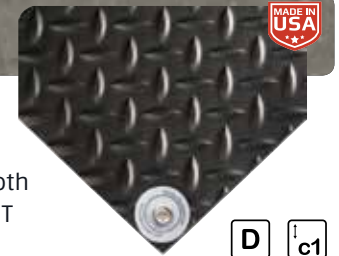

Use Electrically Conductive Runner to prevent static and protect sensitive electronic equipment. It can be rolled out for long aisles or cut to size for specific workstations. A grounding snap is included on each mat for optimum mat performance. Available in Smooth or Diamond-Plate surfaces. **MAT MUST BE GROUNDED WITH A GROUND CORD; WORKERS MUST WEAR HEEL GRINDER OR CONDUCTIVE SHOES.**

SIZE	THICKNESS	COLOR	SURFACE TEXTURE	ITEM NUMBER
3' x 75' (91cm x 23m)	5/32" (4mm)	BK	DP	785.532x3x75
3' x 75' (91cm x 23m)	3/32" (2mm)	BK	SM	785.332x3x75
4' x 75' (122cm x 23m)	5/32" (4mm)	BK	DP	785.532x4x75
4' x 75' (122cm x 23m)	5/32" (4mm)	BK	SM	785.532x4x75

 


### SPECIFICATIONS

**Compound:** PVC  
**Edges:** Square  
**Warranty:** 1 Year  
EOS/ESD S7.1: 1x10^3 - 1x10^6

Available in cuts up to 75' (23m)


# 786

## Electrically Conductive Anti-Fatigue

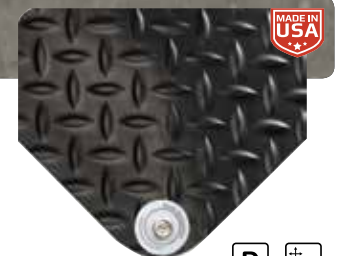

Electrically Conductive Anti-Fatigue protects sensitive electronic equipment while dramatically reducing workers' standing fatigue. Our No. 1 seller for static-control applications, it features our durable, top-of-the-line Nitricell® sponge, providing the best long-term value for ESD applications. Available in Smooth or Diamond-Plate surfaces. **MAT MUST BE GROUNDED WITH A GROUND CORD; WORKERS MUST WEAR HEEL GRINDER OR CONDUCTIVE SHOES.**

SIZE	THICKNESS	COLOR	SURFACE TEXTURE	ITEM NUMBER
2' x 3' (61cm x 91cm)	15/16" (24mm)	BK	SM, DP	786.1516x2x3
3' x 5' (91cm x 152cm)	15/16" (24mm)	BK	SM, DP	786.1516x3x5
3' x 75' (91cm x 23m)	15/16" (24mm)	BK	SM, DP	786.1516x3x75
4' x 75' (122cm x 23m)	15/16" (24mm)	BK	SM, DP	786.1516x4x75
2' x 3' (61cm x 91cm)	9/16" (14mm)	BK	SM, DP	786.916x2x3
3' x 5' (91cm x 152cm)	9/16" (14mm)	BK	SM, DP	786.916x3x5
3' x 75' (91cm x 23m)	9/16" (14mm)	BK	SM, DP	786.916x3x75
4' x 75' (122cm x 23m)	9/16" (14mm)	BK	SM, DP	786.916x4x75

 

### SPECIFICATIONS

**Compound:** PVC/Nitrile-Infused Sponge  
**Edges:** Lay-Flat Bevel  
**Warranty:** 1 Year  
EOS/ESD S7.1: 1x10^3 - 1x10^6

Please specify Smooth or Diamond-Plate when ordering.

# 788

## Modular Diamond-Plate ESD



Modular Diamond-Plate ESD mats have been designed for areas where static discharge is a major concern. These solid 3' x 3' (91cm x 91cm) mats can either be used individually or joined together — quickly and with no connectors — to cover larger work areas.



MAT MUST BE GROUNDED WITH A GROUND CORD; WORKERS MUST WEAR HEEL GRINDER OR CONDUCTIVE SHOES.



SIZE	THICKNESS	COLOR	COMPOUND	ITEM NUMBER
3' x 3' (91cm x 91cm)	1/2" (13mm)	BK	GR	788.12x3x3GRBK

### SPECIFICATIONS

Compound: GR: Natural Rubber

Edges: Safety Rounded


Warranty: 1 Year

EOS/ESD S7.1:1x10<sup>6</sup> to 1x10<sup>10</sup>



# 789

## Modular WorkSafe® Light ESD

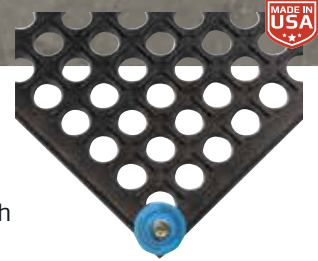

Modular WorkSafe® Light ESD is an ideal matting solution for areas where static discharge is a major concern and where light moisture might also come into play. Modular in nature, these open-design 3' x 3' (91cm x 91cm) mats with 7/8" (22mm) holes are versatile enough that they can either be used individually or interlocked to cover larger work areas.



MAT MUST BE GROUNDED WITH A GROUND CORD; WORKERS MUST WEAR HEEL GRINDER OR CONDUCTIVE SHOES.



SIZE	THICKNESS	COLOR	COMPOUND	ITEM NUMBER
3' x 3' (91cm x 91mm)	1/2" (13mm)	BK	GR	789.12x3x3GRBK

### SPECIFICATIONS

Compound: GR: Natural Rubber

Edges: Safety Rounded

Warranty: 1 Year

EOS/ESD S7.1:1x10<sup>6</sup> to 1x10<sup>10</sup>



Static produced from walking can range from

# 10,000–12,000

## VOLTS.

Static shock isn't felt until it's greater than

# 2,000

## VOLTS.

# DAMAGE

can be done without knowing an event has occurred.

# 791

## Static Dissipative Anti-Fatigue



Static Dissipative Anti-Fatigue is an ergonomic standing solution for manufacturing, pharmaceutical, and commercial areas where static electricity poses a problem.



**MAT MUST BE GROUNDED WITH A GROUND CORD; WORKERS MUST WEAR HEEL GRINDER OR CONDUCTIVE SHOES.**



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	GY	791.12x2x3GY
3' x 5' (91cm x 152cm)	1/2" (13mm)	GY	791.12x3x5GY
3' x 75' (91cm x 23m)	1/2" (13mm)	GY	791.12x3x75GY
4' x 75' (122cm x 23m)	1/2" (13mm)	GY	791.12x4x75GY

### SPECIFICATIONS

**Compound:** PVC/Nitrile-Infused Sponge

**Edges:** Lay-Flat Bevel

**Warranty:** 1 Year

**EOS/ESD S7.1:** 1x10<sup>6</sup> to 1x10<sup>10</sup>



# ESD-SNAP

## ESD Snap

Additional snaps available for longer length mats.



UOM	COLOR	ITEM NUMBER
25-pkg	Silver	ESD.SNAP.PKG

# 793

## Heel Grinder



ESD Heel Grinder allows static electricity to pass from workers who equip it to ESD matting or flooring underfoot. A required accessory for ESD matting, Heel Grinder is "one size fits all" with a Velcro loop for easy attachment.



**FOR USE WITH ESD AND CONDUCTIVE MATTING.**



SIZE	COLOR	ITEM NUMBER
One size fits all	BK	793.HG

### SPECIFICATIONS

One Size Fits All



# 793

## Ground Cord



The 15' (4.6m)-long ESD Ground Cord is used to connect ESD tabletop and floor mats to ground. The molded-in fastener has an integral one-mega-ohm resistor, conforms to 10mm snaps, and features a solderless terminal. Can be used with all conductive mats.



**FOR USE WITH ESD AND CONDUCTIVE MATTING.**



SIZE	COLOR	ITEM NUMBER
15' (4.6m)	BK	793.15Cord

### SPECIFICATIONS



# 793

## ESD Work Surface Material



ESD Work Surface Material is designed for work surfaces where static control is imperative. Featuring a flexible three-layer construction, it's ideal for use under computers, as a liner for conductive bins, or for tabletops where components are packaged. Mat must be grounded with a ground cord.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/8" (3mm)	SB	793.18x2x3SB
2' x 4' (61cm x 122cm)	1/8" (3mm)	SB	793.18x2x4SB

### SPECIFICATIONS

Compound: Vinyl

Edges: Square Cut

Warranty: 1 Year

EOS/ESD S7.1:1x10<sup>6</sup> to 1x10<sup>10</sup>



# 793

## Wrist Strap



ESD Wrist Strap is a six-foot comfort strap that loops around a worker's wrist and grounds them to their ESD tabletop mat, allowing static electricity to dissipate harmlessly. ESD Wrist Strap features a solderless terminal. Includes alligator clip for easy ground



SIZE	COLOR	ITEM NUMBER
6' (1.8m)	BK	793.6WSTRAP

### SPECIFICATIONS

Warranty: 1 Year



# 797

## ESD Common Point Ground Cord



ESD Common Point Ground Cord connects to and grounds two ESD Wrist Straps. ESD Common Point Ground Cord's molded-in male fastener connects to the snap on the tabletop mat while the terminal connects to a building ground.



SIZE	COLOR	ITEM NUMBER
15' (4.6m)	BK	797.CPCORD

### SPECIFICATIONS

Warranty: 1 Year



# WE INTERRUPT THIS CATALOG WITH SOME GREAT INSTALLATION PHOTOS



24/SEVEN® Mat - p38



Diamond-Plate - p26



Diamond-Plate - p26



F.I.T.® Open - p23



ErgoDeck® General Purpose - p18



ErgoDeck® Heavy Duty - p19



**Agility, Ingenuity And The Best Tools Are  
The Answer To Prevention**

**54% DAYS MISSED**

**Injuries resulting in days missed from  
work related to facility maintenance  
and upkeep\***

\* Source: US Bureau of Labor Statistics - BLS Reports, July 2015

# Facility Maintenance



## MAINTENANCE

These products provide needed field support if:

- Your team's workspace requires station-to-station standing, kneeling, or even laying down
- Cross-tracking makes carpets and floors difficult to keep clean
- Cross-tracking means cross-contamination

# 514/515

# ROVER™



The ROVER™ mat lets your industrial athletes excel at any position on the field. Whether they require an anti-fatigue surface for standing, a cushion with great rebound for kneeling, or a comfortable head support for when they're on the ground, ROVER™ mats have them covered.



ROVER™ features a unique 1" (25mm) nitrile-enhanced sponge that is non-conductive, petroleum resistant, and silicone free. If you spend time on your back, use the ROVER™ built-in interlock to combine a rolled ROVER™ mat with a horizontal one for both head and upper-back support.

With ROVER™ mats, your team can play at home or away and always be guaranteed a triple play. Take your game to a new level with the most versatile kneel mat on the market!

TRADITIONAL KNEEL MATS			
SIZE	THICKNESS	COLOR	ITEM NUMBER
12" x 22" (31cm x 56cm)	1" (25mm)	BK	514.1x12x22BK
12" x 22" (31cm x 56cm)	1" (25mm)	BK	514.1x12x22BK-CS5
14" x 21" (36cm x 53cm)	1" (25mm)	BK	514.1x14x21BK
14" x 21" (36cm x 53cm)	1" (25mm)	BK	514.1x12x21BK-CS5
8" x 16" (20cm x 41cm)	1" (25mm)	BK	514.1x8x16BK
8" x 16" (20cm x 41cm)	1" (25mm)	BK	514.1x8x16BK-CS5

3 IN 1- KNEEL MATS			
SIZE	THICKNESS	COLOR	ITEM NUMBER
14" x 21" (36cm x 53cm)	1" (25mm)	BK	515.1x14x21BK
14" x 21" (36cm x 53cm)	1" (25mm)	BK	515.1x14x21BK-CS5



### SPECIFICATIONS

Compound: Nitrile-Infused Sponge

Edges: Square

Warranty: 1 Year

Patent: US D673, 405S



Learn More  
About ROVER®  
Products - Watch  
The Video



# 518

# Comfort2Go™



For workers on the go, Comfort2Go™ mats are the go-to choice that lives up to its name. A portable mat with a built-in handle, it's easy on the knees when you kneel and bolstering underfoot when you need some standing support.



A dual-layer anti-fatigue mat that features a long-lasting PVC surface and a premium nitrile rubber composite sponge base, A Comfort2Go™ mat measures 17" x 30" (43cm x 76cm). Protect yourself on the move with the mat that's always there when you need it.



### SPECIFICATIONS

Compound: PVC/Nitrile-Infused Sponge

Warranty: 4 Years



SIZE	THICKNESS	COLOR	ITEM NUMBER
17" x 30" (43cm x 76cm)	7/8" (22mm)	BK	518.78x17x30BK



# 85,570

## Number of injuries in maintenance and repair occupation for 2014

\* Source: US Bureau of Labor Statistics - BLS Reports, July 2015

# 095

## Clean Room Mat



Hard work can be messy. The Clean Room Mat will keep that mess from being tracked into other areas. The tacky surface pulls and traps dirt and dust from shoe soles during demolition, standing, asbestos remediation, and day-to-day operations.



Simply pull off and discard individually numbered sheets as needed (available in 30 or 60 sheets). Use on low-pile carpet, tile, or concrete surfaces.

SIZE	SHEETS PER MAT	COLOR	ITEM NUMBER
18" x 36" (46cm x 91cm)	30, 60 (WH only)	BL, WH	095.18x36
18" x 45" (46cm x 114cm)	30, 60 (WH only)	BL, WH	095.18x45
24" x 45" (61cm x 114cm)	30, 60 (WH only)	BL, WH	095.24x45
2' x 3' (61cm x 91cm)	30	BL, WH	095.2x3
36" x 45" (91cm x 114cm)	30	BL, WH	095.36x45
3' x 5' (91cm x 152cm)	30	BL, WH	095.3x5



### SPECIFICATIONS

Compound: Polyethylene

Warranty: 1 Year



# 092

## PermaTack



PermaTack is designed for labs, clean rooms, and pharmacies that need serious long-term contamination control. The unique "tacky" surface removes up to 98% of contaminants from shoes. Just clean the surface and the mat's "tackiness" returns.



SIZE	THICKNESS	COLOR	ITEM NUMBER
27" x 48" (69cm x 122cm)	1/8" (3mm)	BL	092.18x27x48BL
36" x 54" (91cm x 137cm)	1/8" (3mm)	BL	092.18x36x54BL
27" x 72" (69cm x 1.9m)	1/8" (3mm)	BL	092.18x27x72BL
27" x 10' (69cm x 3m)	1/8" (3mm)	BL	092.18x27x10BL
27" x 20' (69cm x 6.1m)	1/8" (3mm)	BL	092.18x27x20BL
54" x 10' (137cm x 3m)	1/8" (3mm)	BL	092.18x54x10BL
54" x 20' (137cm x 6.1m)	1/8" (3mm)	BL	092.18x54x20BL



### SPECIFICATIONS

Compound: Vinyl Polymer

Edges: Square

Warranty: 2 Years



# 223

## Sole-Solution Foot Bath



**NEW**



The optimal solution for agriculture, food processing, and other facilities where contamination or grease build-up prevention is a necessity. With deep 2.5" (6cm) walls and 5-gallon (18.9 liter) capacity, the Sole-Solution foot bath is an affordable, effective solution that helps improve safety and fight cross-contamination.



SIZE	THICKNESS	COLOR	ITEM NUMBER
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	BK	223.2.5x31x38BK
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	BL	223.2.5x31x38BL
31" x 38" (79cm x 97cm)	2 1/2" (6cm)	YL	223.2.5x31x38YL

Please specify color

### SPECIFICATIONS

**Compound:** HDPE  
(High-density polyethylene)  
**Edges:** Molded Containment Walls  
**Warranty:** 1 Year



BK



BL



# 229

## Mud Chucker™



The name says it all: This rugged entrance solution was made to chuck mud. The recessed step-in area with rubber fingers on the sides and bottom remove mud, as well as dirt, grass, salt, and snow. The durable ridges and sidewalls work in all seasons, keeping the debris out of your building year-round.



Mud Chucker™ mats can be used as portable shoe scrapers for off-site jobs or traveling workers, or can be permanently installed at facility entryways.

### SPECIFICATIONS

**Compound:** Natural Rubber  
**Warranty:** 1 Year

SIZE	THICKNESS	COLOR	ITEM NUMBER
12" x 15 1/4" (30cm x 39cm)	2.2" (56mm)	BK	229.2.2x12.4x15.25



## SOLE-SOLUTION COMBO

For optimum effectiveness make it a combo and save!


### MUD CHUCKER®



Removes heavy debris from shoe sides & soles before entering



### SOLE-SOLUTION FOOT BATH

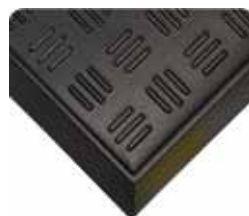

**TOGETHER IS BETTER**



PRODUCT	UOM	COLOR	ITEM NUMBER
Sole-Solution Combo	1 EA	BK, BL, YL	223.COMBO




## Concentration And Focus Is The Name Of The Game.

There is no room for fatigue, and no time to sit. Accuracy is a top priority.

**Add anti-microbial mats as part of  
your PPE requirement standards**

Lab

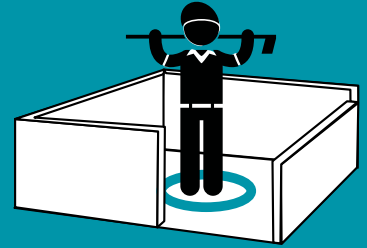

# HEALTH, LAB, PHARMACY

Wearwell has a variety of products that deliver optimum support and address contamination concerns such as particulation, out-gassing, and the spread of bacteria. Your facility shares the concerns of healthcare and lab environments if:

- Areas are typically sterile and have like aesthetics
- Transition areas are crucial points for contamination control
- Team members need standing relief for long or multiple shifts

**Anti-Microbial** — Does not contribute to or support the survival or growth of microorganisms when tested in accordance with ASTM G21-96 (2002).

# REJUVENATOR®

Rejuvenator® provides optimum performance in the field of labs and pharmacies. Not only does it have a clean consistent aesthetic, it also meets the USP 797 compliance standards for non-viable particulates.




Rejuvenator® flooring, runners, and workstation mats help your team stand stronger, longer. Whether you need to cover an entire lab, a multi-shift pharmacy, or just a single workstation, Rejuvenator® delivers the ultimate combination of durability, ergonomics, and awesome good looks! Manufactured entirely from Polyurethane, this perennial all-star features an unparalleled lifetime-warranty. Simply put, we've engineered Rejuvenator® to outlast and outperform any would-be rivals. Rejuvenator® has quickly become the ergonomic floor surface of choice for top-performing companies worldwide.

## 502/503 Flooring



Available in domed and squared designs, Rejuvenator® Flooring features large, 3' x 3' (91cm x 91cm) and 1' x 3' (30cm x 91cm) modules — that interlock on all four sides to customize on-site virtually any flooring configuration. The interlock is incredibly effective and also hidden so the ergonomic floor you've created is seamless and stable underfoot. Having the ability to customize in one-foot increments and finish off with beveled ramps (yellow or black) sets it apart from all other Polyurethane "wannabes."

502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
1' x 3' (30cm x 91cm)	5/8" (16mm)	BK	502.58x1x3BK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	502.58x3x3BK
503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
1' x 3' (30cm x 91cm)	5/8" (16mm)	BK	503.58x1x3BK
3' x 3' (91cm x 91cm)	5/8" (16mm)	BK	503.58x3x3BK

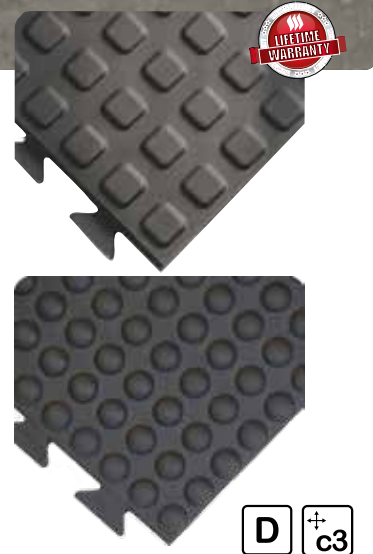


### SPECIFICATIONS

**Compound:** Polyurethane  
**Edges:** Optional 2" (5cm) - Wide Safety Edging  
**Warranty:** Lifetime

UNIVERSAL REJUVENATOR® RAMPS			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2" x 39" (5cm x 96cm)	5/8" (16mm)	BK, YL	502.58x2x39F
2" x 39" (5cm x 96cm)	5/8" (16mm)	BK, YL	502.58x2x39M

F: Female connector M: Male connector  
 Rejuvenator® edging is universal to all Rejuvenator® tiles

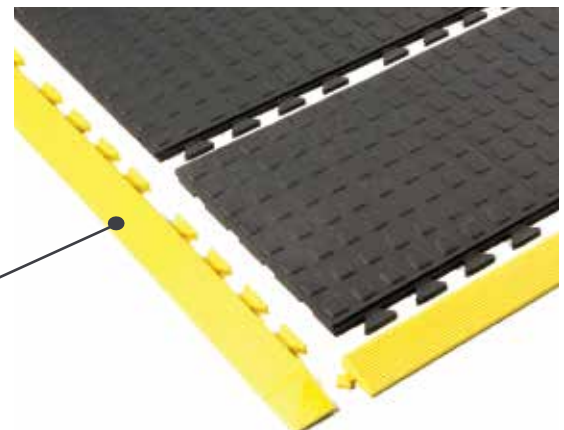

Rejuvenator flooring has 2" (5cm) wide ramps that provide a visual cue and transition for on-off access and are compatible with 502 and 503 flooring tiles.



# 502/503 Rejuvenator® Runner

Rejuvenator® Runners give you the option to create 2' (61cm) and 3' (91cm) wide runs of ergonomic matting. With a female end and a male end, all that's left is to connect as many centers as you need for your space. The molded-in ramps reduce installation time and costs.

- 
- 
- 

502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5EMBK

503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5CBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EFBK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5EMBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5CBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EFBK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5EMBK

C: Center  
 EF: End, Female  
 EM: End, Male



**SPECIFICATIONS**  
 Compound: Polyurethane  
 Edges: Molded-in Safety Bevel  
 Warranty: Lifetime

**Need a longer runner?**  
 Simply add more 5' center mats for unlimited length!



# 502/503 Rejuvenator® Workstation Mat

Rejuvenator® Workstation Mats provide an out-of-the-box anti-fatigue solution for workers who spend most of their shift standing at one station. Rejuvenator® Workstation Mats feature the same awesome aesthetics as the rest of the Rejuvenator® products, so your facility can look clean and consistent.

- 
- 
- 

502 Rejuvenator® Squared			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK	502.58x2x3BK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	502.58x2x5BK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	502.58x3x5BK

503 Rejuvenator® Domed			
SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	5/8" (16mm)	BK	503.58x2x3BK
2' x 5' (61cm x 152cm)	5/8" (16mm)	BK	503.58x2x5BK
3' x 5' (91cm x 152cm)	5/8" (16mm)	BK	503.58x3x5BK



**SPECIFICATIONS**  
 Compound: Polyurethane  
 Edges: Molded-in Safety Bevel  
 Warranty: Lifetime

# TILE-TOP SPONGECOTE™

Across laboratories, pharmacies, and medical environments, Tile-Top Spongecote™ AM ergonomic matting is an MVP. Its smooth surface cleans easily and bounce-back rebound technology provides long term standing relief. US REG. NO: 3,739,714



- Standing area extends to within 1.5" (4cm) - 3.5" (9cm) of surface edge
- Gravity or mechanical beveled for gradual transition to floor for optimum trip prevention

**GOOD**

**BETTER**

**BEST**

Compound	Urethane	PVC	Nitrile Rubber
Product Family	496	494	419, 420
Description	Made from 100% recycled urethane sponge, SMART® is a durable matting base that combines comfort, ecology, and economy. Best suited for dry areas, this green material is a Wearwell exclusive.	Flex-Link™ is a PVC sponge comparable to those used by our competitors, at a similar price point. The difference is our tapered Flex-Link™ base, which offers a larger usable ergonomic area, reduces "sponge dust" and keeps our mats from sliding.	Anti-microbial (AM) top to bottom. Nitricell®, the AM nitrile rubber composite sponge offers maximum comfort and resilience, while the AM surface delivers additional abrasion and chemical resistance.
Anti-Microbial	★ ★	★ ★	★ ★ ★
Standing Area	★	★ ★	★ ★ ★
Rebound	★ ★	★	★ ★ ★
Life Expectancy	★	★ ★	★ ★ ★
Bevel	★	★ ★	★ ★ ★
Green	★ ★ ★	★	★
Price Point	★ ★ ★	★ ★	★
Value	★	★ ★	★ ★ ★
Customization	★	★	★ ★ ★
Warranty	1 Year	3 Years	Lifetime
Application			
Industry			
Colors			



# 419/420

Nitricell®

419 Ultrasoft Tile-Top SpongeCote™ AM 7/8" (22mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BL, CH, GY	419.78x2x3AM
2' x 60' (61cm x 18m)	BK, BL, CH, GY	419.78x2x60AM
3' x 5' (91cm x 1.5m)	BK, BL, CH, GY	419.78x3x5AM
3' x 10' (91cm x 3m)	BK, BL, CH, GY	419.78x3x10AM
3' x 60' (91cm x 18m)	BK, BL, CH, GY	419.78x3x60AM
4' x 60' (122cm x 18m)	BK, BL, CH, GY	419.78x4x60AM

420 Tile-Top SpongeCote™ AM 1/2" (13mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BL, CH, GY	420.12x2x3AM
2' x 60' (61cm x 18m)	BK, BL, CH, GY	420.12x2x60AM
3' x 5' (91cm x 1.5m)	BK, BL, CH, GY	420.12x3x5AM
3' x 10' (91cm x 3m)	BK, BL, CH, GY	420.12x3x10AM
3' x 60' (91cm x 18m)	BK, BL, CH, GY	420.12x3x60AM
4' x 60' (122cm x 18m)	BK, BL, CH, GY	420.12x4x60AM

# 494

Flex-Link™

7/8" (22mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BL, BWH, CH, GY	494.78x2x3
2' x 60' (61cm x 18m)	BL, BWH, CH, GY	494.78x2x60
3' x 5' (91cm x 1.5m)	BL, BWH, CH, GY	494.78x3x5
3' x 60' (91cm x 18m)	BL, BWH, CH, GY	494.78x3x60
4' x 60' (122cm x 18m)	BL, BWH, CH, GY	494.78x4x60

1/2" (13mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BL, BWH, CH, GY	494.12x2x3
2' x 60' (61cm x 18m)	BL, BWH, CH, GY	494.12x2x60
3' x 5' (91cm x 1.5m)	BL, BWH, CH, GY	494.12x3x5
3' x 60' (91cm x 18m)	BL, BWH, CH, GY	494.12x3x60
4' x 60' (122cm x 18m)	BL, BWH, CH, GY	494.12x4x60

# 496

SMART®

7/8" (22mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BL, CH, GY	496.78x2x3
2' x 60' (61cm x 18m)	BK, BL, CH, GY	496.78x2x60
3' x 5' (91cm x 1.5m)	BK, BL, CH, GY	496.78x3x5
3' x 60' (91cm x 18m)	BK, BL, CH, GY	496.78x3x60
4' x 60' (122cm x 18m)	BK, BL, CH, GY	496.78x4x60

1/2" (13mm) Thickness		
SIZE	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	BK, BL, CH, GY	496.12x2x3
2' x 60' (61cm x 18m)	BK, BL, CH, GY	496.12x2x60
3' x 5' (91cm x 1.5m)	BK, BL, CH, GY	496.12x3x5
3' x 60' (91cm x 18m)	BK, BL, CH, GY	496.12x3x60
4' x 60' (122cm x 18m)	BK, BL, CH, GY	496.12x4x60

Available in cuts up to 60' (18m)

# 092

## PermaTack



PermaTack is designed for labs, clean rooms, and pharmacies that need serious long-term contamination control. The unique "tacky" surface removes up to 98% of contaminants from shoes. Just clean the surface and the mat's "tackiness" returns.



SIZE	THICKNESS	COLOR	ITEM NUMBER
27" x 48" (69cm x 122cm)	1/8" (3mm)	BL	092.18x27x48BL
36" x 54" (91cm x 137cm)	1/8" (3mm)	BL	092.18x36x54BL
27" x 72" (69cm x 1.8m)	1/8" (3mm)	BL	092.18x27x72BL
27" x 10' (69cm x 3m)	1/8" (3mm)	BL	092.18x27x10BL
27" x 20' (69cm x 6.1m)	1/8" (3mm)	BL	092.18x27x20BL
54" x 10' (1.4m x 3m)	1/8" (3mm)	BL	092.18x54x10BL
54" x 20' (1.4m x 6.1m)	1/8" (3mm)	BL	092.18x54x20BL

### SPECIFICATIONS

**Compound:** Vinyl Polymer  
**Edges:** Square  
**Warranty:** 2 Years



# 095

## Clean Room Mat



Clean Room Mats are the easy solution for common contamination-control issues. They are comprised of stacks of "tacky" film sheets that collect dirt and debris from shoes. Just peel away a full sheet to expose a new one.



SIZE	SHEETS PER MAT	COLOR	ITEM NUMBER
18" x 36" (46cm x 91cm)	30, 60 (WH only)	BL, WH	095.18x36
18" x 45" (46cm x 114cm)	30, 60 (WH only)	BL, WH	095.18x45
24" x 45" (61cm x 114cm)	30, 60 (WH only)	BL, WH	095.24x45
2' x 3' (61cm x 91cm)	30	BL, WH	095.2x3
36" x 45" (91cm x 114cm)	30	BL, WH	095.36x45
3' x 5' (91cm x 152cm)	30	BL, WH	095.3x5



### SPECIFICATIONS

**Compound:** Polyethylene  
**Edges:** Square



# 580

## Autoclavable Mat



Autoclavable Mat is the standing product of choice for sterile environments such as hospital ORs, surgery centers, and laboratories. The flexible and resilient latex-free non-porous rubber surface is 100% anti-microbial and provides workers with relief during long shifts and periods of extended standing.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	GY	580.12x2x3GY



### SPECIFICATIONS


**Compound:** NBR: Nitrile Rubber  
**Edges:** Beveled  
**Warranty:** 1 Year



# 423

## Soft Rock



 The modern and adaptable matting solution for labs, hotels, retail outlets and other facilities where workers stand on hard tiles and concrete. Easy to clean, Soft Rock is an affordable, anti-microbial solution that helps keep the workplace germ-free, meets ASTM G21-13 standards and is available in a wide array of colors.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 3' (61cm x 91cm)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x2x3
3' x 5' (91cm x 152cm)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x3x5
3' x 75' (91cm x 23m)	1/2" (13mm)	BL, CL, GT, SA, SL, TR	423.12x3x75

Available in cuts up to 75'



### SPECIFICATIONS

**Compound:** PVC over Nitricell® Sponge


**Edges:** Machine Beveled

**Warranty:** 4 Years



Check out the ease of cleaning Soft Rock



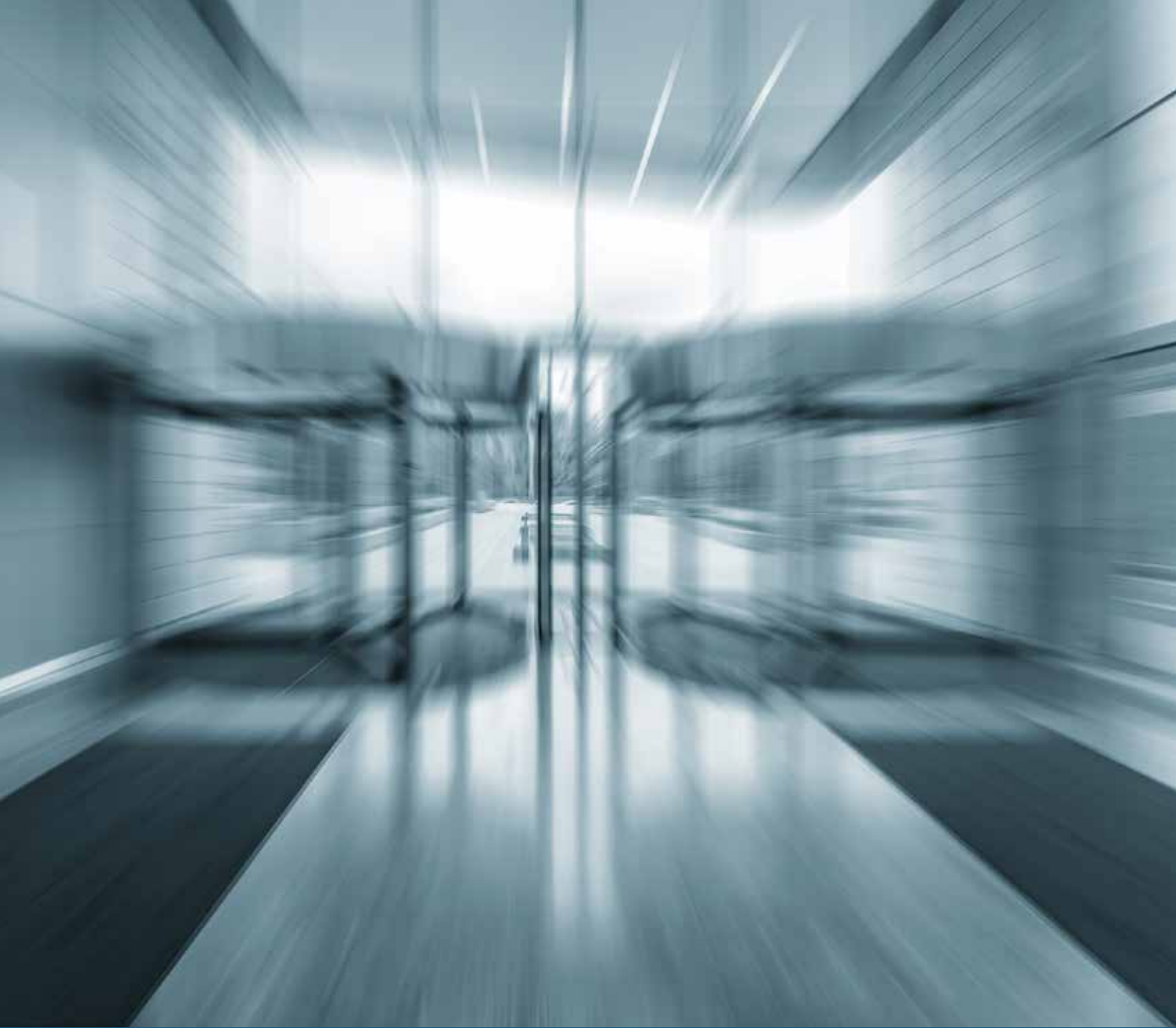

**Safety in many areas.**

Protect your fans as well as your athletes with the best field of play

# COMMERCIAL BUILDINGS



## Entrance/Office/Retail

Choose from a variety of surface patterns and thicknesses to suit your needs.

These products protect your fans, team and your facility, whether in the front office of a plant, educational facility or strip mall, There's room for a runner on your team.

- Work areas are slick, have high traffic, or need protection from wear and debris
- You require a low-profile solution with good abrasion resistance
- Your goals include eliminating slips and improving facility maintenance

# RUNNERS

Increase safety in longer strides, for walkways and entrances.

## 475

### Kushion Walk



At 3/8" (10mm) thick with a super-cut-resistant formulation, Kushion Walk has the enduring and fatigue-fighting characteristics that tough workplaces demand. Use it to cover grated walkways and mezzanines, under heavy equipment, and to guard against slips and falls.



SIZE	THICKNESS	COLOR	SURFACE TEXTURE	ITEM NUMBER
2' x 60' (61cm x 18m)	3/8" (10mm)	BK, BYL	SLT	475.38x2x60SLT
2' x 60' (61cm x 18m)	3/8" (10mm)	BK, BYL	UNS	475.38x2x60UNS
3' x 5' (91cm x 1.5m)	3/8" (10mm)	BK, BYL	SLT	475.38x3x5SLT
3' x 5' (91cm x 1.5m)	3/8" (10mm)	BK, BYL	UNS	475.38x3x5UNS
3' x 60' (91cm x 18m)	3/8" (10mm)	BK, BYL	SLT	475.38x3x60SLT
3' x 60' (91cm x 18m)	3/8" (10mm)	BK, BYL	UNS	475.38x3x60UNS

Please specify Slotted or Unslotted when ordering.

Available in cuts up to 60' (18m)



#### SPECIFICATIONS

Compound: PVC  
Edges: Square  
Warranty: 1 Year

## 480

### Abrasive Coated Kushion Walk



Abrasive Coated Kushion Walk features our unique GRITSHIELD™ surface, specifically designed for the slickest locations. With slips and falls being such dangers in today's workplaces, Abrasive Coated Kushion Walk offers a sure-footed solution for areas requiring high traction.



SIZE	THICKNESS	COLOR	SURFACE TEXTURE	ITEM NUMBER
2' x 60' (61cm x 18m)	3/8" (10mm)	BK	SLT	480.38x2x60SLTBK
2' x 60' (61cm x 18m)	3/8" (10mm)	BK	UNS	480.38x2x60UNSBK
3' x 60' (91cm x 18m)	3/8" (10mm)	BK	SLT	480.38x3x60SLTBK
3' x 60' (91cm x 18m)	3/8" (10mm)	BK	UNS	480.38x3x60UNSBK

Available in cuts up to 60' (18m)



#### SPECIFICATIONS

Compound: PVC  
Edges: Square  
Warranty: 1 Year

## 405

### Enviro Mat



Made of more than 80% post-consumer recycled material, Enviro Mat is one of the most environmentally friendly mats on the market. Designed for impact resistance, it is a great choice for work areas that involve heavy objects.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 105' (61cm x 32m)	3/8" (10mm)	BK	405.38x2x105BK
3' x 105' (91cm x 32m)	3/8" (10mm)	BK	405.38x3x105BK
4' x 105' (122cm x 32m)	3/8" (10mm)	BK	405.38x4x105BK

Available in cuts up to 105'



#### SPECIFICATIONS

Compound: Recycled Rubber  
Edges: Square  
Warranty: 1 Year



# 347


## H.T. Runner



The perfect solution for High Temperature and High Traffic areas where anti-fatigue isn't the primary objective. Textured rubber surface assures solid footing and can be used for semi-permanent installations with common mastics.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 75' (91cm x 23m)	5/64" (2mm)	BK	347.564x3x75BK
4' x 75' (122cm x 23m)	5/64" (2mm)	BK	347.564x4x75BK

Available in cuts up to 75' (23m)

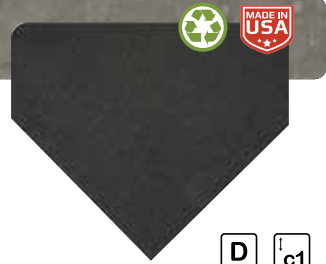

### SPECIFICATIONS

Compound: Rubber  
Edges: Square  
Warranty: 1 Year

# 385


## Diamond-Plate



Our industrial strength Diamond-Plate runner protects floors in busy work areas from heavy foot traffic and provides workers with increased traction. 100% vinyl, it can be custom sized up to 75' (23m) in length.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	3/16" (5mm)	BK, BYL, GY	385.316x2x75
3' x 75' (91cm x 23m)	3/16" (5mm)	BK, BYL, GY	385.316x3x75
4' x 75' (122cm x 23m)	3/16" (5mm)	BK, BYL, GY	385.316x4x75

Available in cuts up to 75' (23m)

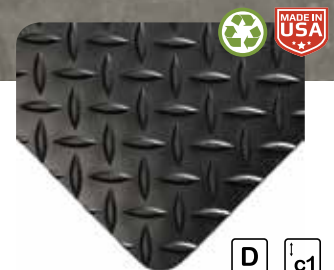

### SPECIFICATIONS

Compound: PVC  
Edges: Square  
Warranty: 1 Year

# 305


## Heavy Duty Corrugated



Our thickest and toughest runner, Heavy Duty Corrugated protects floors in heavily trafficked areas and provides long-lasting slip and chemical resistance in nearly all environments. 100% vinyl, it can be custom sized up to 75' (23m) in length.

SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	1/4" (6mm)	BK	305.14x2x75BK
3' x 75' (91cm x 23m)	1/4" (6mm)	BK	305.14x3x75BK
4' x 75' (122cm x 23m)	1/4" (6mm)	BK	305.14x4x75BK

Available in cuts up to 75' (23m)

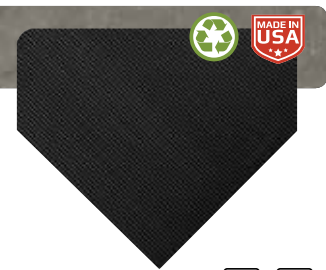

### SPECIFICATIONS

Compound: PVC  
Edges: Square  
Warranty: 1 Year

# 391

## KleenSweep

 


Designed for areas with moderate foot traffic, this round-ribbed vinyl runner is especially easy to clean. Made with post-consumer recycled material, KleenSweep runners are 1/8" (3mm) thick and can be custom sized up to 105' (32m) in length.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 105' (61cm x 32m)	1/8" (3mm)	BK	391.18x2x105BK
3' x 105' (91cm x 32m)	1/8" (3mm)	BK	391.18x3x105BK
4' x 105' (122cm x 32m)	1/8" (3mm)	BK	391.18x4x105BK

Available in cuts up to 105' (32m)



### SPECIFICATIONS

Compound: Vinyl  
Edges: Square  
Warranty: 1 Year

# 383

## Textured Kleen-Rite



This low-profile, versatile runner is made from textured thermoplastic rubber and has a tensile strength of 1,000 lbs (454kg). Designed to prevent slips on slick floors, it can also be sized for use as a shelf, drawer, or locker liner.



SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 75' (91cm x 23m)	3/32" (2mm)	BK	383.332x3x75BK
3' x 150' (91cm x 46m)	3/32" (2mm)	BK	383.332x3x150BK
4' x 75' (122cm x 23m)	3/32" (2mm)	BK	383.332x4x75BK
4' x 150' (122cm x 46m)	3/32" (2mm)	BK	383.332x4x150BK

Available in cuts up to 150' (46m)



### SPECIFICATIONS

Compound: TPE  
Edges: Square  
Warranty: 1 Year

# 381

## Standard Corrugated Vinyl




Standard Corrugated Vinyl adds traction where needed while protecting floors from wear and chemical damage. Our most popular runner, it is easy to clean, has a low maintenance cost, and helps reduce the frequency of comprehensive floor cleanings.



SIZE	THICKNESS	COLOR	ITEM NUMBER
2' x 75' (61cm x 23m)	1/8" (3mm)	BK	381.18x2x75BK
2' x 105' (61cm x 32m)	1/8" (3mm)	BK	381.18x2x105BK
2' x 150' (61cm x 46m)	1/8" (3mm)	BK	381.18x2x150BK
3' x 75' (91cm x 23m)	1/8" (3mm)	BK	381.18x3x75BK
3' x 105' (91cm x 32m)	1/8" (3mm)	BK	381.18x3x105BK
3' x 150' (91cm x 46m)	1/8" (3mm)	BK	381.18x3x150BK
4' x 75' (122cm x 23m)	1/8" (3mm)	BK	381.18x4x75BK
4' x 105' (122cm x 32m)	1/8" (3mm)	BK	381.18x4x105BK
4' x 150' (122cm x 46m)	1/8" (3mm)	BK	381.18x4x150BK

Available in cuts up to 150' (46m)

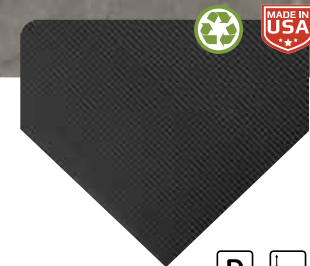

### SPECIFICATIONS

Compound: PVC  
Edges: Square  
Warranty: 1 Year

# 356

## Radial Runner



Designed for high-traffic interior walkways, Radial, with its signature circular pattern, complies with the National Fire Protection Association's (NFPA) flammability specifications for Type II construction, meaning that it is non-combustible and can be permanently installed.




SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 50' (91cm x 15m)	1/8" (3mm)	BK, GY	356.18x3x50
4' x 50' (122cm x 15m)	1/8" (3mm)	BK, GY	356.18x4x50

Available in cuts up to 50' (15m)






Grey

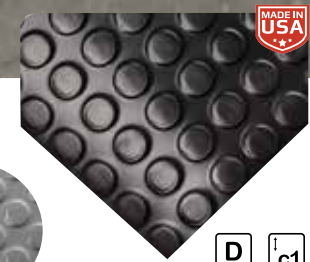

### SPECIFICATIONS

Compound: Vinyl  
Edges: Square  
Warranty: 1 Year

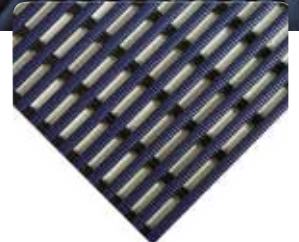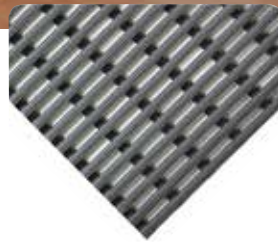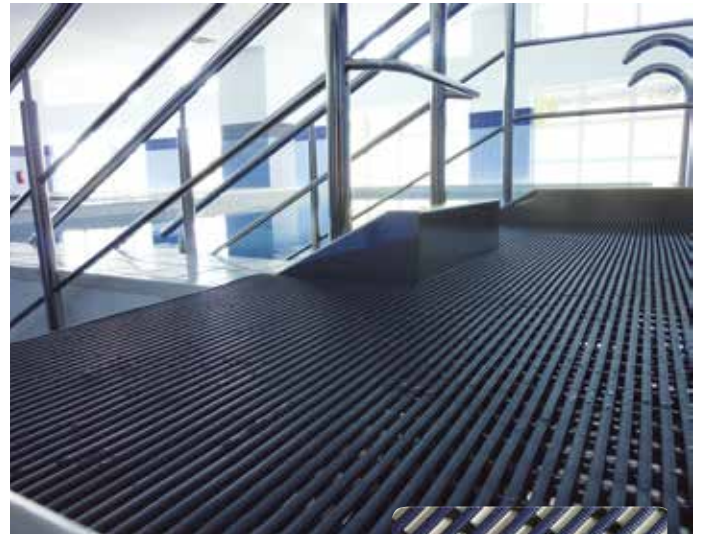


Elevate Sport is the ultimate sports and leisure matting for use in wet areas with barefoot traffic. Elevate Sport has a specially embossed slip resistant surface making it comfortable to stand and walk on with your bare feet. It is made from a strong, non-porous PVC and contains anti-fungal and anti-microbial additives to prevent fungal and microbial growth. The channeled underbars provide multi-directional drainage and will automatically self-drain large amounts of water. Elevate Sport is an effective barefoot wet area solution that is hygienic, UV resistant and easy to clean and maintain whether used indoors or outdoors.

**SUGGESTED APPLICATIONS**

- Shower Areas
- Locker Rooms
- Pools & Saunas
- Water Parks
- Recreational Facilities
- Marinas
- Boats
- Government Municipalities
- Yacht & Boat Manufacturers
- Outdoor Shower Areas



Channeled underbars to facilitate multi-directional drainage

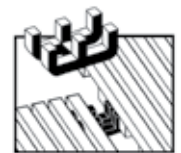

Easy snap connectors



**SPECIFICATIONS**

Compound: PVC  
Edges: Square  
Warranty: 1 Year



SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 33' (91cm x 10m)	3/8" (10mm)	CH	372.38x3x33CH
3' x 33' (91cm x 10m)	3/8" (10mm)	BL	372.38x3x33BL
3' x Cut (91cm x Cut)	3/8" (10mm)	CH	372.38x3CUTCH*
3' x Cut (91cm x Cut)	3/8" (10mm)	BL	372.38x3CUTBL*
Connectors		BK	370.Connector-PK10
Floor Hook		BK	370.FloorHook-PK10

\*Available in cuts 10' (3m) up to 33' (10 m)

# ENTRANCE

Check debris at the door. Use entrance mats to keep dirt outside and your facility in top condition.

## 220

### Multi-Guard Heavy Duty

Multi-Guard Heavy Duty entrance mats use thousands of rubber scrapers to remove dirt, mud, and other debris from shoes. Capable of capturing pounds of dirt between cleanings, Multi-Guard Heavy Duty defends your entryways from crud — period.

SIZE	THICKNESS	COLOR	ITEM NUMBER
24" x 32" (61cm x 81cm)	1/2" (13mm)	BK	220.12x24x32BK
28" x 46" (71cm x 117cm)	1/2" (13mm)	BK	220.12x28x46BK
32" x 39" (81cm x 99cm)	1/2" (13mm)	BK	220.12x32x39BK
3' x 5' (91cm x 152cm)	1/2" (13mm)	BK	220.12x3x5BK
3' x 6' (91cm x 1.8m)	1/2" (13mm)	BK	220.12x3x6BK



#### SPECIFICATIONS

**Compound:** GR: Natural Rubber  
**Edges:** 1" (2.5cm) Molded and Beveled  
**Warranty:** 1 Year



## 224

### UpFront Scraper

UpFront Scraper mats are the industry standard for economical entrance mats. Both the solid and drainage versions do a great job preventing dirt and moisture from entering buildings. UpFront Scraper gets the dirty work done.

SIZE	THICKNESS	COLOR	SURFACE TEXTURE	ITEM NUMBER
3' x 5' (91cm x 152cm)	5/16" (8mm)	BK	UNS	224.516x3x5GRBK
3' x 5' (91cm x 152cm)	5/16" (8mm)	BK	SLT	224.516x3x5GRSLTBK

Please specify Slotted or Unslotted when ordering.



#### SPECIFICATIONS

**Compound:** SBR: Natural Rubber  
**Edges:** Tapered  
**Warranty:** 1 Year



## 227

### OutFront Reversible

A versatile scraper mat, OutFront Reversible provides an all-season line of defense for entryways. One side is designed to remove heavy debris and snow; the other side dislodges the dirt and moisture that comes with more moderate weather.

SIZE	THICKNESS	COLOR	ITEM NUMBER
3' x 6' (91cm x 1.9m)	7/16" (11mm)	BK	227.716x3x6BK



#### SPECIFICATIONS

**Compound:** SBR: Natural Rubber  
**Edges:** Tapered  
**Warranty:** 1 Year





229

## Mud Chucker™



The name says it all: This rugged entrance solution was made to chuck mud. The recessed step-in area with rubber fingers on the sides and bottom remove mud, as well as dirt, grass, salt, and snow. The durable ridges and sidewalls work in all seasons, keeping the debris out of your building year-round.

Mud Chucker™ mats can be used as portable shoe scrapers for off-site jobs or traveling workers, or can be permanently installed at facility entryways.

### SPECIFICATIONS

Compound: Natural Rubber

Warranty: 1 Year



SIZE	THICKNESS	COLOR	ITEM NUMBER
2 x 12 x 15 1/4" (5cm x 30cm x 39cm)	2.2" (56mm)	BK	229.2.2x12.4x15.25

095

## Clean Room Mat



Clean Room Mats are the easy solution for common contamination-control issues. They are comprised of stacks of "tacky" film sheets that collect dirt and debris from shoes. Just peel away a full sheet to expose a new one.

SIZE	SHEETS PER MAT	COLOR	ITEM NUMBER
18" x 36" (46cm x 91cm)	30, 60 (WH only)	BL, WH	095.18x36
18" x 45" (46cm x 114cm)	30, 60 (WH only)	BL, WH	095.18x45
24" x 45" (61cm x 114cm)	30, 60 (WH only)	BL, WH	095.24x45
2' x 3' (61cm x 91cm)	30	BL, WH	095.2x3
36" x 45" (91cm x 114cm)	30	BL, WH	095.36x45
3' x 5' (91cm x 152cm)	30	BL, WH	095.3x5

### SPECIFICATIONS

Compound: Polyethylene

Edges: Square



# Slips, Trips & Falls

# The first step in prevention is evaluating how safe your floors are

# Accessories



Mats aren't supposed to walk, people are, but sometimes on highly polished surfaces everything can be slick. All the more important to have a mat in that location. Use adhesive accessories to secure the mat to where it is supposed to be for sure footed traction.



## GripSafe Reflective Tape 050

This heavy-duty reflective tape prevents mats from sliding on almost any surface. Use it also to eliminate trip hazards and define borders in high-traffic areas.

SIZE	ITEM NUMBER
4" x 45' (10cm x 13.8m)	050.4x45YL



## GripStrips 051

These two-sided tacky strips are designed to keep mats in place on highly polished surfaces. The strips remain sticky after cleaning so they can be reused.

SIZE	ITEM NUMBER
6" x 6" (15cm x 15cm)	051.6x6BL



## LockFast 053

Tiny grippers on this tape anchor both carpet- and sponge-backed mats on carpeted surfaces. No additional adhesives are required — just peel, cut, stick and press.

SIZE	ITEM NUMBER
1" x 75' (3cm x 23m)	053.1x75BK



## Safety Track 698

This adhesive strip is a convenient way to add traction to existing interior ramps, ladders and walkways. It readily adheres to concrete, metal and wood.

SIZE	COLOR	ITEM NUMBER
12" x 60' (30cm x 18m)	BK	698.12x60BK
18" x 60' (46cm x 18m)	BK	698.18x60BK
1" x 60' (3cm x 18m)	BK	698.1x60BK
2" x 60' (5cm x 18m)	BK	698.2x60BK
4" x 60' (10cm x 18m)	BK	698.4x60BK
6" x 60' (15cm x 18m)	BK	698.6x60BK
6" x 24" (15cm x 61cm)	BK	698.6x24BK

# Product Specifications

Group Code	Product Name	Page	Recycled Content	Flammability
092	PermaTack	68, 76	<10%	
095	Clean Room Mat	68, 76, 85	<10%	
220	Heavy Duty Multi-Guard	84	>33%	DOC FF1-70 / Meets Standards
222-ST	Sanitizing Footbath Mat Standard	45	>33%	DOC FF1-70 / Meets Standards
222-TW	Sanitizing Footbath Mat Tall Wall	45	>33%	DOC FF1-70 / Meets Standards
223	Sole-Solution Foot Bath	45, 69	>50% (Black)	
224-SLT	Upfront Scraper Mat Slotted	84	>33%	MVSS 302 / "A" Rating
224-UNS	Upfront Scraper Mat Unslotted	84	>33%	MVSS 302 / "A" Rating
227	OutFront Reversible	84	>33%	MVSS 302 / "A" Rating
229	Mud Chucker™	69, 85	>50%	MVSS 302 / "A" Rating
305	Heavy Duty Corrugated	81	>50%	MVSS 302 / "A" Rating
347	H.T. Runner	81	>20%	MVSS 302 / "A"; Rating
356	Radial	82	<10%	MVSS 302 / "A" Rating
370	Elevate AFR	44	0%	Not Available
371	Elevate OR	36	0%	Not Available
372	Elevate Sport	83	0%	Not Available
373	Elevate Extreme	36	0%	
381	Standard Corrugated Vinyl	82	>50%	MVSS 302 / "A" Rating
383	Textured Kleen-Rite	82	>50%	MVSS 302 / "A" Rating
385	Diamond-Plate	81	>50%	MVSS 302 / "A" Rating
391	KleenSweep	82	>50%	MVSS 302 / "A" Rating
405	Enviro Mat	80	>95%	MVSS 302 / "A" Rating
414	UltraSoft Diamond-Plate	26-27, 48	>50%	MVSS 302 / "A" Rating
415	Diamond-Plate SpongeCote®	26-27, 48	>50%	MVSS 302 / "A" Rating
416	Diamond-Plate w/GRITSHIELD™ UltraSoft	26-27	>50%	MVSS 302 / "A" Rating
419	UltraSoft Tile-Top Spongecote™ AM	74-75	<10%	MVSS 302 / "A" Rating
420	Tile-Top Spongecote™ AM	74-75	<10%	MVSS 302 / "A" Rating
423	Soft Rock	28, 77	<10%	MVSS 302 / "A"; Rating
427	Soft Step	51	<10%	DOC FF1-70 / Flame Retardant Rating
431	Corrugated SpongeCote®	29	>50%	MVSS 302 / "A" Rating
433	ComfortPro™	29	>50%	DOC FF1-70 / Flame Retardant Rating
438	LightWorks Inspection Mat	28	<10%	MVSS 302 / "A" Rating
440	Ultra-Tred ArmorCote	49	<10%	DOC FF1-70 / Flame Retardant Rating
442	Deluxe Tuf Sponge	50	<10%	DOC FF1-70 / Flame Retardant Rating
444	Deluxe Soft Step	51	<10%	DOC FF1-70 / Flame Retardant Rating
447	WeldSafe® UltraSoft	28	>20%	MVSS 302 / "A" Rating
451	Tuf Sponge	50	<10%	DOC FF1-70 / Flame Retardant Rating
452	Diamond Tuf Sponge	50	<10%	DOC FF1-70 / Flame Retardant Rating
454	Ortho Stand™	37	>50%	MVSS 302 / "A" Rating
459	Endurable	51	<10%	MVSS 302 / "A" Rating
468	Workrite II	37	>33%	MVSS 302 / "A" Rating
470	Modular Diamond-Plate Grease Proof	37	>50%	MVSS 302 / "A" Rating
472-GR	Modular WorkSafe® Light Grease Resistant	41	>33%	MVSS 302 / "A" Rating
472-GP	Modular WorkSafe® Light Grease Proof	41	>33%	MVSS 302 / "A" Rating
474	WorkRite	45	>33%	MVSS 302 / "A" Rating
475-SLT	Kushion Walk Slotted	80	<10%	MVSS 302 / "A" Rating
475-UNS	Kushion Walk Unslotted	80	<10%	MVSS 302 / "A" Rating
476-GR	Industrial WorkSafe® GR	40	>33%	MVSS 302 / "A" Rating
476-NBR	Industrial WorkSafe® NBR	40	>15%	MVSS 302 / "A" Rating
477	WorkSafe® Grease Resistant	41	>33%	MVSS 302 / "A" Rating
478	WorkSafe® Light CFR	41	<10%	MVSS 302 / "A" Rating
480-SLT	Abrasive Coated Kushion Walk Slotted	80	<10%	MVSS 302 / "A" Rating
480-UNS	Abrasive Coated Kushion Walk Unslotted	80	<10%	MVSS 302 / "A" Rating
482	Grade "A"®	44	<10%	MVSS 302 / "A" Rating
494	Tile-Top Spongecote™ Select	74-75	<10%	MVSS 302 / "A" Rating
495	D-P Select UltraSoft	26-27	>50%	MVSS 302 / "A" Rating
496	SMART® Tile Top	74-75	>50%	MVSS 302 / "A" Rating
497	SMART® D-P UltraSoft	26-27	>80%	MVSS 302 / "A" Rating
502-F	Rejuvenator® Squared Interlocking Tile	12, 48, 72	0%	MVSS 302 / "A" Rating
502-M	Rejuvenator® Squared Workstation Mat	13, 73	0%	MVSS 302 / "A" Rating
502-R	Rejuvenator® Squared Modular Runner	13, 48, 73	0%	MVSS 302 / "A" Rating
503-F	Rejuvenator® Domed Interlocking Tile	12, 48, 72	0%	MVSS 302 / "A" Rating
503-M	Rejuvenator® Domed Workstation Mat	13, 73	0%	MVSS 302 / "A" Rating
503-R	Rejuvenator® Domed Modular Runner	13, 48, 73	0%	MVSS 302 / "A" Rating
513-DP/ 513-PB	SubStance w/D-P or Pebble Pattern (See Website)			
514	ROVER™	66	<10%	MVSS 302 / "A" Rating

	Tabor Abrasion	Temp Range (°F)	Coefficient of Friction	Compression Deflection
		32-123	2.02 per ASRM C1028, 4.05 Tortus	
		32-123	2.02 per ASRM C1028, 4.05 Tortus	
		10-120	ASTM F1677 / Dry: >1.0 / Wet: .98	
		10-120	ASTM F1677 / Dry: >1.0 / Wet: .98	
		10-120	ASTM F1677 / Dry: >1.0 / Wet: .98	
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: .91 / Wet: .65	
	Fed Std 191 / 1% lost @ 1,000 cycles	>500 mp*	ASTM F1677 / Dry: COF = 1.10 / Wet COF = .32	ASTM D575 / Deflection @ 35 psi, mm=7.85
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: 1.1 / Wet: .67	Not Available
	Not Available	-9 to 140	ASTM F1677 / Dry: COF= .82 / Wet: COF = .72	Not Available
	Not Available	-9 to 140	ASTM F1677 / Dry: .82 / Wet: .63	Not Available
	Not Available	-9 to 140	ASTM F1677 / Dry: COF= .82 / Wet: COF = .71	Not Available
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: .91 / Wet: .65	
	Fed Std 191 / 1% lost @ 1,000 cycles	0-600	ASTM F1677 / Dry: 1.1 / Wet: .67	
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: .68 / Wet: .17	
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: .84 / Wet: .77	
	Fed Std 193 / <5% lost @ 1,000 cycles			
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: .68 / Wet: .17	ASTM D575 / Deflection @ 35psi, mm = 13.20
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-120	ASTM F1677 / Dry: .68 / Wet: .17	ASTM D575 / Deflection @ 35psi, mm = 8.43
	Fed Std 191 / 1% lost @ 1,000 cycles	0-110	ASTM F1677 / Dry: 1.10 / Wet: 1.0	ASTM D575 / Deflection @ 35psi, mm = .50
	Fed Std 191 / 1,000g, CS-17 wheel	0-110	ASTM F1677 / Dry: .78	ASTM D575 / Deflection @ 35psi, mm = .472
	Fed Std 193 / <1% lost @ 1,000 cycles	0-110	ASTM F1677 / Dry: .78	ASTM D575 / Deflection @ 35psi, mm = .343
	Federal Standard 191 / 1000g, CS-17 wheel	0 to 110	ASTM F1677 / Dry: COF = .78	
	Fed Std 191 / 2% lost @ 1,000 cycles	20-110	ASTM F1677 / Dry: .60	
	Fed Std 193 / <1% lost @ 1,000 cycles	20-110	ASTM F1677 / Dry: .60	ASTM D575 / Deflection @ 35psi, mm = .337
	Fed Std 191 / 1% lost @ 1,000 cycles	20-110	ASTM F1677 / Dry: .60	ASTM D575 / Deflection @ 35psi, mm = .310
	Fed Std 191 / 1,000g, CS-17 wheel	-10-120	ASTM F1677 / Dry: .84 / Wet: .77	
	Fed Std. 193 / 13% lost @ 1,000 cycles	20-110	ASTM F1677 / Dry: .60	ASTM D575 / Deflection @ 35psi, mm = .178
	Fed Std 191 Modified / 2% lost @ 1,000 cycles	0-110	ASTM F1677 / Dry: .94 / Wet: .72	ASTM D575 / Deflection @ 35psi, mm = .276
	Fed Std 191 Modified / 2% lost @ 1,000 cycles	20-110	ASTM F1677 / Dry: .60	ASTM D395-98 / 20%
	Fed Std 191 / 1% lost @ 1,000 cycles	>500 mp*	ASTM F1677 / Dry: .90 / Wet: .36	ASTM D575 / Deflection @ 35 psi, mm = 7.85
	Fed Std 191 Modified / 2% lost @ 1,000 cycles	0-100	ASTM F1677 / Dry: .94 / Wet: .72	ASTM D575 / Deflection @ 35psi, mm = .205
	Fed Std 191 Modified / 2% lost @ 1,000 cycles	0-110	ASTM F1677 / Dry: .94 / Wet: .72	ASTM D575 / .205 @ 35 psi
	Fed Std. 193 / 2% lost @ 1,000 cycles	10-120	ASTM F1677 / Dry: .90 / Wet: .36	
	Fed Std 191 / 2% lost @ 1,000 cycles		ASTM F1677 / Dry: .91	ASTM D575 / .23 inches @ 35 psi
	Fed Std 191 / 1% lost @ 1,000 cycles	10-110	ASTM F1677 / Dry: COF = > .90 / Wet: COF = .34	
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: >.84 / Wet: .78 / Oily: .34	ASTM D575 / Deflection @ 35 psi, mm = 4.10
		-50-250	ASTM F1677 / Dry: >.84 / Wet: .78 / Oily: .34	ASTM D575 / Deflection @ 35 psi, mm = 4.10
		-50-250	ASTM F1677 / Dry: >.84 / Wet: .78 / Oily: .34	ASTM D575 / Deflection @ 35 psi, mm = 4.10
	Fed Std 191 / 1% lost @ 1,000 cycles	10-110	ASTM F1677 / Dry: > .78 / Wet: .68	
	Fed Std 193 / <3% lost @ 1,000 cycles		ASTM F1677 / Dry: 1.03 / Wet: .81	
	Fed Std 193 / <3% lost @ 1,000 cycles		ASTM F1677 / Dry: 1.03 / Wet: .81	
	Fed Std 191 / 1% lost @ 1,000 cycles	10-110	ASTM F1677 / Dry: .78 / Wet: .68	ASTM D575 / Deflection @ 35psi, mm = 4.10
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .78 / Wet: .68	
	Fed Std 191 / 1% lost @ 1,000 cycles	10-120	ASTM F1677 / Dry: > .90	
		10-250	ASTM F1677 / Dry: > .90 / Wet: .36	ASTM D575 / Deflection @ 35 psi, mm = 4.10
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: 1.10 / Wet: 1.10	
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: 1.10 / Wet: 1.10	
		-20-250	ASTM F1677 / Dry: .78 / Wet: .68	
	Fed Std 191 / 1000g, CS-17 wheel	0-110	ASTM F1677 / Dry: .79	ASTM D575 / Deflection @ 35 psi, mm = .237
	Fed Std 191 / 1000g, CS-17 wheel	0-110	ASTM F1677 / Dry: .68 / Wet: .17	ASTM D575 / Deflection @ 35 psi, mm = .315
	Fed Std 191 / 1000g, CS-17 wheel	0-110	ASTM F1677 / Dry: .79	
	Fed Std 191 / 1000g, CS-17 wheel	-10-120	ASTM F1677 / Dry: .68 / Wet: .17	ASTM D395-98 / 20%
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	Fed Std 191 / 1% lost @ 1,000 cycles	-50-250	ASTM F1677 / Dry: .75 / Wet: .28	ASTM D 395 / 30 minutes 5.67 / 24 hours 1.42
	-20-200	-20-200	ASTM D 1056 / 25%	

# Product specifications

Group Code	Product Name	Page	Recycled Content	Flammability
515	ROVER™	66	<10%	MVSS 302 / "A" Rating
518	Comfort2Go™	67	>50%	MVSS 302 / "A" Rating
540	F.I.T.™ Open	23	>80%	MVSS 302 / "A" Rating
541	F.I.T.™ Solid	23	>80%	MVSS 302 / "A" Rating
542	F.I.T.™ Open w/GRITSHIELD™	23	>80%	MVSS 302 / "A" Rating
543	F.I.T.™ Solid w/GRITSHIELD™	23	>80%	MVSS 302 / "A" Rating
544	F.I.T.™ Kits	34	>80%	MVSS 302 / "A" Rating
545	F.I.T.™ Kits w/GRITSHIELD™	34	>80%	MVSS 302 / "A" Rating
546	F.I.T.™ Emergency Shower and Eyewash	35	>80%	MVSS 302 / "A" Rating
548	F.I.T.™ Comfort Deck	20	>80%	MVSS 302 / "A" Rating
552	ErgoDeck® w/Integrated No-Slip Cleats Solid	20, 32	>80%	MVSS 302 / "A" Rating
553	ErgoDeck® w/Integrated No-Slip Cleats Open	20, 32	>80%	MVSS 302 / "A" Rating
553	ErgoDeck® No-Slip Kit	32	>80%	MVSS 302 / "A" Rating
554	ErgoDeck® w/Steel No-Slip Cleats Solid (See Website)		>80%	MVSS 302 / "A" Rating
555	ErgoDeck® w/Steel No-Slip Cleats-Open (See Website)		>80%	MVSS 302 / "A" Rating
556	ErgoDeck® Comfort Solid	17	>80%	MVSS 302 / "A" Rating
556	ErgoDeck® Comfort Kit	33	>80%	MVSS 302 / "A" Rating
557	ErgoDeck® ESD	59	>80%	MVSS 302 / "A" Rating
558	ErgoDeck® Comfort Open	17	>80%	MVSS 302 / "A" Rating
560	ErgoDeck® HD Open	19	>80%	MVSS 302 / "A" Rating
561	ErgoDeck® HD Open w/GRITSHIELD™	19	>80%	MVSS 302 / "A" Rating
562	ErgoDeck® HD Solid	19	>80%	MVSS 302 / "A" Rating
563	ErgoDeck® HD Solid w/GRITSHIELD™	19	>80%	MVSS 302 / "A" Rating
564	ErgoDeck® GP Open	18	>80%	MVSS 302 / "A" Rating
565	ErgoDeck® GP Open w/GRITSHIELD™	18	>80%	MVSS 302 / "A" Rating
566	ErgoDeck® GP Solid	18	>80%	MVSS 302 / "A" Rating
567	ErgoDeck® GP Solid w/GRITSHIELD™	18	>80%	MVSS 302 / "A" Rating
568	ErgoDeck® GP Smooth	17	>80%	MVSS 302 / "A" Rating
569	ErgoDeck® HD Smooth	17	>80%	MVSS 302 / "A" Rating
590	ErgoDeck® Diamond Plate -GP	16	>80%	MVSS 302 / "A" Rating
598	ErgoDeck® MAX Geometric Surface Design	14-15	>30%	MVSS 302 / "A" Rating
599	ErgoDeck® MAX Diamond Plate Surface Design	14-15	>30%	MVSS 302 / "A" Rating
570-CFR	24/Seven® Solid CFR	38	>50%	MVSS 302 / "A" Rating
570-GR	24/Seven® Solid GR	39	>50%	MVSS 302 / "A" Rating
570-NBR	24/Seven® Solid NBR	39	>50%	MVSS 302 / "A" Rating
572-CFR	24/Seven® CFR	38	>50%	MVSS 302 / "A" Rating
572-GR	24/Seven® GR	39	>50%	MVSS 302 / "A" Rating
572-NBR	24/Seven® NBR	39	>50%	MVSS 302 / "A" Rating
574-CFR	24/Seven® Solid GRITSHIELD™ CFR	38	>50%	MVSS 302 / "A" Rating
574-NBR	24/Seven® Solid GRITSHIELD™ NBR	39	>50%	MVSS 302 / "A" Rating
576-CFR	24/Seven® GRITSHIELD™ CFR	38	>50%	MVSS 302 / "A" Rating
576-NBR	24/Seven® GRITSHIELD™ NBR	39	>50%	MVSS 302 / "A" Rating
580	Autoclavable Mat	76	<10%	MVSS 302 / "A" Rating
698	Safety Track	87	<10%	
701	Diamond-Plate Switchboard Matting	54	<10%	MVSS 302 / "A" Rating
702	Corrugated Switchboard Matting	54	<10%	MVSS 302 / "A" Rating
710-MAT	Marbleized Military Switchboard Matting	55	<10%	MVSS 302 / "A" Rating
710-THR	Welding Thread	55	<10%	
711	Smooth Military Switchboard Matting	55	<10%	MVSS 302 / "A" Rating
712	Diamond-Plate Military Switchboard	55	<10%	MVSS 302 / "A" Rating
720	Double Duty Switchboard Corrugated Mat	54	<10%	MVSS 302 / "A" Rating
785-DP	Electrically Conductive, Diamond-Plate	59	<10%	MVSS 302 / "A" Rating
785-SM	Electrically Conductive, Smooth	59	<10%	MVSS 302 / "A" Rating
786-DP	UltraSoft Electrically Conductive Diamond-Plate	59	<10%	MVSS 302 / "A" Rating
786-SM	UltraSoft Electrically Conductive, Smooth	59	<10%	MVSS 302 / "A" Rating
788	Modular Diamond-Plate ESD	60	<10%	MVSS 302 / "A" Rating
789	Modular WorkSafe® Light ESD	60	<10%	MVSS 302 / "A" Rating
791	Static Dissipative Anti-Fatigue	61	<10%	MVSS 302 / "A" Rating
793-Surface	ESD Work Surface Material	62	<10%	

Tabor Abrasion		Temp Range (°F)	Coefficient of Friction	Compression Deflection
		-20-200		ASTM D 1056 / 25%
	Fed Std 191 / 1000g, CS-17 wheel	10-110	ASTM F1677 / Dry: .68 / Wet: .17	ASTM D395-98 / 20%
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: .81 / Wet: .49	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: .81 / Wet: .49	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: 1.1 / Wet: .63	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: 1.1 / Wet: .63	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: .81 / Wet: .49	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: 1.1 / Wet: .63	
	ASTM D 3884 / 1% loss	10-110	ASTM F1677 / Dry: .81 / Wet: .49	
	ASTM D 3884 / 1% loss	10-110	Not Available	Not Available
	ASTM D 3884 / <1% loss	10-110	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D575-91 / 8.03%
	ASTM D 3884 / <1% loss	10-110	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D575-91 / 10.00%
	ASTM D 3884 / <1% loss	10-110	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D575-91 / 10.00%
	ASTM D 3884 / <1% loss	10-110	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D575-91 / 4.84%
	ASTM D 3884 / <1% loss	10-110	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D575-91 / 4.84%
	ASTM D 3884 / <1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 19.98%
	ASTM D 3884 / <1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 19.98%
	ASTM D 3884 / <1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 19.85%
	ASTM D 3884 / <1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 19.85%
	ASTM D 3884 / <1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 4.84%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677-05 / Dry: 1.1 / Wet: .93	
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 4.84%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677-05 / Dry: 1.1 / Wet: .93	
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 14.15%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677-05 / Dry: 1.1 / Wet: .93	
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	ASTM D575-91 / 14.15%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677-05 / Dry: 1.1 / Wet: .93	
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: COF = .65 / Wet: COF = .42	ASTM D575-91 / 14.15%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: COF = 1.1 / Wet: COF = .93	ASTM D575-91 / 4.84%
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .65 / Wet: .42	Not Available
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .68	
	ASTM D 3884 / 1% loss	0-120	ASTM F1677 / Dry: .68	
	Fed Std 191 Modified / 1% loss	10-110	ASTM F1677 / Dry: .78 / Wet: .68	
	Fed Std 191 Modified / 1% loss	10-110	ASTM F1677 / Dry: .78 / Wet: .68	
	Fed Std 191 Modified / 1% loss	10-110	ASTM F1677 / Dry: .78 / Wet: .68	
	Fed Std 191 Modified / 1% loss	10-140	ASTM F1677 / Dry: .90 / Wet: 020	
	Fed Std 191 Modified / 1% loss	10-140	ASTM F1677 / Dry: .90 / Wet: 020	
	Fed Std 191 Modified / 1% loss	10-140	ASTM F1677 / Dry: .90 / Wet: 020	
	Fed Std 191 Modified / 1% loss	10-120	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D 575 / Deflection @ 35 psi, mm = 8.02, inches = .315
	Fed Std 191 Modified / 1% loss	10-120	ASTM F1677 / Dry: 1.10 / Wet: 1.10	ASTM D 575 / Deflection @ 35 psi, mm = 8.02, inches = .315
	Fed Std 191 Modified / 1% loss	10-120	ASTM F1677 / Dry: 1.10 / Wet: .90	ASTM D 575 / Deflection @ 35 psi, mm = 8.02, inches = .315
	Fed Std 191 Modified / 1% loss	10-120	ASTM F1677 / Dry: 1.10 / Wet: .90	ASTM D 575 / Deflection @ 35 psi, mm = 8.02, inches = .315
	Fed Std 191 Modified / 1% loss		ASTM F1677 / Dry: .78 / Wet: .68	
			ASTM F1677 / Dry: .95 / Wet: .80	
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: COF .68 / Wet: COF .17	
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: .91	
			ASTM F1677 / Dry: COF .79	
		-20-160	Not Available	
		-20-160	ASTM F1677 / Dry: COF .79	
	Fed Std 191 / 4% lost @ 1,000 cycles	-20-160	ASTM F1677 / Dry: COF .68 / Wet: COF .17	
	Fed Std 191 / 1% lost @ 1,000 cycles		ASTM F1677 / Dry: COF .91	
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-130	ASTM F1677 / Dry: .68 / Wet: .17	
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-130	ASTM F1677 / Dry: .68 / Wet: .17	
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-130	ASTM F1677 / Dry: .90	ASTM D575 / Deflection @ 35 psi, mm = 8.43
	Fed Std 191 / 1% lost @ 1,000 cycles	-10-130	ASTM F1677 / Dry: .90	ASTM D575 / Deflection @ 35 psi, mm = 8.43
		-50-250	ASTM F1677 / Dry: >.84 / Wet: .78 / Oily: .34	ASTM D575 / Deflection @ 35 psi, mm = 4.10
	Fed Std 191 / 1% lost @ 1,000 cycles	0-110	ASTM F1677 / Dry: .62 / Wet: .17	ASTM D575 / Deflection @ 35 psi, mm = .343

# Customization

One-Size does not fit all. Unique production processes call for specialized work flow. Your anti-fatigue solution should fit your special space. Customization is easy to fit any configuration. Large or original shapes are our specialty. Contact us for a site survey or send us a drawing of your spacial configuration. No matter whether it is a C1 which is length only, C2 where we customize the length and the width, or a C3 where we have a full custom configuration for your specific area, we can build to suit your needs. Call us at 1-800-264-3030.



Diamond-Plate  
Custom - Pg 26



24/SEVEN® Custom Pg 38



Rejuvenator®  
Custom - Pg 12



Diamond-Plate  
Custom Pg 26



Rejuvenator®  
Custom - Pg 12

# SIMPLE GAME-WINNING STRATEGY



Even the best coaches are faced with challenges. You don't have to go it alone! Tackle them with one of our global team experts. Using state of the art tools, they'll come to your facility, assess your areas of concern and create a game plan specific to your goals, initiatives and budget.

## The Wearwell Site-Survey is Free of Charge

This service is valued at \$2,000, but we provide it at no charge with confidence we will earn your business.

## Backed by 68 Years of Expertise

You could purchase competitor products, but we are confident you won't find any that can compare to the quality and value of a **Wearwell product**. We are the industry experts

## Your Team, Your Plan

You can prioritize based on your time-line and budget.

## Work with Your Current Distributors

With our large network of top notch distributors, purchasing Wearwell flooring and matting is simple and convenient.



Find Your Anti-Fatigue and Safety Solutions  
@ [wearwell.com](http://wearwell.com)

NEED HELP? We Have Over 70 Field Experts  
Across U.S., Canada, Mexico And South America



### NORTH AMERICA

Wearwell, Inc. (Headquarters)  
Phone: 1.800.264.3030  
[info@wearwell.com](mailto:info@wearwell.com)  
[wearwell.com](http://wearwell.com)

MEXICO  
[wearwell.com/mx](http://wearwell.com/mx)

CANADA  
[wearwell.com/ca](http://wearwell.com/ca)

### EUROPE

Wearwell Europe LTD  
Phone: 44.1525.307271  
[info@wearwell-europe.co.uk](mailto:info@wearwell-europe.co.uk)

UK & Ireland  
[wearwell.com/uk](http://wearwell.com/uk)

France  
[wearwell.com/fr](http://wearwell.com/fr)

Germany  
[wearwell.com/de](http://wearwell.com/de)