

SHOWA CHM

This chemical protection glove is flexible, comfortable, and resistant to a broad range of chemicals. Engineered with a neoprene-over-natural rubber construction with tractor tread grip, the SHOWA CHM provides maximum precision, sensitivity, and defense. The cotton flocked liner helps to maintain a comfortable temperature within the glove.




BENEFITS

- Flexible
- Increased sensitivity
- Chemical-resistant
- Neoprene over natural rubber

FEATURES

- Embossed grip
- Unsupported
- Cotton liner
- Flocked

NORMS & CERTIFICATES

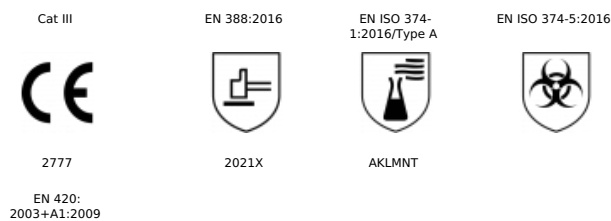

INDUSTRIES



Automotive



Chemical



Janitorial

HAZARDS



Chemical

TRADES & APPLICATIONS

- Mechanical and engineering
- Painting & spray workshops
- Chemical spray and treatment
- Coating preparation
- Assembly dry and oily parts
- Washing and cleaning

GET IN TOUCH

SHOWA International | WTC - Tower I - Strawinskylaan 1077 XX Amsterdam - The Netherlands
showagroup.com | info@showagroup.eu
© SHOWA GROUP 2021 | All rights reserved

PACKAGING

- Pair per polybag: 12
- Polybags per case: 12
- Pair per case: 144

THICKNESS

0.66mm

LENGTH

305 mm

COATING

- Bi-Polymer
- Latex
- Neoprene

SIZES

7/S | 8/M | 9/L | 10/XL

COLOUR

- Blue
- Black

MATERIAL

- Cotton flock
- Unsupported

USER INSTRUCTIONS

Gloves provide protection from chemical and mechanical hazards shown. Do not use gloves that show signs of wear. If required, cleanse outer surface of glove with running water. Discard used gloves in compliance with local regulations. Do not wear gloves when there is a risk of entanglement by moving parts of machines.

DISCLAIMER

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment. The manufacturer reserves the right to make any modifications it deems necessary.

GET IN TOUCH

SHOWA International | WTC - Tower I - Strawinskylaan 1077 XX Amsterdam - The Netherlands
showagroup.com | info@showagroup.eu
© SHOWA GROUP 2021 | All rights reserved