


PORTABLE MAGNETIC HOLDERS

Secure brooms, flashlights, spray cans, markers, etc. to any steel surface without drilling to install clips/holders. These powerful permanent magnets are quickly installed and repositioned when needed. Keep critical tools for the job handy.

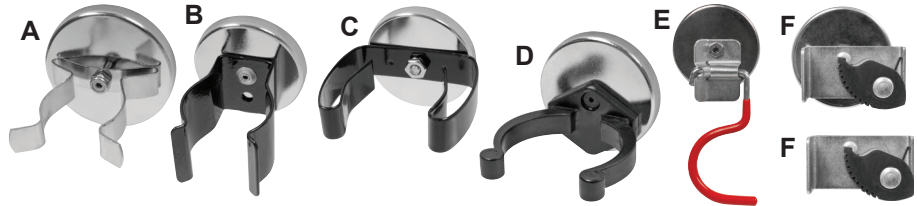


Style	Max Hold - lbs (kg)	Description	Application	Magnet O.D. (in)	Opening (in)	Magnet I.D. (in)	OAH (in)	Wt. (lbs)	Model No.	
A	15.0 (6.80)	Nickel Plated Clamp	Spring Tension	Ceramic	1.24	0.19 - 0.38	0.25	0.88	0.05	MX1000NP01
A	25.0 (11.34)	Nickel Plated Clamp	Spring Tension	Ceramic	1.41	0.31 - 0.75	0.375	1.53	0.10	MX1500NP01
A	42.0 (19.05)	Nickel Plated Clamp	Spring Tension	Ceramic	2.03	0.63 - 1.25	0.859	2.31	0.19	MX2000NP01
A	80.0 (36.29)	Nickel Plated Clamp	Spring Tension	Ceramic	2.63	1.00 - 1.88	1.00	2.50	0.41	MX2500NP01
A	15.0 (6.80)	Stainless Steel Clamp	Spring Tension	Ceramic	1.24	0.38 - 0.50	0.25	1.09	0.05	MX1000SS01
A	25.0 (11.34)	Stainless Steel Clamp	Spring Tension	Ceramic	1.41	0.63 - 0.88	0.375	1.91	0.11	MX1500SS01
A	25.0 (11.34)	Stainless Steel Clamp	Spring Tension	Ceramic	1.41	0.88 - 1.13	0.375	2.03	0.10	MX1500SS02
A	25.0 (11.34)	White Plastic Coated Clamp	Spring Tension	Ceramic	1.41	0.31 - 0.75	0.375	1.66	0.10	MX1500WP03
A	25.0 (11.34)	White Plastic Coated Clamp	Spring Tension	Ceramic	1.41	0.56 - 0.88	0.375	1.28	0.09	MX1500WP01
A	42.0 (19.05)	White Plastic Coated Clamp	Spring Tension	Ceramic	2.03	0.63 - 1.25	0.859	2.31	0.19	MX2000WP01
A	80.0 (36.29)	White Plastic Coated Clamp	Spring Tension	Ceramic	2.63	1.00 - 1.88	1.00	2.88	0.41	MX2500WP01
B	42.0 (19.05)	Black Vinyl Coated Clamp	Flashlight	Ceramic	2.03	1.50 - 1.88	0.859	2.19	0.19	MX2000VB02
C	15.0 (6.80)	Zinc Plated Clamp	Spring Tension	Ceramic	1.24	0.38 - 0.63	0.25	1.13	0.06	MX1000ZP01
C	25.0 (11.34)	Zinc Plated Clamp	Spring Tension	Ceramic	1.41	0.75 - 1.13	0.375	1.53	0.13	MX1500ZP01
C	25.0 (11.34)	Zinc Plated Clamp	Spring Tension	Ceramic	1.41	1.00 - 1.50	0.375	1.53	0.19	MX1500ZP02
C	15.0 (6.80)	Black Vinyl Coated Clamp	Spring Tension	Ceramic	1.24	0.38 - 0.63	0.25	1.13	0.06	MX1000VB01
C	25.0 (11.34)	Black Vinyl Coated Clamp	Spring Tension	Ceramic	1.41	0.75 - 1.13	0.375	1.53	0.13	MX1500VB01
C	19.0 (8.62)	Black Vinyl Coated Clamp	Spring Tension	Ceramic	2.03	2.00 - 2.50	0.859	2.31	0.22	MX2000VB01
D	15.0 (6.80)	Black Plastic Clamp	Non-Conductive	Ceramic	1.24	0.87 - 1.13	0.25	0.98	0.05	MX1000BP01
D	25.0 (11.34)	Black Plastic Clamp	Non-Conductive	Ceramic	1.41	1.13 - 1.38	0.375	1.25	0.10	MX1500BP01
D	42.0 (19.05)	Black Plastic Clamp	Non-Conductive	Ceramic	2.03	1.87 - 2.13	0.859	2.06	0.20	MX2000BP01
E	42.0 (19.05)	Red Vinyl Hook	Broom Holder	Ceramic	2.03	1.38	0.859	4.50	0.20	MX2000RV01
F	80.0 (36.29)	Black Rubber Spring Clamp	Broom Holder	Ceramic	2.63	0.87 - 1.25	1.00	1.50	0.65	MX2500BH01
F	N/A	Black Rubber Spring Clamp	Broom Holder	N/A	N/A	0.87 - 1.25	2.62"L x 1.25"W x 1.50"H	0.20	981113	

GRINDER TOOL HOLDER



Keep your grinder handy on top or side of steel work benches. Powerful permanent magnet holds up to 6" diameter grinder wheels in horizontal or vertical positions, regardless of trigger location.

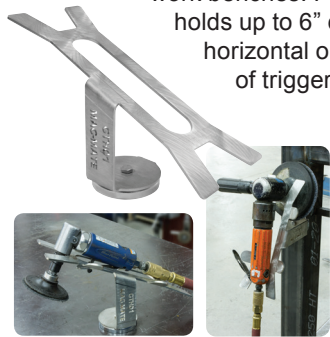

Features

- Sturdy stainless steel holder
- Keep grinder protected and close at hand
- Magnetic base allows for quick placement and repositioning

Hold - lbs (kg)	Height (in)	Width (lbs)	Length (in)	Weight (in)	Model No.
56.0 (25.40)	6	4-3/8	9-1/8	1.20	GTH01

TWO LINE CLAMPS



Instantly install magnetic clamps on any steel surface. No drilling or other mounting hardware needed. Idea for pneumatic lines, PVC lines and electrical wires. Perfect for holding forklift battery cables and connector in place. Bright plated permanent magnet and black polypropylene holder withstand moisture. Temperature range is -20° to 190°F.



ID (in)	Hold - Lbs (kg)	Dia (in)	Projects (in)	Weight (lb)	Model No.
1/4	25 (11.34)	1.41	1-1/4	0.10	TLC0250M
3/8	42 (19.05)	2.03	1-1/4	0.15	TLC0375M
1/2	80 (36.29)	2.63	1-3/4	0.40	TLC0500M
5/8	80 (36.29)	2.63	1-3/4	0.40	TLC0625M

SPRAY GUN HOLDER



Keep your spray gun handy inside your paint booth! This magnetic Spray Gun Holder sticks through many layers of paint to hold your spray gun. Easily moved when necessary.

Features

- Sturdy Stainless Steel holder
- Plated Permanent Ceramic Cup Magnet



Holds - lbs (kg)	Height (in)	Width (in)	Projects (in)	Weight (lbs)	Model No.
95 (43.09)	4.9	4.9	5.5	1.75	SGH01

FLEXIBLE FLASHLIGHT HOLDER

When you need to use both hands and there is nobody to hold a light for you, these magnetic based flexible flashlight holders will come to the rescue. Strong magnetic hold is easily repositioned. Flexible neck lets you pinpoint the light right where you need it. MX25FLVB02 fits typical Mag-Lite® flashlights. Flashlights not included.



Hold - Lbs. (kg)	Open Range (in)	A (in)	B (in)	C (in)	Weight (lbs)	Model No.
42 (19.1)	0.62 - 1.25	2.03	8.50	7.87	0.25	MX20FLNP01
42 (19.1)	1.00 - 1.50	2.03	9.00	8.00	0.25	MX20FLZP02
80 (36.3)	1.50 - 1.87	2.63	10.75	9.75	0.55	MX25FLVB02